


order number: J00023A0207

Outlet AMJ45 8/8 K AP Cat.6_A, pearl white

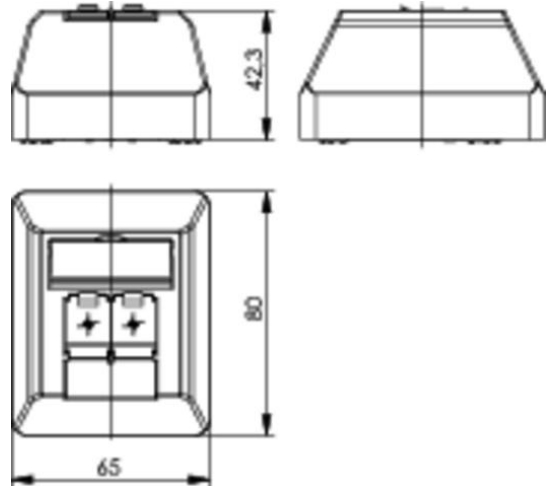

REAL-TIME
RE-EMBEDDED

Technical Attributes	
Short name	AMJ45 8/8 K AP Cat.6 _A
Type	surface mounting, 2xRJ45
Colour	pearl white

Performance Characteristics

- Transmission performance: Cat.6_A acc. to ISO/IEC 11801; EN 50173-1
- full shielded, zinc diecast housing
- 360° shielding contact and strain relief by means of two separate, captive screwclamps for the exterior cable jacket and shielding
- simple lead presorting guarantees leads will be laid without damage and good transmission performance
- cover plate can be retrofitted with a flip-up loss-proof, transparent label field
- dust cover flaps protected
- rugged zinc diecast housing for surface mounting
- compact design
- cable entry in 4x90° steps selectable