

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [130039-0284](#)  
**Status:** **Active**  
**Overview:** Brad® Mini-Change® Connectors  
**Description:** DeviceNet® Mini-Change® Receptacle, 5 Poles, Female (Straight) to DeviceNet Trunk Cable, 1/2" - 14 NPT Threads, 1.0m (3.28') Length

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR6837  
 UL E152210

**General**

Product Family Industrial Receptacles  
 Series [130039](#)  
 IP Rating IP67  
 NEMA Rating NEMA 6  
 Overview [Brad® Mini-Change® Connectors](#)  
 Product Name DeviceNet® Trunk, Mini-Change®  
 Type Single Ended (pigtail)  
 UPC 78678828755

**Physical**


Coupling Type Internal Thread  
 Gender Female  
 Keyway Single  
 Length 1.0m  
 Material - Component Gray Anodized Aluminum  
 Mounting Thread Size 1/2" - 14 NPT  
 Net Weight 26.660/g  
 Orientation Straight  
 Panel Mount Front  
 Poles 5  
 Temperature Range - Operating -20°C to +80°C  
 Wire Size AWG N/A  
 Wire/Cable Type N/A

**Electrical**

Current - Maximum per Contact 8A  
 Voltage - Maximum 300V AC/DC

**Material Info**

Old Part Number DN5000-M010

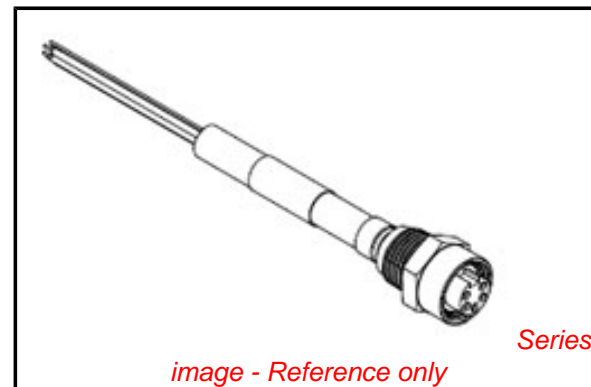

*image - Reference only*

**EU RoHS**

**RoHS Compliant by Exemption**  
**REACH SVHC**  
 Not Reviewed  
**Low-Halogen Status**  
**Not Low-Halogen**

**China RoHS**



**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

130039Series