
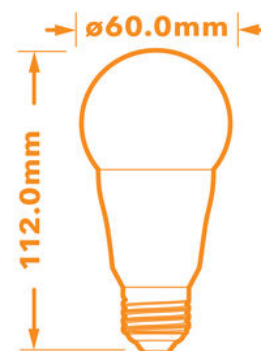


Verbatim LED Classic A E27 12W 3000K Warm White 1100 LM


- E27 Socket
- 220 - 240 Voltage
- 30,000 hours Lifetime
- 84% Energy Saving
- Lumen: 1100
- Equivalent to 77W incandescent bulb

Product Number	52153
General Data	
Lamp Socket	E27
Electric Data	
Wattage (W)	12
Wattage Equivalent (W)	77
Voltage (V)	220 - 240
Dimmable	no
Power Factor	0.90
Operating Frequency (Hz)	50-60
Geometric Data	
Length (mm)	112
Diameter (in mm)	60
Weight (g)	177
Photometric Data	
Luminous Flux (lm)	1100
CRI	≥ 80
CCT (K)	3000
Beam Angle (°)	130
Luminous Efficacy (lm/W)	91.7
Lifetime (hrs)	30,000
Switching Cycle	20,000

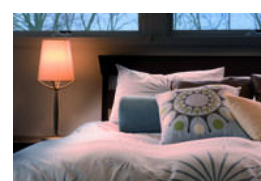

02/07/2014


Photometric Diagrams

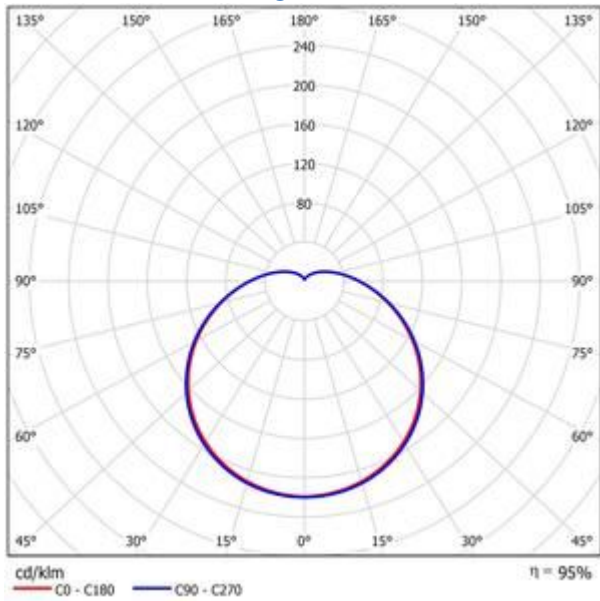

Distance [m]	Cone Diameter [m]	Illuminance [lx]
0.5	2.44 2.36	E(0°) 940 E(C90) 67.7° 26 E(C0) 67.0° 28
1.0	4.88 4.71	E(0°) 235 E(C90) 67.7° 6 E(C0) 67.0° 7
1.5	7.31 7.07	E(0°) 104 E(C90) 67.7° 3 E(C0) 67.0° 3
2.0	9.75 9.42	E(0°) 59 E(C90) 67.7° 2 E(C0) 67.0° 2
2.5	12.19 11.78	E(0°) 38 E(C90) 67.7° 1 E(C0) 67.0° 1
3.0	14.63 14.14	E(0°) 26 E(C90) 67.7° 1 E(C0) 67.0° 1

Distance [m] Cone Diameter [m] Illuminance [lx]
 — C0 - C180 (Half-value Angle: 134.0°)
 — C90 - C270 (Half-value Angle: 135.4°)

Energy Rating

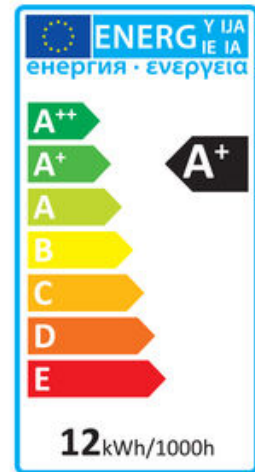

Technical Packaging Details

Barcode

023942521532

EAN 128

(02)00023942521532(37)04(91)204

EAN 14

50023942521537

Pack Dimensions(HxWxL)

178 x 118 x 61

Pack Weight

203

MOQ

4

Carton Dimensions (HxWxL)

195 x 144 x 253

Cartons/Pallet

80

Layers/Pallet

4

Units/Pallet

320

02/07/2014