


# Datasheet

## Fibre Optic Cable Assembly

RS Stock number 536-6901



### Dimensions: (mm)

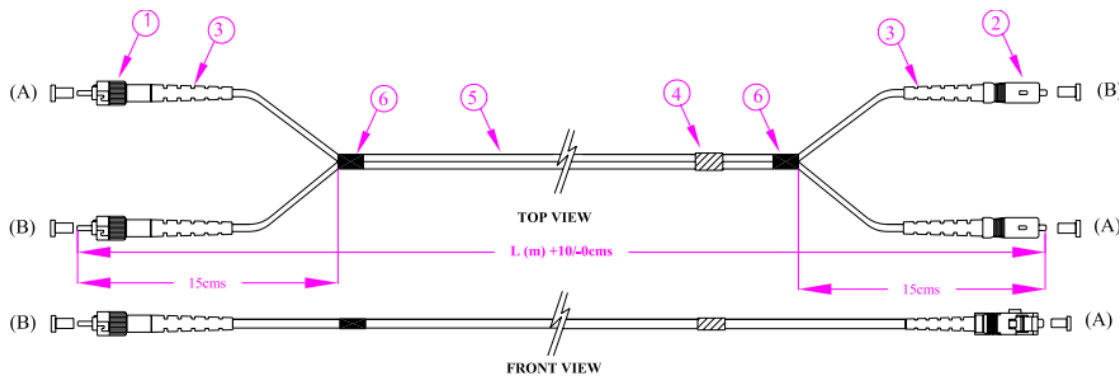

**Optical Performance (IEC 61300-3-4):**  
**Multimode (@ 1300nm)**  
 Max. IL - 0.30dB Typical: 0.20dB  
**Singlemode: (@1310nm and/or 1550nm)**  
 Max. IL - 0.30dB Typical: 0.20dB Return Loss: >50dB

**RoHS Compliant**

| Id No. | Description              | Ea |
|--------|--------------------------|----|
| 1.     | ST Connector             | 2  |
| 2.     | SC Connector             | 2  |
| 3.     | SC & ST Boots            | 4  |
| 4.     | Identification Label     | 1  |
| 5.     | 2.8mm Duplex Cable (L m) | 1  |
| 6.     | Black Tape               | 2  |

**Connector:** LC clips shall be mounted on to the connector to make it duplex.

**Coiling Diameter:** Coiling Diameter of the patchcord shall be greater than 200mm