


Item # 70-750DL8-1, 70-750DL8-1 Socket / 16/5 Amp Rating, 300/600 Volts

8 Pin Octal, Logic Style, Finger Safe, DIN/Panel Mount, Module Compatible

This Item is Normally Stocked

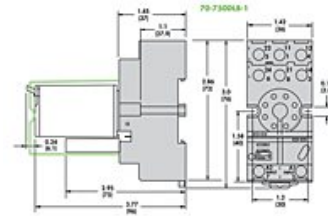

[Specifications](#) · [Electrical Rating](#) · [Temperature](#) · [Construction](#) · [Miscellaneous](#) · [Product Certifications](#)

Specifications

Check Inventory	Check Distributor Inventory
Legacy Part No.	70-750D8-1
Contact Configuration	DPDT
Number of Terminals	8
Mounting Style	DIN Rail Panel

Electrical Rating

Current Rating	16 A
Nominal Voltage Rating	300 V

Temperature

Storage Range	- 40 to + 105 °C
---------------	------------------

Construction

Protection Category (Finger Safe)	IP 20
Internal Metal Tracks	Copper Alloy Zinc Plated
Terminals	Steel Zinc Plated
Screw Style	Combination Head
Screw Size	M3.5 mm
Screw Torque 3.5 mm (Maximum)	9 / 1.0 Lb-in / Nm
Terminal Connection	Screw Clamping
Terminal Layout	Non-Logic
Base	Octal

Miscellaneous

Wire Size Capacity (Maximum), EN 60204-1, Solid Cu	12 / 14 (2) AWG, 4 / 2.5 (2) mm ₂
Wire Size Capacity (Maximum), EN 60204-1, Stranded Cu	12 / 14 (2) AWG, 4 / 2.5 (2) mm ₂
DIN Rail Mounting, EN 60715	35 mm
Chassis Mount Screw Torque	7 / 0.8 Lb-in / Nm
Flammability Rating	94V-0 Class
Body Color	Light Gray
DIN Locking Method	Red Plastic Locking Clip

Product Certifications

Agency Approvals	CE RoHS UL CSA
-------------------------	-------------------------