



WD-40 Company Ltd, PO Box 440, Kiln Farm, Milton Keynes, MK11 3LF
Tel: 01908 555400 Fax: 01908 266900 Fax orders: 01908 266913
Email: info@wd40.co.uk Web: www.wd40.co.uk



SPECIALIST™

**A TOOL FOR
EVERY JOB**

THE ORIGINAL

WD-40® MULTI-USE PRODUCT has been getting tough jobs sorted since 1953 and has become the product of choice for Trades and Industry throughout the UK.

With awareness levels of 99%*, WD-40® remains the most highly recognised and considered brand for solving problems, with more uses being discovered every day.

Recently, WD-40® has been recognised as a UK Superbrand 2012 because of the quality, reliability and distinction that it represents for users.

WD-40® Multi-Use Product remains as important today as it has ever been, and still the number one tool for every toolbox.



**PROBLEM SORTED,
JOB DONE RIGHT!**



A TOOL FOR EVERY JOB SPECIALIST

Introducing WD-40 Specialist™ line an exciting range of products wearing the WD-40® shield you've come to rely on. These products have been specially designed for those more demanding jobs that just need to be done right.

You can still rely on WD-40® Multi-Use Product, but can now add WD-40 Specialist™ to your tool box for all those jobs requiring a specific solution.



HIGH PERFORMANCE SILICONE LUBRICANT

This solution is a non-staining, hard working formula which provides excellent lubrication, won't attract dirt, and protects against moisture. It stops parts from sticking and can be used on high pressure equipment.



- ⊕ Withstands temperatures of -35°C to +200°C
- ⊕ Prevents parts from sticking
- ⊕ Waterproofs and protects against moisture
- ⊕ For use on Metal, Plastic, Rubber & Wood

NSF H2 Registered #145374



NARROW SPRAY



WIDE SPRAY



FAST RELEASE PENETRANT

This powerful fast acting solution, quickly penetrates its way into hard to reach areas, rapidly loosen seized fixings, stuck or rusted moving parts. Highly water resistant.



- ⊕ Withstands temperatures of -20°C to +90°C
- ⊕ Quickly penetrates rusted and corroded parts
- ⊕ Loosens seized fixings
- ⊕ For use on Metal, Alloys, Rubber, Plastic & Most Paints

NSF H2 Registered #145375



NARROW SPRAY




WIDE SPRAY



HIGH PERFORMANCE WHITE LITHIUM GREASE

This grease is a thicker solution which provides long term lubrication that won't drip nor run. It's great for metal to metal applications, reducing friction to ensure your tools and equipment keep moving smoothly. For use on load bearing metal connections.

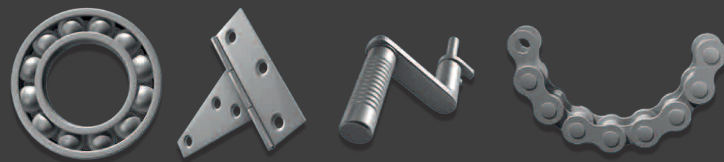

- ⊕ Withstands temperatures of -18°C to +145°C
- ⊕ Water and heat resistant lubricant
- ⊕ Long lasting protection against rust & corrosion
- ⊕ For use on Metal to Metal connections

NSF H2 Registered #145376



FAST ACTING DEGREASER

This fast acting, solvent based solution, quickly removes grease, oil, dirt and grime without leaving any residue. It works immediately on contact and is easy to rinse away. For use on a wide variety of surfaces including metal, exhaust hoods, and flooring.




- ⊕ Works immediately on contact
- ⊕ Easy to rinse and leaves no residue
- ⊕ Cleans away Oil, Grease, Dirt & Grime

NSF K1 Registered #145373



HIGH PERFORMANCE PTFE LUBRICANT

This solution contains PTFE which provides excellent lubrication and protection whilst reducing friction and wear, extending the life of tools and equipment.

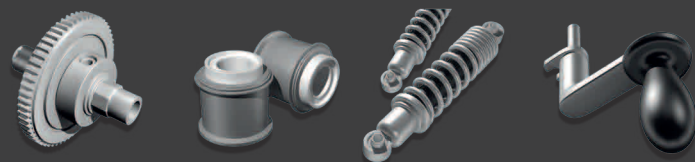

- ⊕ Withstands temperatures of -20°C to +100°C
- ⊕ Long lasting lubrication
- ⊕ Extends life of tools and equipment
- ⊕ For use on Metals, Glass, Vinyl, Rubber & Plastic



NSF H2 Registered #145377



FAST DRYING CONTACT CLEANER

This solution cleans oil, dirt, flux residue and condensation from sensitive electronics and electrical equipment. It rapidly penetrates into hard to reach areas, fast drying, without leaving any residue.



- ⊕ Fast acting, non conductive cleaner
- ⊕ Penetrates quickly and leaves no residue
- ⊕ For use on Electrical Equipment, Contacts, Plastic & Rubber




NSF K2 Registered #145372



ANTI FRICTION DRY PTFE LUBRICANT

This solution contains PTFE which provides enhanced lubrication, leaving a dry clear film that won't attract dirt, dust or oil. It's quick drying and also great as a mould release agent.

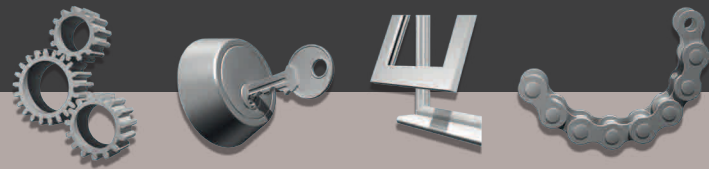

- ⊕ Withstands temperatures of -20°C to +250°C
- ⊕ Enhanced lubrication and protection
- ⊕ Dry clear film that resists dirt, dust and oil
- ⊕ For use on Metals, Plastic & Glass

NSF H2 Registered #145371



NARROW SPRAY



WIDE SPRAY



**PROBLEM
SORTED,
JOB DONE
RIGHT!**