


Deep groove ball bearings, single row, unsealed

Product information



Tolerances , see also text
 Radial internal clearance , see also text
 Recommended fits
 Shaft and housing tolerances

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	* - SKF Explorer bearing
60	130	31	85,2	52	2,2	11000	7000	1,70	6312 *

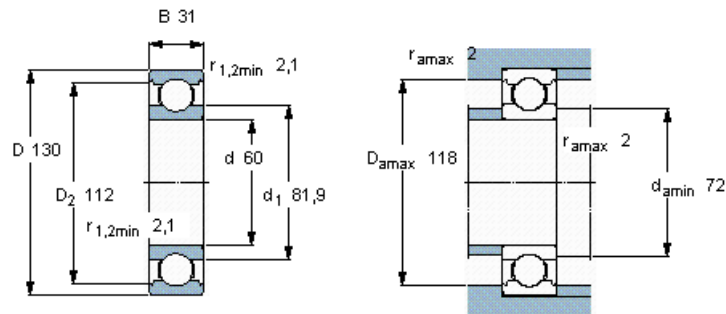

Calculation factors

k_f 0,03
 f_0 13