


Spherical roller bearings, cylindrical and tapered bore



Principal dimensions			Basic load ratings		Fatigue load limit P_U	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			C	C_0	kN	r/min		kg	* - SKF Explorer bearing
65	120	31	193	216	24	5000	7000	1,50	22213 EK *

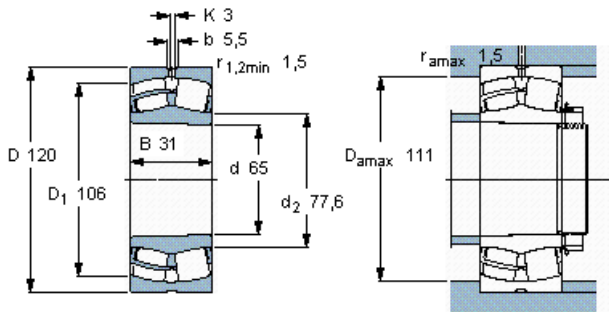

Tapered bore, taper
1: 12

Calculation factors

e 0,24
 Y_1 2,8
 Y_2 4,2
 Y_0 2,8