


**EG-Series**  
**EGT1 EG2/EN SCHALT.1X1U**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

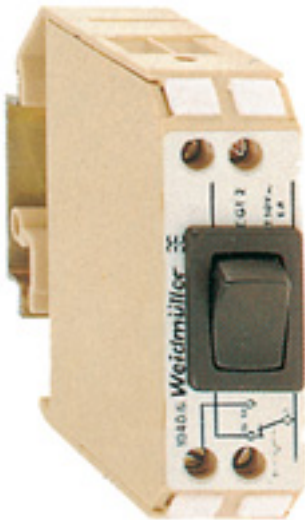

The profiles of the switch and button components match those of the electronic components.  
 Switches and buttons facilitate commissioning, servicing, monitoring and repair of industrial installations.

**General ordering data**

Order No.	<a href="#">0126360000</a>
Type	EGT1 EG2/EN SCHALT.1X1U
Version	EG-Series, Relays, No. of contacts: 1, Rated control voltage: 250 V AC, Screw connection
GTIN (EAN)	4008190097141
Qty.	10 pc(s).

**EG-Series**  
**EGT1 EG2/EN SCHALT.1X1U**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Technical data**
**Dimensions and weights**

Length	58 mm	Width	18 mm
Height	50 mm	Net weight	41.8 g

**Temperatures**

Operating temperature	-25 °C...+85 °C	Ambient temperature	-25 °C...+85 °C
Storage temperature	-40 °C...+100 °C		

**Rated data**

Conductor connection system	Screw connection
-----------------------------	------------------

**Connection data**

Clamping range, rated connection	6 mm <sup>2</sup>	Clamping range, rated connection, min.	0.5 mm <sup>2</sup>
Clamping range, rated connection, max.	6 mm <sup>2</sup>	Wire connection cross section, finely stranded, max.	4 mm <sup>2</sup>

**Classifications**

ETIM 2.0	EC001437	ETIM 3.0	EC001437
UNSPSC	30-21-19-17	eClass 4.1	40-02-06-14
eClass 5.1	27-37-16-01	eClass 6.0	27-37-16-01
eClass 7.0	27-37-16-01		

**Approvals**

Approvals


**Downloads**

Declaration of Conformity	<a href="#">K011_07_09.pdf</a>
---------------------------	--------------------------------