



Receptacle

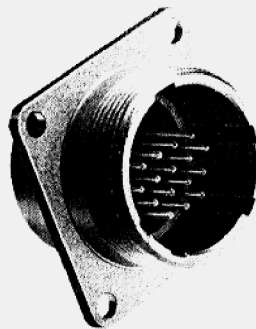

JR21RK-16P

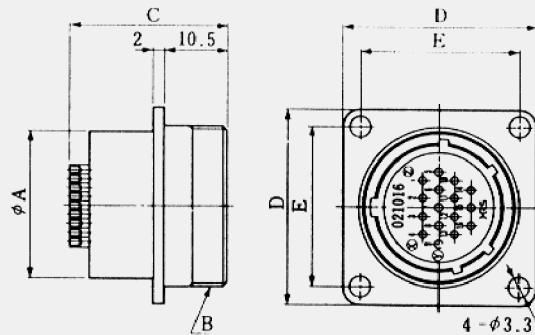

Unit: mm

HRS No.	Part No.	No. of Pin	φA	B	C	D	E	JIS No.
114-0517-7	JR13RK-3P	3	15.9	M18 x 1	26.6	26	20	CNR01SRM013003
114-0518-0	JR13RK-5P	5	15.9	M18 x 1	26.1	26	20	CNR01SRM013005
114-0519-2	JR16RK-7P	7	19.9	M22 x 1	26.6	29	23	CNR01SRM016007
114-0520-1	JR16RK-10P	10	19.9	M22 x 1	16.1	29	23	CNR01SRM016010
114-0521-4	JR21RK-10P	10	23.9	M26 x 1	26.6	32	26	CNR01SRM021010
114-0522-7	JR21RK-16P	16	23.9	M26 x 1	26.1	32	26	CNR01SRM021016
114-0523-0	JR25RK-16P	16	27.9	M30 x 1	26.6	35	29	CNR01SRM025016
114-0524-2	JR25RK-24P	24	27.9	M30 x 1	26.1	35	29	CNR01SRM025024
114-0558-4	JR25RK-4P	4	27.9	M30 x 1	28	35	29	—
114-0560-6	JR25RK-5P	5	27.9	M30 x 1	26.6	35	29	—
114-0562-1	JR25RK-8P	8	27.9	M30 x 1	26.6	35	29	—

HRS No.	Part No.	No. of Pin	φA	B	C	D	E	JIS No.
114-0525-5	JR13RK-3S	3	15.9	M18 x 1	28	26	20	CNR01SRF013003
114-0526-8	JR13RK-5S	5	15.9	M18 x 1	27	26	20	CNR01SRF013005
114-0527-0	JR16RK-7S	7	19.9	M22 x 1	28	29	23	CNR01SRF016007
114-0528-3	JR16RK-10S	10	19.9	M22 x 1	27	29	23	CNR01SRF016010
114-0529-6	JR21RK-10S	10	23.9	M26 x 1	28	32	26	CNR01SRF021010
114-0530-5	JR21RK-16S	16	23.9	M26 x 1	27	32	26	CNR01SRF021016
114-0531-8	JR25RK-16S	16	27.9	M30 x 1	28	35	29	CNR01SRF025016
114-0532-0	JR25RK-24S	24	27.9	M30 x 1	27	35	29	CNR01SRF025024
114-0559-7	JR25RK-4S	4	27.9	M30 x 1	28	35	29	—
114-0561-9	JR25RK-5S	5	27.9	M30 x 1	27.8	35	29	—
114-0563-4	JR25RK-8S	8	27.9	M30 x 1	27.8	35	29	—