


Product selected: Sylproof Superia PC T8 26mmØ 1x36W lamp with B2 ballast PC

Moisture proof diffuser luminaire. Housing made of polycarbonate. Colour light grey. With top and fitting end cut outs for mains supply and further wiring as well as for through wiring by means of heat resistant internal wiring. Injection mulded diffuser with internal prism for even lighting distribution. Diffuser fixed to the body by using stainless steel clips. Inject gasket for high IP rate. Aluminium reflector. Gear tray made of steel, saved by maintenance cord. D-Mark for electronic ballast version. Polyurethane seal gasket

Product Image




Product Line Drawing

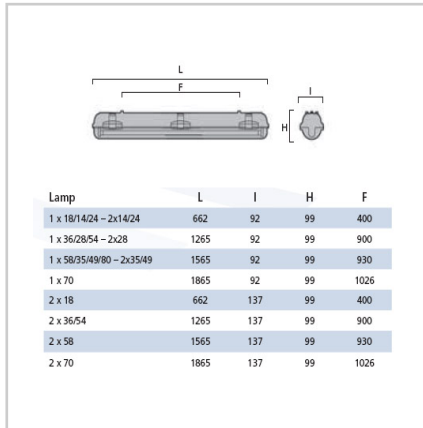

Lamp(s)



Light distribution

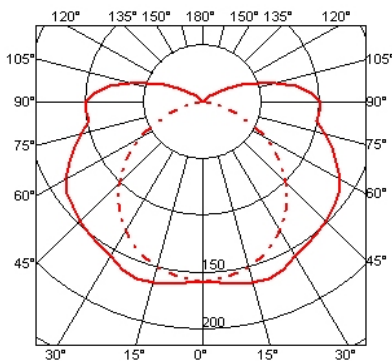

Product Details

Order code	0056135
Item name	Sylproof Superia PC T8 26mmØ 1x36W lamp with B2 ballast PC
Mounting	Ceiling pendant, Ceiling surface
Technical description	Parallel compensated. Polycarbonate body & diffuser. Stainless steel fixing
Place of use	Interior
Colour	Grey
Length (mm)	1265
Width (mm)	92
Height (mm)	99
Weight (kg)	2.4
Housing	Polycarbonate
Shock resistance	2 J
Distribution type	Symmetric
Diffuser finish	Prismatic
Diffuser material	Polycarbonate
LOR (%)	74%
Reflector finish	Aluminium
Reflector material	Polycarbonate
Lamps description	1 x 36W T26 G13
Lamp included	No
Number of heads	1
Control gear availability	Included
Control gear type	Magnetic
Control gear description	Magnetic ballast with low losses
Control gear mounting	Integral
T Class Max	+25°C
T Class Min	-20°C
Voltage (V)	230

Certifications

