



HIRSCHMANN

A BELDEN BRAND

Product information GDML 2011 LED 24 GB grau/grey


Industrial Connecting Solutions:Archive - Industrial Connectors:Rectangular connectors GDM-series (Archive):Type A EN 175301-803 (DIN 43650) / ISO 4400:Cable socket with electronic insert:GDML 2011 LED 24 GB grau/grey

<http://e-catalog.hirschmann.com/link/57078-24228-62529-86162-24310-24314-34930/en/conf/ui/state>

Name		GDML 2011 LED 24 GB grau/grey
		
		LED rectifier with protective circuit (varistor) and function indicator (LED)
Delivery informations		
Availability		available
Product description		
Description		LED rectifier with protective circuit (varistor) and function indicator (LED)
Type		GDML 2011 LED 24 GB grau/grey
Order No.		932 501-003
Other standard types		transparent housing, cable gland black: Order no. 932 501-002
Number of contacts		2 + PE
Cable gland		PG 11 (grey)
Conductor size		max. 1.5 mm ²
Standard		DIN EN 175 301-803-A
Housing Color		transparent
Construction type		A
Description of Wiring		
LED color		LED red
Voltage rectifier		for LED
Suppressor		varistor
Technical data		
Pin dimensions		6.3 mm x 0.8 mm, 4.8 mm x 0.8 mm
Rated voltage		AC/DC 24 V
Rated current		8 A
Contact resistance		<= 4 mOhm
Type of termination		screw
Suitable cables		4.5 mm to 11 mm diameter
Mounting		central nut
Material		
Contact surface material		Sn
Contact bearer material		PA
Housing material		PA
Environmental conditions		
Protection class (IEC 60529)		IP 65 (gasket necessary)
Pollution severity		3
Temperature range		-40 °C to +90 °C
Inflammability class		
Housing		94 HB
Contact bearer		94 HB
Packing unit		
Packaging unit		50 pieces
Scope of delivery and accessories		
Accessories to order separately		(NBR) flat gasket GDM 3-7, Order no. 730 801-002; (EPDM) flat gasket GDM 3-21, Order no. 731 739-004; profiled gasket GDM 3-16, Order no. 731 531-002; knurled screw GDM 3011-8, Order no. 732 574-001; stainless steel screw GDM 3011 RF-1, Order no. 734 363-001

Picture

Drawing

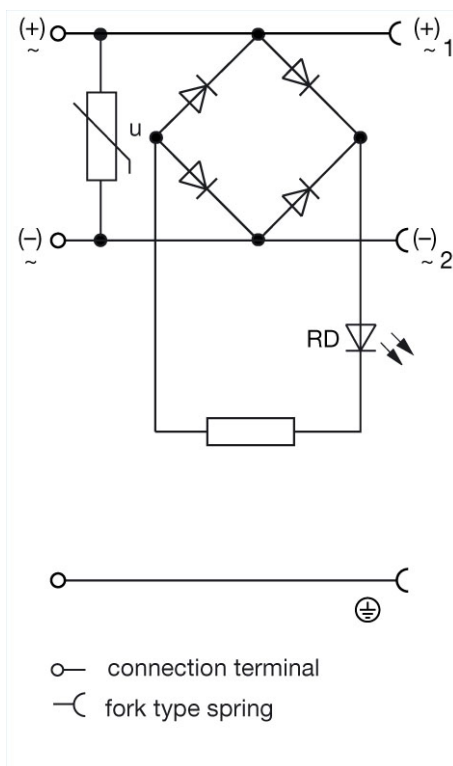

Belden Deutschland GmbH

Im Gewerbepark 2
58579 Schalksmühle
Germany
Phone: +49 7127/14-1806
E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.