


78 91 125

Electronic Super Knips®



- Precision pliers for ultra fine cutting work, e. g. in electronics and fine mechanics
- Ground, very sharp cutting edges without bevel
- Shear cut with controlled micro cutting edge misalignment for the most precise cutting of even the thinnest of wires and for a long service life
- Precision shaped tips cut wires resting on a board from 0.2 mm dia.
- Joint with stainless steel rivet
- Extremely smooth movement for minimum operator fatigue
- With opening spring and opening limiter
- Precision ground cutting edges with very small bevel suitable also for hard wire
- With lead catcher - no uncontrolled loss of cut wire ends
- Cutting edges additionally induction hardened, cutting edge hardness approx. 64 HRC
- Special tool steel, burnished

Article No.	78 91 125
EAN	4003773061595
Pliers	burnished
Handles	with multi-component grips
Style	9
Head	
Cutting capacities medium hard wire (diameter) Ø mm	1,2
Cutting capacities hard wire (diameter) Ø mm	0,6
Cutting capacities soft wire (diameter) Ø mm	0,2 - 1,6
D mm	7,5
B mm	9,0
A mm	13,5
Length mm	125
Net weight g	57

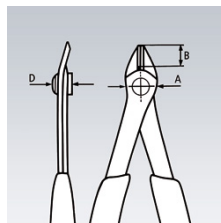

technical change and errors excepted

