

ITT 3000 W 400 V-0826 K

HALOTHERM | Infrared halogen lamps with white reflector



Areas of application

- Manufacture of PET bottles
- Coil coating
- Professional grills and heated counters in restaurants

Product benefits

- High efficiency
- Precise controllability
- Long lamp life
- Short response time



Technical data


Electrical data

Nominal wattage	3000.00 W
Nominal voltage	400 V
Nominal current	7.5 A
Lamp current	7.50000 A
Construction voltage	400 V

Photometrical data

Color temperature	2500 K
-------------------	--------

Dimensions & weight

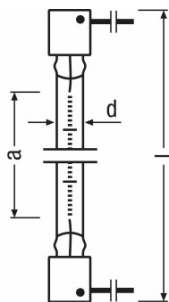

Diameter	11.0 mm
Length	351.0 mm
Filament length	285.00 mm
Cable length	200.0 mm

Lifespan

Lifespan	5000 h
----------	--------

Additional product data

Base (standard designation)	K9x15/21
Connector: Presence	Yes

Capabilities

Burning position	p15
------------------	-----

Country specific information

Product datasheet

Product code	METEL code	SEG-No.	STK-Number	UK Org
4008321206312	OSRHALOTT3000826	-	-	-

Product datasheet

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4008321206312	ITT 3000 W 400 V- 0826 K	Folding carton box 1	378 mm x 26 mm x 26 mm	0.26 dm ³	77.00 g
4008321206329	ITT 3000 W 400 V- 0826 K	Shipping carton box 12	125 mm x 90 mm x 395 mm	4.44 dm ³	1021.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.