

Verbatim LED Classic A B22 6W 2700K Warm White 480 LM

- B22 Socket
- 220 - 240 V Voltage
- 20,000 hours Lifetime
- 85% Energy Saving
- Luminous Flux: 480
- Equivalent to 40W incandescent bulb

Product Number 52619

General Data

Lamp Socket B22

Electric Data


Wattage (W) 6
Wattage Equivalent (W) 40
Voltage (V) 220 - 240 V
Dimmable no
Power Factor 0.75
Operating Frequency (Hz) 50-60

Geometric Data

Length (mm) 115.5
Diameter (in mm) 60
Weight (g) 76


Photometric Data

Luminous Flux (lm) 480
CRI ≥ 80
CCT (K) 2700
Beam Angle ($^{\circ}$) 220
Luminous Efficacy (lm/W) 80
Lifetime (hrs) 20,000
Switching Cycle 100,000

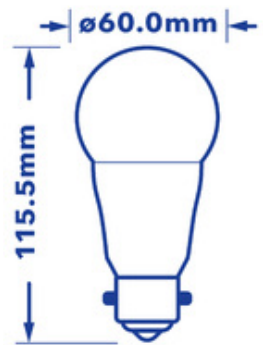

16/07/2014

Energy Rating

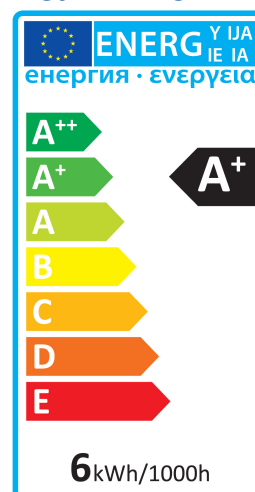Technical Packaging
Details**Barcode**

023942526193

EAN 128

(02)00023942526193(37)04(91)204

EAN 14

50023942526198

Pack Dimensions(HxWxL)

178 x 118 x 61 (mm)

MOQ

4

Carton Dimensions (HxWxL)

195 x 144 x 253 (mm)

Cartons/Pallet

80

Layers/Pallet

4

Units/Pallet

320

16/07/2014