



Compact design delivering up to 120dB the Symphoni High Output provides an ideal solution to your signalling challenges. Producing levels of up to 120dB(A) this sounder can be used in open areas or in situations having higher than normal background noise levels. Despite its high output the unit is efficient and offers relatively low current consumption.

An IP66 rated WP version is also available.


Features

- High output up to 120dB(A)
- Two stage alarm
- 32 tones (user selectable)
- Weatherproof option

Benefits

- Ideal for high noise environments
- Alert and alarm function
- 6 tones certified for fire use
- Suitable for outdoor use


Dimensions

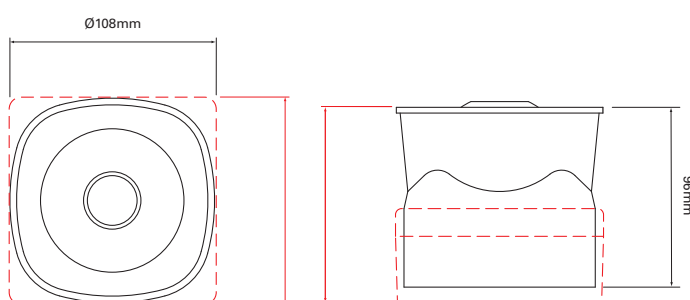

Technical Specification

Voltage	18 - 28Vdc
Current	240mA (Typical Tone 3)
Sound Output	114dB(A) (Typical Tone 3) 120dB(A) (Typical Tone 6)
Tones	32
Volume Control	20dB
Monitoring	Reverse polarity
Temperature	- 10°C to + 55°C - 25°C to + 70°C (WP)
Protection	IP21C, IP66 (WP)
Construction	ABS, PC lens
Weight	0.58Kg, 0.68Kg (WP)
Colours	Red or white

WP version white

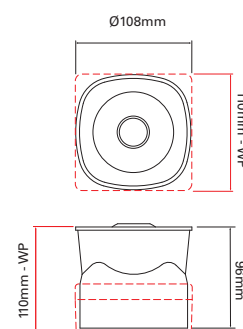

Catalogue Numbers

Reference	Cat No	Description
SY/HO/R	651004FULL-0009X	Symphoni High Output Sounder, Red Body
SY/HO/W1	651003FULL-0008X	Symphoni High Output Sounder, White Body
SYHO/R/IP	651012FULL-0057X	Symphoni High Output Sounder, Red Body, IP66 Version
SYHO/GW/IP	650022FULL-1029X	Symphoni High Output Sounder, White Body, WP IP66 Version