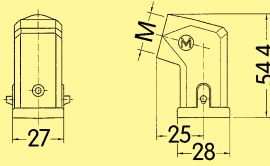
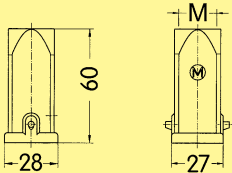
 
 
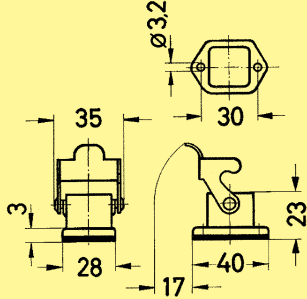


## Metal hoods/housings for industrial applications / 1 lever locking system

| Identification                 |                                                                                     | Part number                                                                                 | Cable entry<br>metric | Drawing                                                                              | Dimensions in mm |
|--------------------------------|-------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------|-----------------------|--------------------------------------------------------------------------------------|------------------|
| Hoods<br>side entry            |    | <b>19 20 003 1640</b>                                                                       | <b>1 x 20</b>         |    |                  |
| Hoods<br>top entry             |    | <b>19 20 003 1440</b>                                                                       | <b>1 x 20</b>         |    |                  |
| Hoods<br>top entry             |   | <b>6 ... 12 mm</b><br><b>19 20 003 1421</b><br><b>11 ... 17 mm</b><br><b>19 20 003 1422</b> |                       |   |                  |
| Protection covers<br>for hoods |  | <b>09 20 003 5422<sup>2)</sup></b><br><b>09 20 003 5421<sup>1)</sup></b>                    |                       |  |                  |

## Metal hoods/housings for industrial applications / 1 lever locking system

| Identification                 |                                                                                     | Part number           | Cable entry<br>metric | Drawing                                                                              | Dimensions in mm         |
|--------------------------------|-------------------------------------------------------------------------------------|-----------------------|-----------------------|--------------------------------------------------------------------------------------|--------------------------|
| Housings, bulkhead<br>mounting |  | <b>09 20 003 0301</b> |                       |  | Panel cut out 22 x 22 mm |
|                                |                                                                                     |                       |                       |                                                                                      |                          |

<sup>1)</sup> for mounted female insert  
<sup>2)</sup> for mounted male insert