


Datasheet


Galvanized steel level foot – M12x75

Application areas

- *Lighter engineering machinery*
- *Equipment cabinets*
- *Office machines*
- *Domestic appliances*

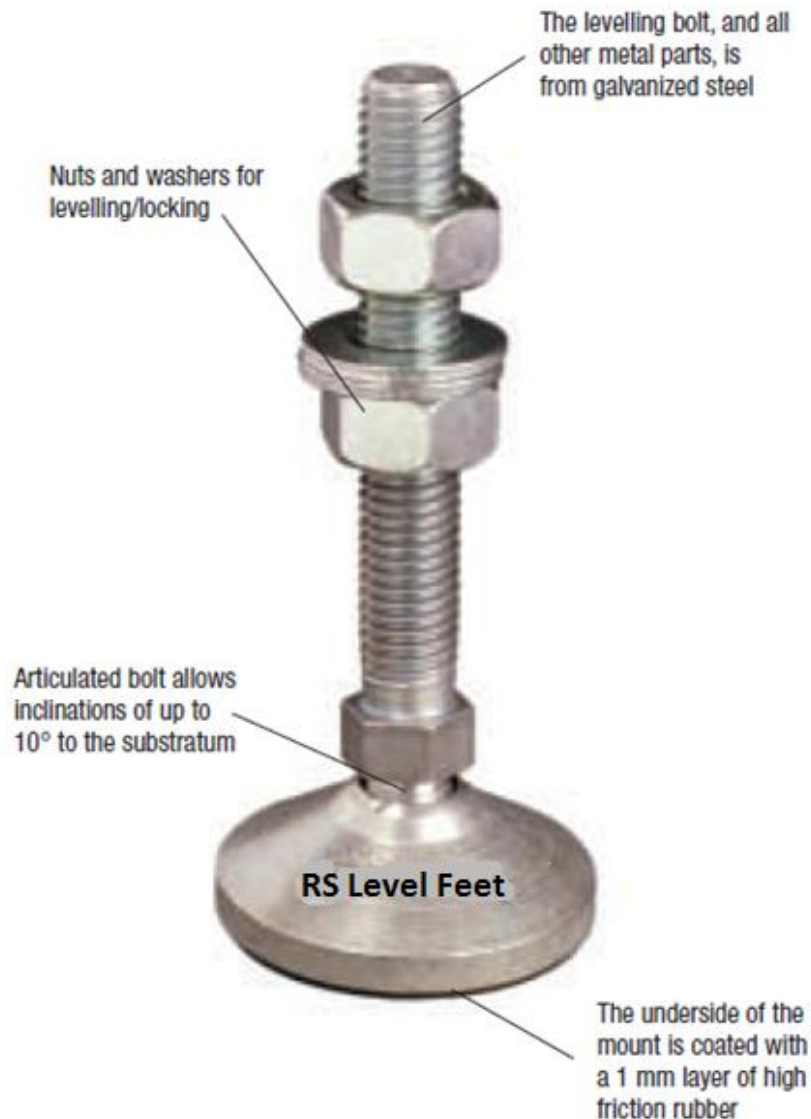

- *Articulated bolt allows inclinations of up to 10° to the substratum*
- *With anti-slip protection for stable installation*
- *Made from galvanized steel*

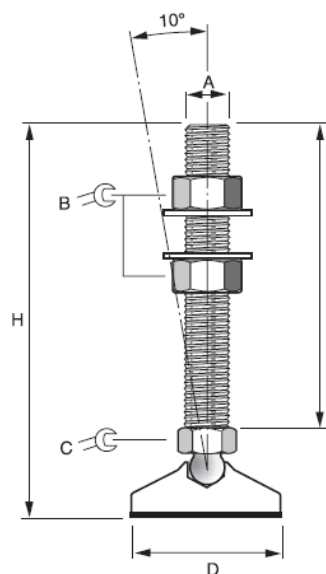

Max load per mount* daN (kg)	D mm	H mm	H mm	B mm	C mm	A** mm
---------------------------------	---------	---------	---------	---------	---------	-----------

1200	45	105	75	19	14	M12
------	----	-----	----	----	----	-----

This level foot is a machine mount that is specially designed to provide stable levelling of lighter equipment such as engineering machines, equipment cabinets, office machines and domestic appliances.

The level foot consists of a galvanized levelling screw with an articulated foot that allows inclinations of up to 10° to the substratum. The underside of the mount is coated with a thin friction mat of specially treated nitrile rubber that guarantees stable installation on most surfaces in normal conditions.