


Capacitor, tantalum, 10 uF, 7343, +/-10% Tol, 50V@85C

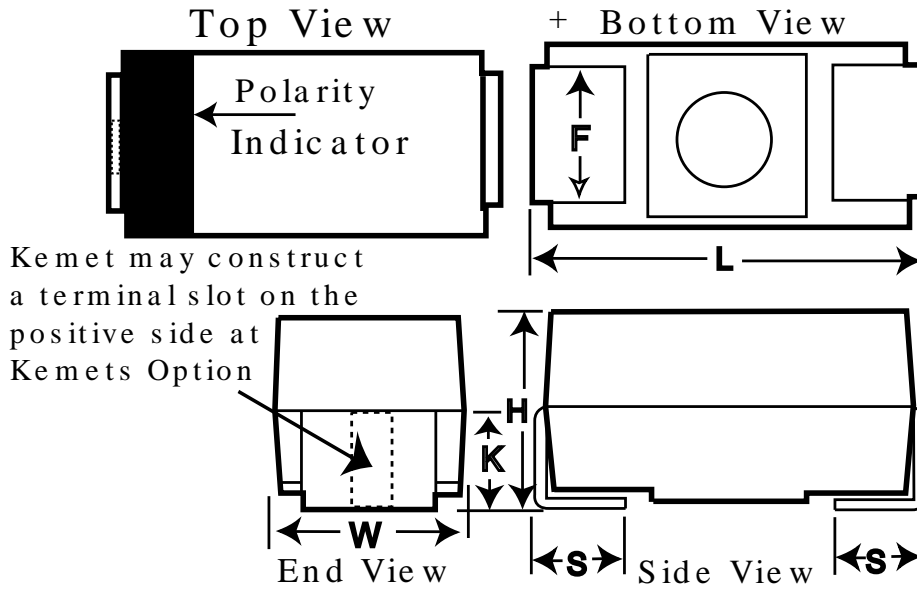

**Dimensions (mm)**

**Specifications**

ID	Dimension	Tolerance	Manufacturer:	KEMET
L	7.3	+/-0.3	Capacitance:	10 uF
W	4.3	+/-0.3	Voltage DC @ 85C:	50V
H	4.1	+/-0.3	Voltage DC @ 105C:	41.5V
K	1.8	nom	Voltage DC @ 125C:	33V
F	2.4	+/-0.1	Tolerance:	+/-10%
S	1.3	+/-0.3	Application:	Low ESR
			Body Type:	Molded Chip
			Temperature Range:	-55/+125C
			ESR:	300 mOhm
			Footprint:	7343
			Termination:	Tin
			Leakage Current:	5 uA
			Dissipation Factor:	6%
			Ripple @ 25C:	0.74 A
			Ripple @ 85C:	0.666 A
			Ripple @ 125C:	0.296 A
			Package Kind:	T&R
			Package Quantity:	400

Notes:

-E