




# Elite 303 Cabinet


## Schematics Drawings

ELITE  
303  
CABINET

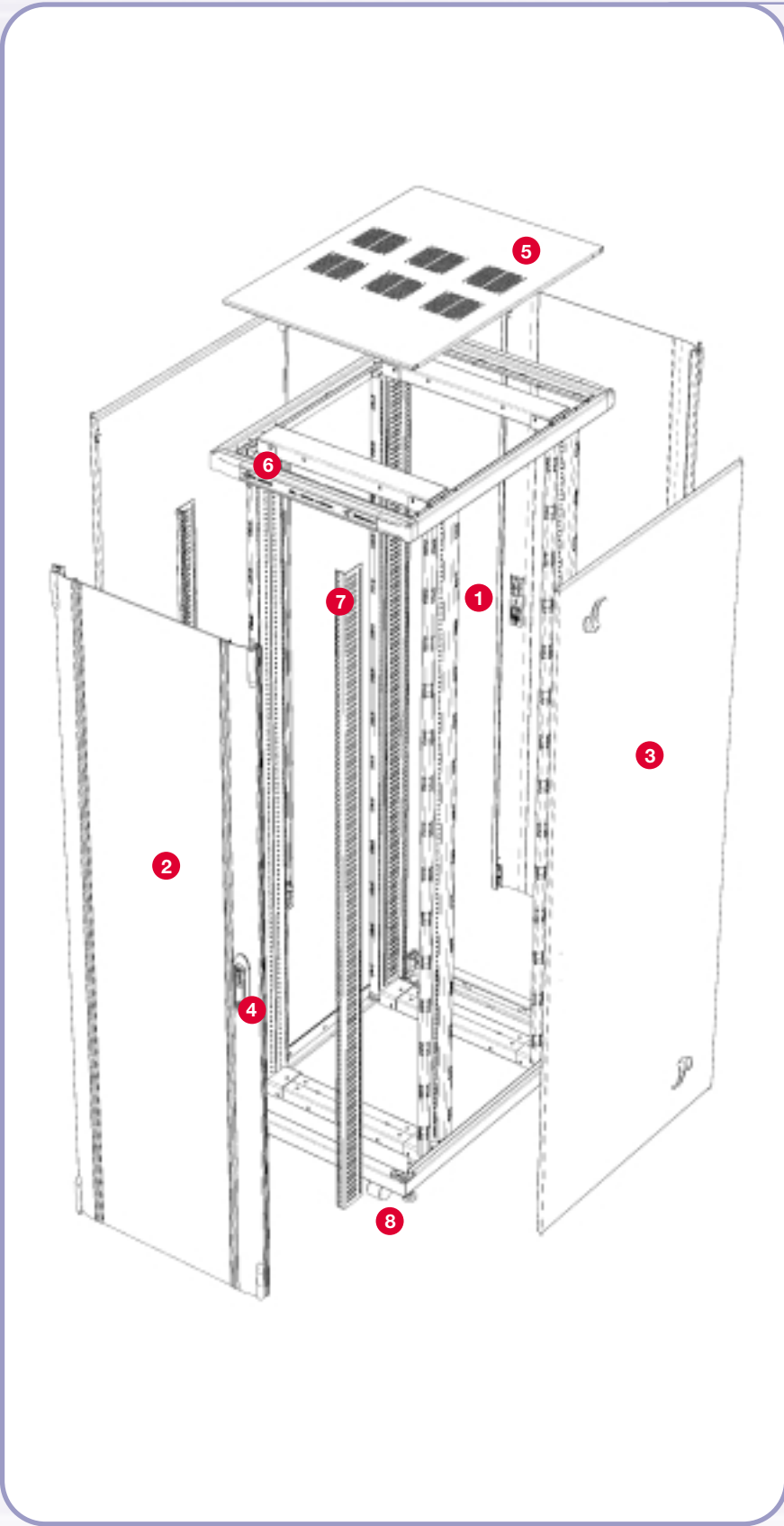

### Elite Cabinet

Description	page
1 Frame	21
2 Glass and steel doors	22
Vented glass and steel doors	22
3 Side doors	24
4 Lock options	24 & 57
5 Top covers	25
6 Labelling service	26
7 19" mounting angles	27
8 Castors and Leveling feet	35

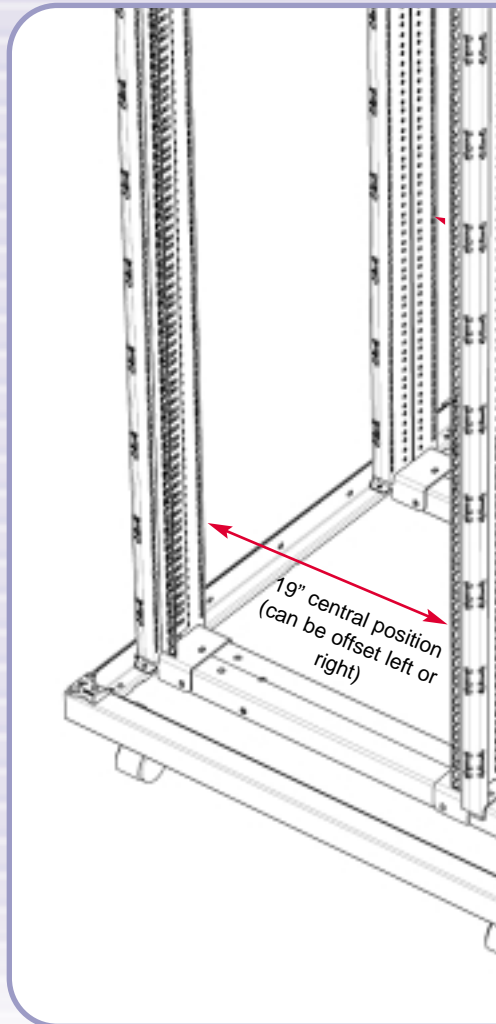

19" central position  
(can be offset left or right)



### Elite Frame



#### Description

- 1 Trimmed end frame x 1
- 2 Plain end frame x 1
- 3 Cross-member x 4
- 4 Universal mounting upright x 4
- 5 Castors braked x 4

### 800 Wide Frame

#### Description

- ☞ Optional settings for Universal Mounting Upright
- ☞ Standard 19" central
- ☞ Full width
- ☞ Left or right offset 19"

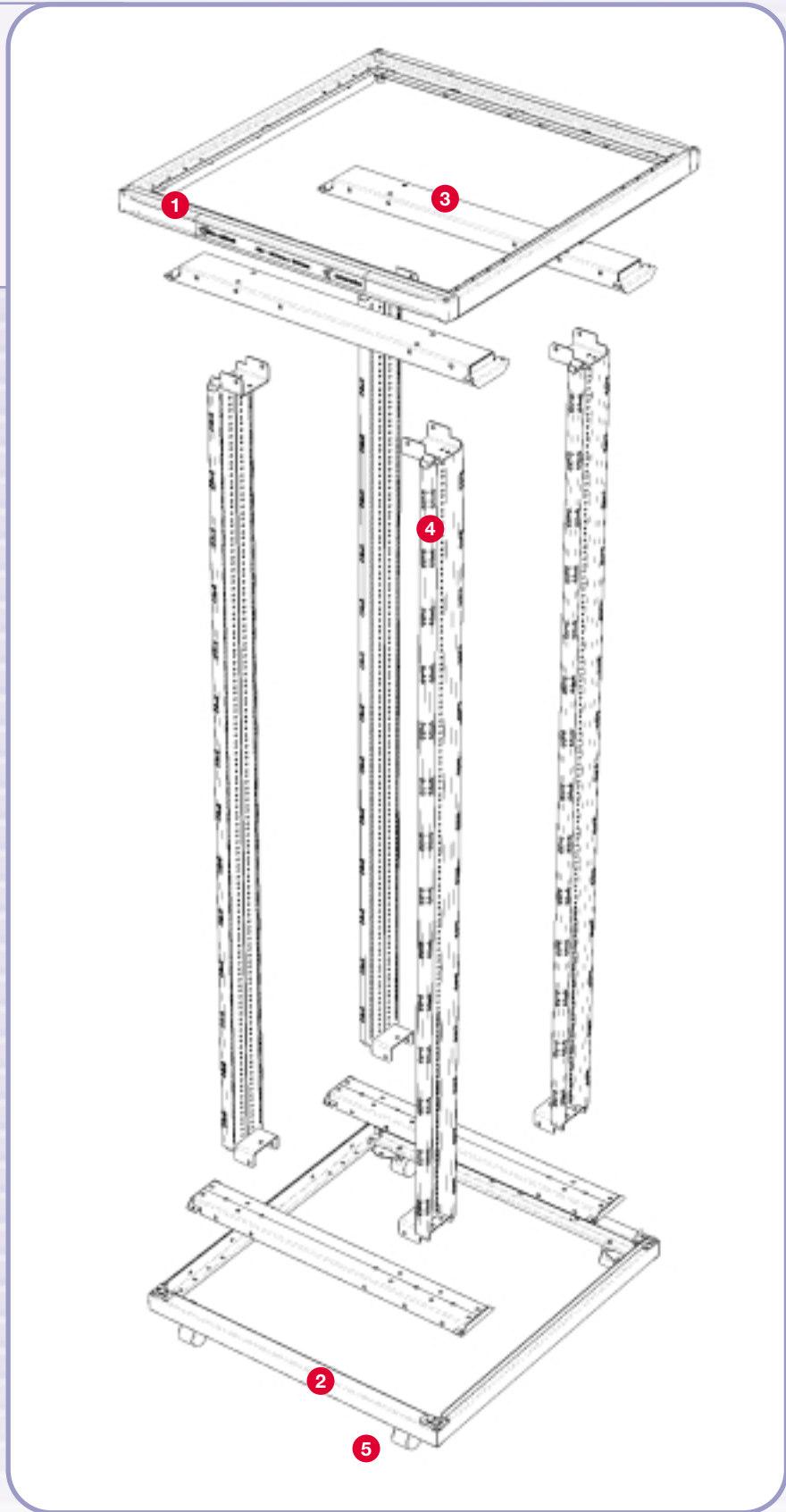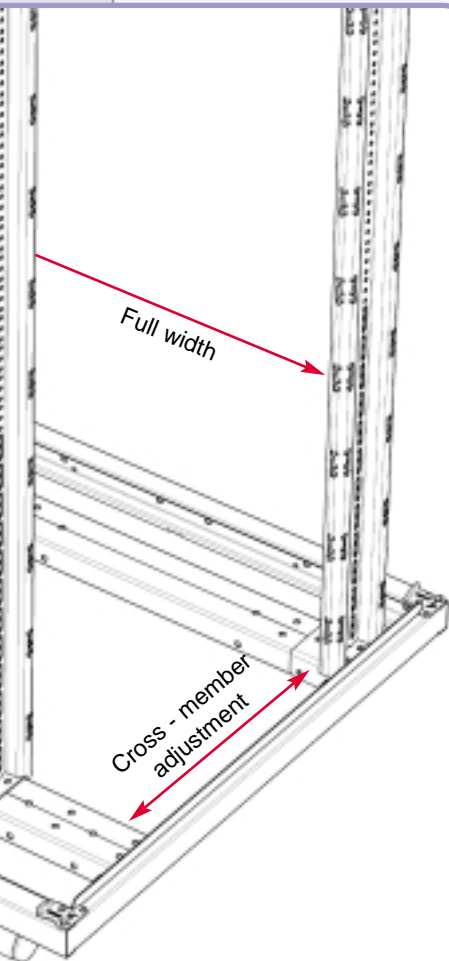




# Elite 303 Cabinet

## Technical Information


E  
L  
I  
T  
E

### Plan View of Plain Endframe, Cross Members & Universal Mounting Uprights

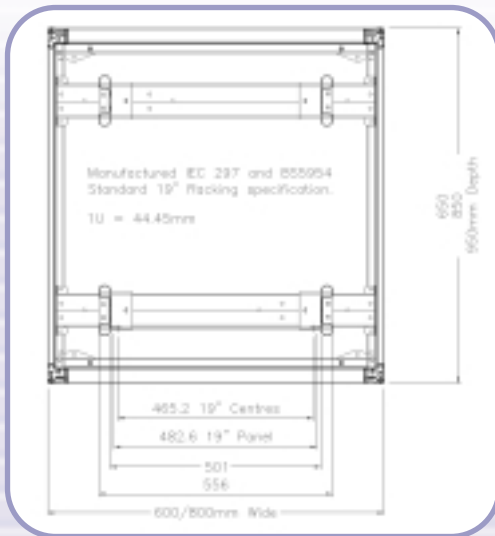

3  
0  
3

C  
A  
B  
I  
N  
E  
T

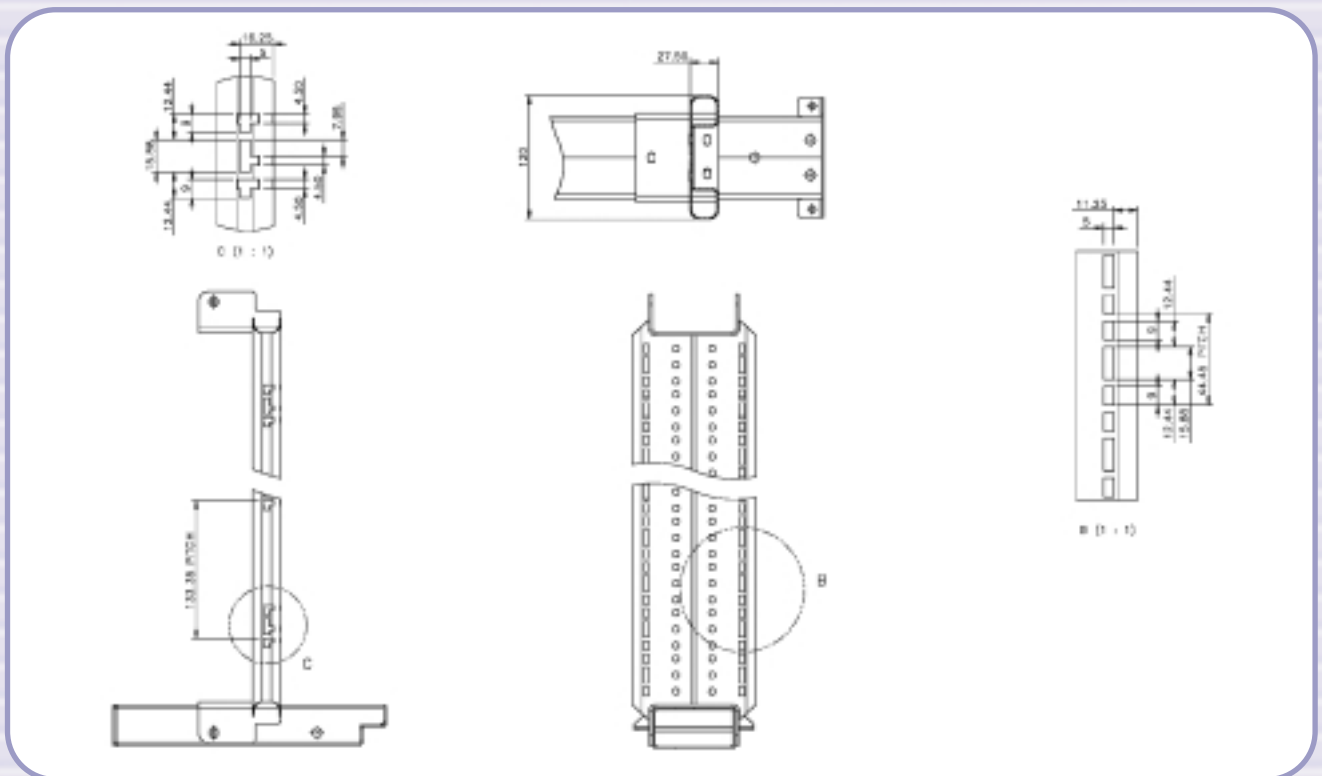

### Castor & Levelling Feet Matrix

Description	Height	Diameter	Weight loading
Transport castor	54mm	50mm	60kg each
Light duty castor	54mm	50mm	60kg each
Medium duty castor	104mm	80mm	120kg each
Heavy duty castor	128mm	100mm	180kg each
Plinth levelling foot	70mm	37.5mm foot	750kg each static load
Levelling foot	100mm	37.5mm foot	750kg each static load

### Height Matrix

U height	Overall height
12U	640mm
18U	908mm
24U	1175mm
30U	1440mm
36U	1708mm
42U	1975mm
48U	2240mm

# Elite 303 Cabinet

Standard Build



## Elite Cabinet 600mm wide

Unrivalled 600 wide cabinet characterised by its open structure and its modern classic styling. The only cabinet available on the market to boast totally unique purpose designed cable management as an optional feature amongst its many other unique attributes.

### Glass front door fitted <sup>z</sup>

#### Contents:

- 1 x Frame
- 1 x Steel door <sup>z</sup>
- 1 Pair side doors
- 1 x Glass door <sup>z</sup>
- 1 x 19" Mounting angles (fitted to front)
- 1 x Vented top cover
- 1 x Transport castors (all braked)

#### Ordering Codes

Height	650mm deep	850mm deep
12U	FS1-012-300	FS1-112-300
18U	FS1-018-300	FS1-118-300
24U	FS1-024-300	FS1-124-300
30U	FS1-030-300	FS1-130-300
36U	FS1-036-300	FS1-136-300
42U	FS1-042-300	FS1-142-300
48U	FS1-048-300	FS1-148-300


### Steel front door fitted <sup>z</sup>

#### Contents:

- 1 x Frame
- 2 x Steel door <sup>z</sup>
- 1 Pair side Doors
- 1 x 19" Mounting angles (fitted to front)
- 1 x Vented top cover
- 1 x Transport castors (all braked)

#### Ordering Codes

Height	650mm deep	850mm deep
12U	FS1-612-300	FS1-712-300
18U	FS1-618-300	FS1-718-300
24U	FS1-624-300	FS1-724-300
30U	FS1-630-300	FS1-730-300
36U	FS1-636-300	FS1-736-300
42U	FS1-642-300	FS1-742-300
48U	FS1-648-300	FS1-748-300

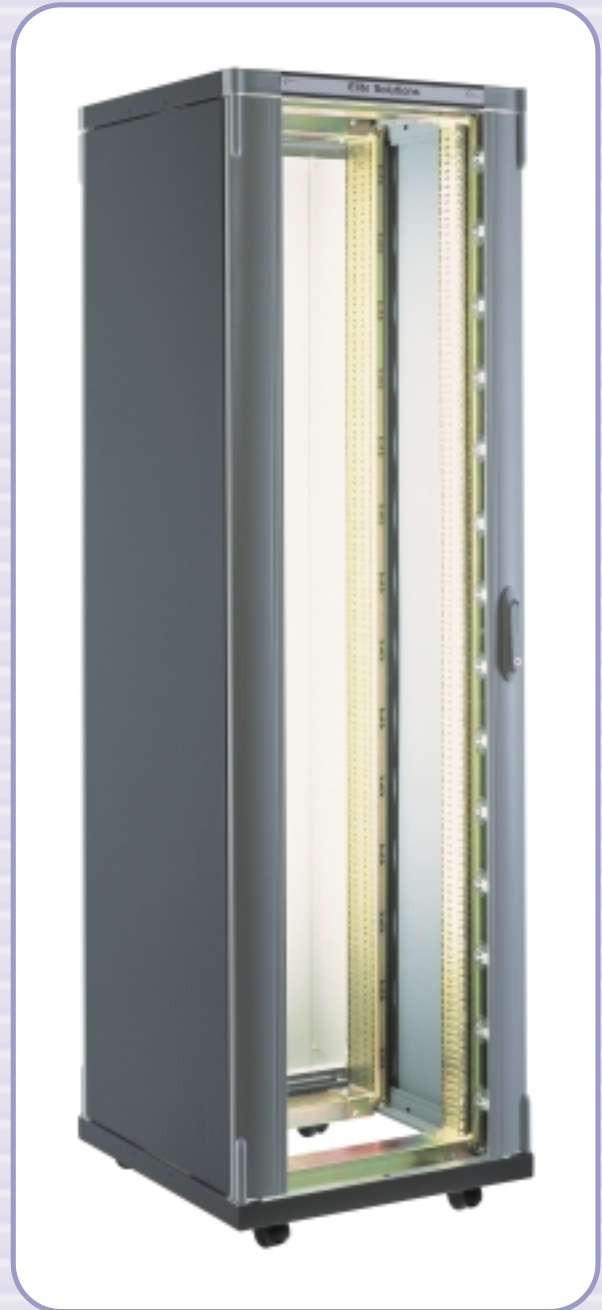

ELITE 303 CABINET

<sup>z</sup> left hand hinged as standard - please specify if right hand is required at time of placing order



# Elite 303 Cabinet

Standard Build

## Elite Cabinet 800mm Wide

The 800 wide cabinet - boasting the same classic styling and multifunctional frame as the 600 version, Full advantage can be taken of the additional space that is provided by the 800 frame, by using the purpose designed cable management arms.



☞ Supports best cabling practice

☞ Modular and adaptable

☞ Forward or side facing

☞ Quick and easy to fit

☞ No additional fixings required

## Standard Build

### Contents:

- 1 x Frame
- 1 x Glass or Steel front door <sup>Z</sup>
- 1 x Steel rear door <sup>Z</sup>
- 1 Pair side doors
- 1 x 19" Mounting angles (fitted to front)
- 1 x Vented top cover
- 1 x Transport castors (all braked)

**NB:** Cable management not included in standard build, please see below for ordering details

## Glass Front Door Fitted <sup>Z</sup>

### Ordering codes:

Height	650mm deep	850mm deep
12U	FS1-212-300	FS1-312-300
18U	FS1-218-300	FS1-318-300
24U	FS1-224-300	FS1-324-300
30U	FS1-230-300	FS1-330-300
36U	FS1-236-300	FS1-336-300
42U	FS1-242-300	FS1-342-300
48U	FS1-248-300	FS1-348-300

## Steel Front Door Fitted <sup>Z</sup>

### Ordering codes:

Height	650mm deep	850mm deep
12U	FS1-812-300	FS1-912-300
18U	FS1-818-300	FS1-918-300
24U	FS1-824-300	FS1-924-300
30U	FS1-830-300	FS1-930-300
36U	FS1-836-300	FS1-936-300
42U	FS1-842-300	FS1-942-300
48U	FS1-848-300	FS1-948-300

**NB:** Cable management not included in standard builds, please see below for ordering details.

## Elite 50mm & 100mm Cable Management Arms

**NB:** When ordering cabinet please specify if vertical cable management is required.

50mm	100mm
1 x Set complete Arm GA1-170-000	1 x Set complete Arm GA1-173-000

Number of cable management sets required per pair of uprights based on U height of cabinet.

1 set = 4 cable management arms.

Height	Recommended sets (per pair of uprights)	Maximum sets per pair of uprights
12	1	2
18	2	3
24	3	4
30	4	5
36	5	6
42	6	7
48	7	8

<sup>Z</sup> left hand hinged as standard - please specify if right hand hinged required at time of placing order

# Elite 303 Cabinet

Customer Configured Cabinets



E L I T E 3 0 3 C A B I N E T

## How to Order a Configured Cabinet

To order your customer configured cabinet simply start with the footprint and height frame required and then select the appropriate options and accessories from the following pages.

Frame		Options		Accessories	
Description	Pages	Description	Pages	Description	Pages
Frame	21	Doors	22-24	Mounting angles	27
		Door Locks/security	24 & 57	Depth support rail	27
		Brush entry panel	24	Shelving & associated products	27-32
		Top covers	25	Earth kits	33
		Fan units/Thermal options	58-61	Document wallets	33
		Personalised label	26	Plinths	34
				Castors	35
				Cable management	36-38
				Blanking panels	39
				Fixings	39

### Elite Frame

A robust bolted construction using minimal fixings, offering totally unrestricted access with the added advantage of fully adjustable uprights.

#### Contents:

- 4 x Universal mounting uprights zinc plate and yellow passivate to BSEN 12329
- 4 x Cross members zinc plate and yellow passivate to BSEN 12329
- 1 x Trimmed end frame complete with corner and middle label trims
- 1 x Plain end frame
- 1 x Set M6 x 12mm AF
- 1 x Set transport castors (braked)

**NB:** 19" Mounting Angles not included see pages 27 for ordering details.




#### Ordering codes:

Height	600 wide			800wide		
	650mm deep	850mm deep	950mm deep	650mm deep	850mm deep	950mm deep
12U	FS2-012-314	FS2-112-314	N/A	FS2-212-314	FS2-312-314	N/A
18U	FS2-018-314	FS2-118-314	N/A	FS2-218-314	FS2-318-314	N/A
24U	FS2-024-314	FS2-124-314	N/A	FS2-224-314	FS2-324-314	N/A
30U	FS2-030-314	FS2-130-314	FS2-430-314	FS2-230-314	FS2-330-314	FS2-530-314
36U	FS2-036-314	FS2-136-314	N/A	FS2-236-314	FS2-336-314	N/A
42U	FS2-042-314	FS2-142-314	FS2-442-314	FS2-242-314	FS2-342-314	FS2-542-314
48U	FS2-048-314	FS2-148-314	FS2-448-314	FS2-248-314	FS2-348-314	FS2-548-314


When configuring cabinet build please specify which position you require the cross members to be

Default position

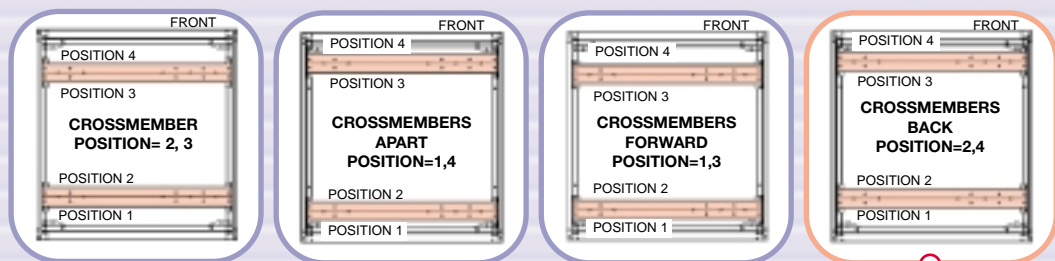

When configuring an 800wide please specify positioning of universal mounting uprights

Default position

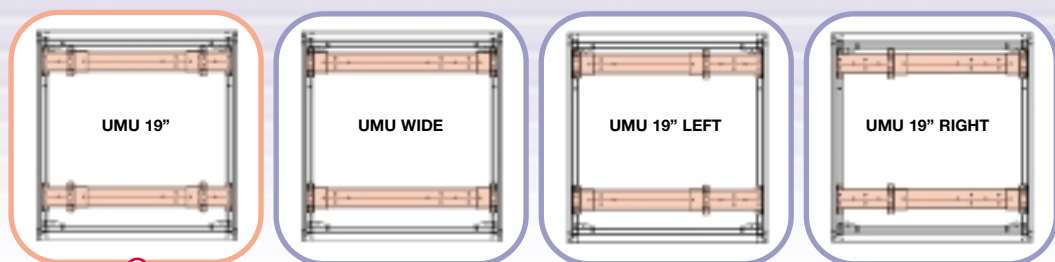



# Elite 303 Cabinet

## Options

ELITE 303 CABINET



### Glass & Steel Doors <sup>z</sup>

Stylised extra wide radius door trim to conceal patch cables. Inclusive of modular swing handle 2-point locking system and specially designed quick release door pins.

**Contents:**

- 1 x Steel door<sup>z</sup>, 1.2 mm steel, colour goose grey to BS4800 00A05
- 1 x Glass door<sup>z</sup>, 4mm clear toughened glass, extruded aluminium trim colour goose grey to BS4800 00A05
- 2 x Hinges
- 1 x Modular swing handle incorporating 2 point locking system complete with 2 keys


**Order code:**

Height	Glass	
	600mm wide	800mm wide
12 U	DA1-041-311	DA1-061-311
18 U	DA1-042-311	DA1-062-311
24 U	DA1-043-311	DA1-063-311
30 U	DA1-044-311	DA1-064-311
36 U	DA1-045-311	DA1-065-311
42 U	DA1-046-311	DA1-066-311
48 U	DA1-047-311	DA1-067-311



**Order code:**

Height	Steel	
	600mm wide	800mm wide
12 U	DA1-160-311	DA1-167-311
18 U	DA1-161-311	DA1-168-311
24 U	DA1-162-311	DA1-169-311
30 U	DA1-163-311	DA1-170-311
36 U	DA1-164-311	DA1-171-311
42 U	DA1-165-311	DA1-172-311
48 U	DA1-166-311	DA1-173-311

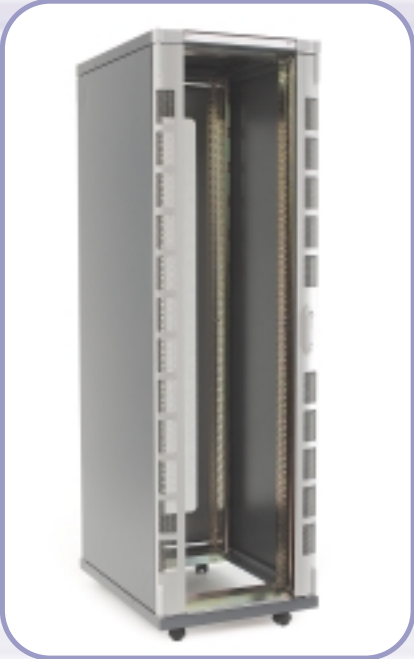

### Vented Glass & Steel Doors <sup>z</sup>

Ingenious design allows through put of air over and around housed equipment. Stylish radius doors enable cabling to remain concealed without compromise to performance. modular swing handle 2-point locking system and specially designed quick release door pins.

**Contents:**

- 1 x Steel door<sup>z</sup>, Meshed insert panels 1.2mm steel, colour goose grey to BS4800 00A05
- 1 x Glass door<sup>z</sup>, 4mm clear toughened glass, extruded aluminium trim colour goose grey to BS4800 00A05 extruded aluminium trim meshed insert panels
- 2 x Hinges
- 1 x Modular swing handle incorporating 2 point locking system complete with 2 keys

**Ordering codes:**

Height	Steel		Glass	
	600mm wide	800mm wide	600mm wide	800mm wide
30 U	DA1-139-311	DA1-142-311	DA1-001-311	DA1-004-311
42 U	DA1-140-311	DA1-143-311	DA1-002-311	DA1-005-311
48 U	DA1-141-311	DA1-144-311	DA1-003-311	DA1-006-311

See page 24 or 57 for alternative lock options.

<sup>z</sup> left hand hinged as standard - please specify if right hand hinged required at time of placing order

# Elite 303 Cabinet



## Double Doors

Vertically split doors in the 'wardrobe style' - completely removable using our time saving quick release hinges.

### Contents:

1 Pair steel doors 1.2 mm steel, colour goose grey to BS4800 00A05

or

1 Pair glass doors, 4mm clear toughened glass, extruded aluminium trim colour goose grey to BS4800 00A05

2 x Hinges

1 x Modular swing handle and 2 point locking system complete with 2 keys

1 x Glass doors, 4mm clear toughened glass, extruded aluminium trim colour goose grey to BS4800 00A05

1 x Modular swing handle incorporating 2 point locking system complete with 2 keys

### Ordering codes:

Height	Steel		Glass	
	600mm wide	800mm wide	600mm wide	800mm wide
30 U	DA1-150-311	DA1-153-311	DA1-070-311	DA1-073-311
42 U	DA1-151-311	DA1-154-311	DA1-071-311	DA1-074-311
48 U	DA1-152-311	DA1-155-311	DA1-072-311	DA1-075-311



## Stable Doors <sup>z</sup>

Horizontally split doors in the 'stable door' style - completely removable using our time saving quick release hinges.

### Contents:

1 x Steel door<sup>z</sup>, colour goose grey to BS4800 00A05 1.2mm steel

2 x Hinges

1 x Modular swing handle incorporating 2 point locking system complete with 2 keys

1 x 1U divider, colour slate grey to RAL7015

### How to configure stable doors

Follow this simple formula

e.g. 12U Glass door (standard glass door sizes, see page 22)  
 + 29U Steel door (see table below for range of sizes available)  
 + 1U Door divider  
 = 42U Cabinet

### Ordering codes:

Height	Steel door + (1U) divider	
	600mm wide	800mm wide
11 U + 1U	DA1-123-311	DA1-128-311
17 U + 1U	DA1-124-311	DA1-129-311
23 U + 1U	DA1-125-311	DA1-130-311
29 U + 1U	DA1-126-311	DA1-131-311
35 U + 1U	DA1-127-311	DA1-132-311



See page 24 or 57 for alternative lock options.

<sup>z</sup> left hand hinged as standard - please specify if right hand hinged required at time of placing order

E  
L  
I  
T  
E  
  
3  
0  
3  
  
C  
A  
B  
I  
N  
E  
T



# Elite 303 Cabinet

Options

ELITE



## Side Doors

Hinged front and rear featuring as standard increased integral security - No locks required, release access via inside of cabinet.

### Contents:

- 1 x Steel door 1.2mm steel, colour slate grey to RAL7015
- 4 x Hinges

### Ordering Codes:

Height	650mm wide	850mm wide	950mm wide
12 U	DA1-101-314	DA1-108-314	N/A
18 U	DA1-102-314	DA1-109-314	N/A
24 U	DA1-103-314	DA1-110-314	N/A
30 U	DA1-104-314	DA1-111-314	DA1-118-314
36 U	DA1-105-314	DA1-112-314	N/A
42 U	DA1-106-314	DA1-113-314	DA1-120-314
48 U	DA1-107-314	DA1-114-314	DA1-121-314

303



## Brush Entry Panel


When top & bottom cable entry is inappropriate this 6U brush panel enables access to both front & rear of the cabinet. Simply order a door 6U shorter than the overall height of cabinet required.

### Contents:

- 1 x 6U steel panel colour goose grey BS 4800 00A05
- 1 x Brackets and fixings

### Ordering Code:

Height	600mm wide	800mm wide
6U	GA1-025-311	GA1-026-311

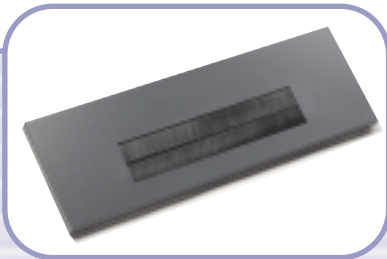

CABINET

## Door lock options

### Ordering Code:

- Euro lock
- Radial lock
- Square lock
- Triangle lock
- Coin lock

Please speak to sales advisor



# Elite 303 Cabinet



E  
L  
I  
T  
E  
  
3  
0  
3  
  
C  
A  
B  
I  
N  
E  
T

## Top Covers

No screws required, clips for quick and easy fit or removal - available in four different options: plain, vented, fan or raised side vented covers. NB: Raised cover version will increase overall height of cabinet by 33mm.


### Top Plain Cover:

#### Contents:

- 1 x Steel Top cover 1.2mm steel, zinc plate and yellow passivate to BSEN 12329
- 4 x Clips

#### Ordering codes:

Depth	600mm wide	800mm wide
650	SM1-250-121	SM1-253-121
850	SM1-251-121	SM1-254-121
950	SM1-252-121	SM1-255-121

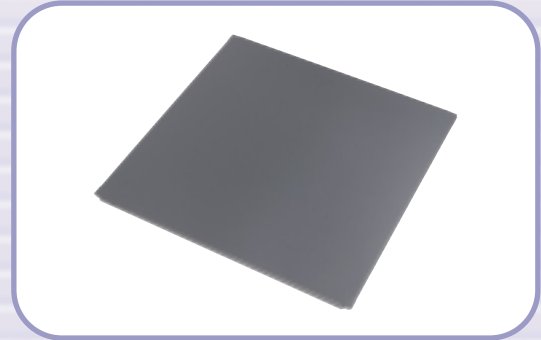


### Top Vented Cover:

#### Contents:

- 1 x Steel Top cover 1.2mm steel, zinc plate and yellow passivate to BSEN 12329
- 4 x Clips

#### Ordering codes:

Depth	600mm wide	800mm wide
650	SM1-256-121	SM1-259-121
850	SM1-257-121	SM1-260-121
950	SM1-258-121	SM1-261-121

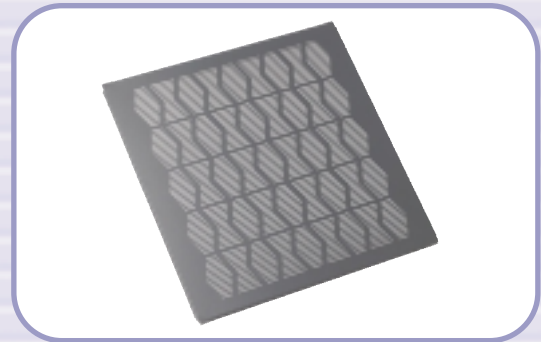

### 240V Top Fan Cover:

(Please see thermal pages 58 to 61 for fan specification)


#### Contents:

- 1 x Steel Top cover 1.2mm steel, zinc plate and yellow passivate to BSEN 12329
- 4 x Clips

#### Ordering codes:

	2 Way		4 Way		6 Way	
	600 wide	800 wide	600 wide	800 wide	600 wide	800 wide
650 deep	EA1-040*	EA1-043*	EA1-046*	EA1-049*	N/A	EA1-055*
850 deep	EA1-041*	EA1-044*	EA1-047*	EA1-050*	N/A	EA1-056*
950 deep	EA1-042*	EA1-045*	EA1-048*	EA1-051*	EA1-054*	EA1-057*

\*To include the type of fan required simply add one of the following suffixes to the above numbers: 240v fans add -021, 48v fans add -022, 110v fans add -023, high speed 240v fans add -024, high speed 110v fans add -025.

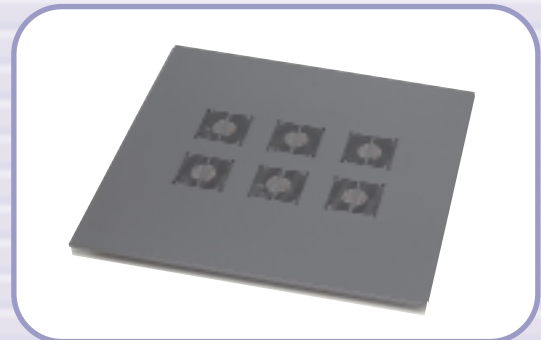

### Thermostatically Controlled Fan Cover

	2 Way		4 Way		6 Way	
	600 wide	800 wide	600 wide	800 wide	600 wide	800 wide
650 deep	EA1-058*	EA1-061*	EA1-064*	EA1-067*	EA1-070*	EA1-073*
850 deep	EA1-059*	EA1-062*	EA1-065*	EA1-068*	EA1-071*	EA1-074*
950 deep	EA1-060*	EA1-063*	EA1-066*	EA1-069*	EA1-072*	EA1-075*

\*To include the type of fan required simply add one of the following suffixes to the above numbers: 240v fans add -021, 48v fans add -022, 110v fans add -023, high speed 240v fans add -024, high speed 110v fans add -025.



# Elite 303 Cabinet

Options

E  
L  
I  
T  
E  
  
3  
0  
3  
  
C  
A  
B  
I  
N  
E  
T



### Top Raised Side Vented Cover

 
 
 
Please note the raised side vented top cover increases the overall height of the cabinet by 33mm.

#### Contents:

- 1 x Steel Top cover 1mm steel, colour slate grey to RAL7015
- 4 x Clips

#### Ordering codes:

Depth	600mm wide	800mm wide
650	SM1-262-121	SM1-265-121
850	SM1-263-121	SM1-266-121
950	SM1-264-121	SM1-267-121



# Elite 303 Cabinet

## Accessories

### Depth Support Rails

Enables 19" mounting angles to traverse throughout the full depth of the cabinet. Also used to support other accessories such as shelves, cable trays, PDU's etc.

#### Contents:

- 1 x Depth support rail
- 1.5mm steel, zinc plate and yellow passivate to BSEN 12329
- 4 x Clips

#### Ordering codes:

To suit cabinet

Depths 650		Depths 850		Depths 950	
180mm	GA1-090-321	380mm	GA1-093-321	480mm	GA1-095-321
230mm	GA1-091-321	430mm	GA1-094-321	530mm	GA1-097-321
280mm	GA1-092-321	480mm	GA1-095-321	580mm	GA1-098-321

Coloured number = *Default Size*

### 19" Mounting Angles

19" Fully adjustable mounting angles - with integral U space indication for quick & easy reference.

#### Contents:

- 1 Pair 19" mounting angles 2mm steel, zinc plate and yellow passivate to BSEN 12329
- 1 x Set M6 fixings

#### Ordering codes:

Height	
1U	GA1-100-321
3U	GA1-101-321
6U	GA1-102-321
12 U	GA1-103-321
18 U	GA1-104-321
24 U	GA1-105-321
30 U	GA1-106-321
36 U	GA1-107-321
42 U	GA1-108-321
48 U	GA1-109-321

### Extended 19" Mounting Angles






Deeper than standard 19" mounting angles, this extended design allows rack mount equipment to maximise full depth of cabinet.

#### Contents:

- 1 Pair mounting angles 2mm steel zinc plate and yellow passivate to BSEN 12329
- 1 x Set fixings

#### Ordering codes:

Height	
12 U	GA1-112-321
18 U	GA1-113-321
24 U	GA1-114-321
30 U	GA1-115-321
36 U	GA1-116-321
42 U	GA1-117-321
48 U	GA1-118-321

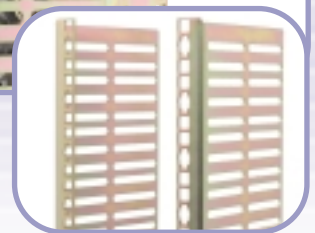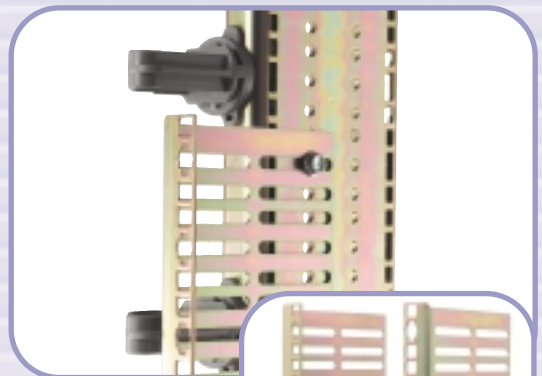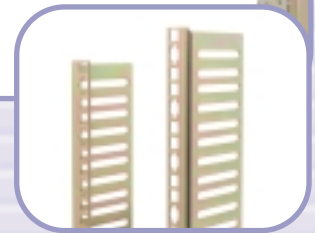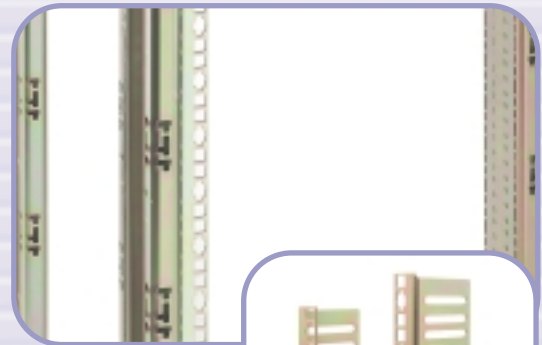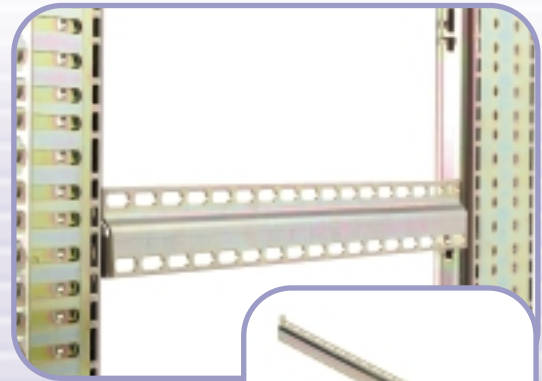

ELITE 303 CABINET



# Elite 303 Cabinet

ACCESSORIES

ELITE

303

CABINET


B

I

N

E

T

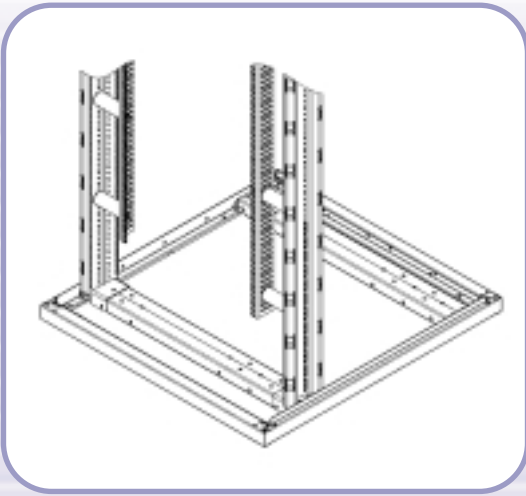

## 800 Wide to 19" Adaptors


When full width and 19" mounts are required within the same cabinet.

### Contents:

- 4 x Adaptors , zinc plate and yellow passivate to BSEN 12329
- 1 x Set fixings

### Ordering codes:

- 1 x Adaptors and fixings GA1-203-321

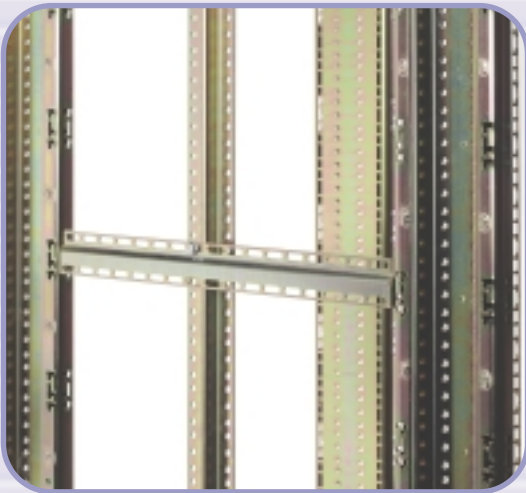

## Mid-Mounting Posts

To be used when mounting different depth shelves and equipment to support different depth equipment.

*NB. When ordering posts you will need to order 2 pairs of depth support rails.*

### Contents:

- 1 Pair mid mounting posts 2mm steel zinc plate and yellow passivate to BSEN 12329
- 1 x Set fixings

### Ordering codes:

Height	
12 U	GA1-120-321
18 U	GA1-121-321
24 U	GA1-122-321
30 U	GA1-123-321
36 U	GA1-124-321
42 U	GA1-125-321
48 U	GA1-126-321

## ETSI Mounting angles

Mounting angles to comply with ETSI standard.

- Please contact sales desk for product and pricing information •

# Elite 303 Cabinet



E  
L  
I  
T  
E  
  
3  
0  
3  
  
C  
A  
B  
I  
N  
E  
T

## 3 into 2 19" Mounting Angles Kit

Kit assists in converting 2 x 800mm cabinets into 1 enclosure which houses 3 x 19" racks without compromise to housing depth availability.


### 1. Conversion Kit:

#### Contents:

- 4 x 19" mounting angles 2mm steel zinc plate and yellow passivate to BSEN 12329
- 8 x Fixing brackets
- 4 x Depth support rails
- 1 x Set fixings

#### Ordering codes:

Height	650 deep	850 deep	950 deep
36 U	GA1-190-321	GA1-193-321	GA1-196-321
42 U	GA1-191-321	GA1-194-321	GA1-197-321
48 U	GA1-192-321	GA1-195-321	GA1-198-321

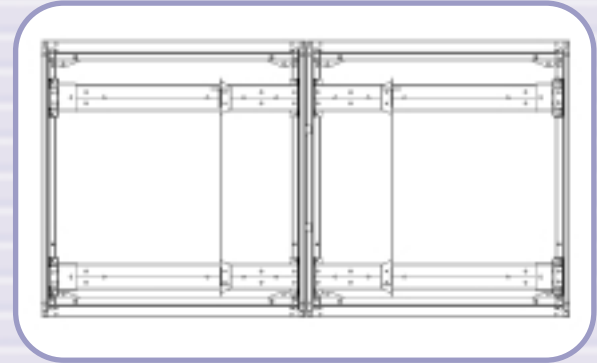

### 2. Please consult sales desk for factory configured service



#### SAFETY NOTE:


Cabinets need to be bayed together BEFORE fitting any equipment. This solution is NOT SUITABLE for movement of cabinets post installation - failure to comply with this notice may result in damage of cabinet/equipment or personal injury. Ensure cabinet is floor bolted or extendable plinth utilised PRIOR to withdrawal of any equipment.



# Elite 303 Cabinet

## ACCESSORIES

ELITE 303 CABINET

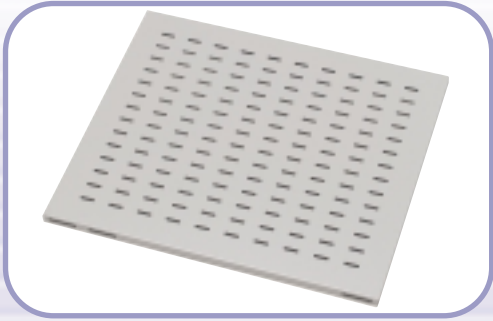

### Standard Fixed Vented Shelving


Can be fixed in place using standard M6 nut & bolt or using the unique quick fit fixing - weight loading capacity 50kgs.

#### Contents:

- 1 x Shelf 1.5mm steel colour goose grey to BS 4800 00A05
- 4 x 2mm spacers (to be used when fitted to upright, not required when shelf is fitted to 19" mounting angles)
- 1 x Set fixings

#### Ordering codes:

To suit cabinet:	19" 600wide (full width)			800wide (full width)		
	650d	850d	950d	650d	850d	950d
450mm (Actual Depth)	SM1-355-311	N/A	N/A	SM1-359-311	N/A	N/A
570mm (Actual Depth)	SM1-356-311	N/A	N/A	SM1-360-311	N/A	N/A
670mm (Actual Depth)	N/A	SM1-357-311	SM1-357-311	N/A	SM1-361-311	SM1-361-311
720mm (Actual Depth)	N/A	SM1-358-311	SM1-358-311	N/A	SM1-362-311	SM1-362-311

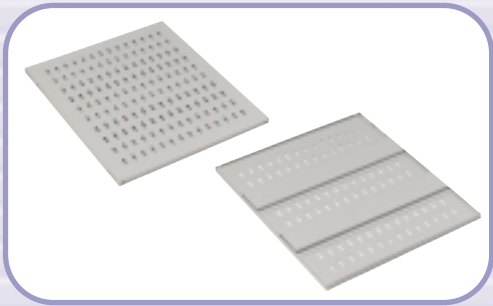

### Heavy Duty Fixed Vented Shelving


Can be fixed in place using standard M6 nut & bolt - weight loading capacity 100kgs.

#### Contents:

- 1 x Shelf 1.5mm steel with fixed brace/stiffener
- 4 x 2mm spacers
- 1 x Set fixings

#### Ordering codes:

To suit cabinet:	19" 600wide (full width)			800wide (full width)		
	650d	850d	950d	650d	850d	950d
450mm (Actual Depth)	SM1-372-311	N/A	N/A	SM1-376-311	N/A	N/A
570mm (Actual Depth)	SM1-373-311	N/A	N/A	SM1-377-311	N/A	N/A
670mm (Actual Depth)	N/A	SM1-374-311	SM1-374-311	N/A	SM1-378-311	SM1-378-311
720mm (Actual Depth)	N/A	SM1-375-311	SM1-375-311	N/A	SM1-379-311	SM1-379-311

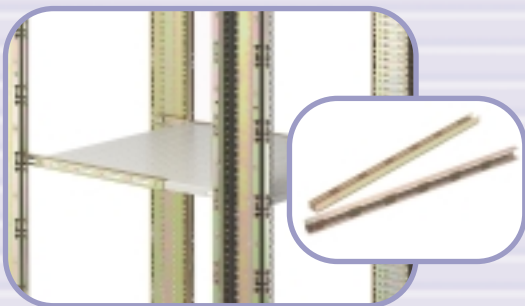

### Shelf Support Kit


Required when fitting shelf in non standard position or when using shorter than standard size shelf.

#### Contents:

- 4 x Support rails
- 1 x Set fixings

#### Ordering codes:

Depth of cabinet	650d	850d	950d
	GA1-147-321	GA1-148-321	GA1-149-321

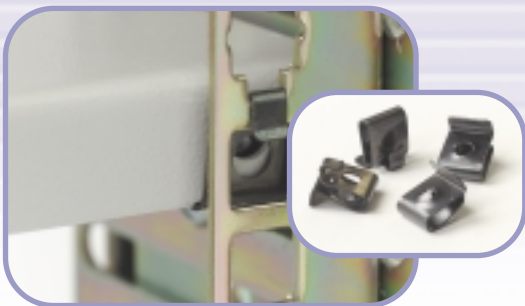

### Quick Fit Shelf Fixing

Simply hook into place either on the universal upright or into the 19" mounting angles. Weight loading capacity 50kg.

#### Contents:

- 1 x Quick fit shelf fixing 0.7mm spring steel

#### Ordering code:

- 1 x GA1-146-321

# Elite 303 Cabinet




E  
L  
I  
T  
E  
  
3  
0  
3  
  
C  
A  
B  
I  
N  
E  
T

## Telescopic Shelving

Can be fixed in place using standard M6 nut & bolt - weight loading capacity 45kgs.

### Contents:

- 1 x Shelf 1.5mm steel
- 2 x Telescopic runners
- 1 x Set fixings

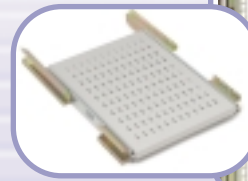

### Ordering codes:


To suit cabinet:	19" 600wide (full width)			800wide (full width)		
	650d	850d	950d	650d	850d	950d
450mm (Actual Depth)	GA1-321-311	GA1-322-311	GA1-323-311	GA1-330-311	GA1-331-311	GA1-332-311
570mm (Actual Depth)	N/A	GA1-324-311	GA1-325-311	N/A	GA1-333-311	GA1-334-311
670mm (Actual Depth)	N/A	GA1-326-311	GA1-327-311	N/A	GA1-335-311	GA1-336-311
720mm (Actual Depth)	N/A	GA1-328-311	GA1-329-311	N/A	GA1-337-311	GA1-338-311

## Heavy Duty Telescopic Shelving

Can be fixed in place using standard M6 nut & bolt or using the unique quick fit fixing - weight loading capacity 100kgs.

### Contents:

- 1 x Shelf 2mm steel
- 2 x Telescopic runners
- 1 x Set fixings

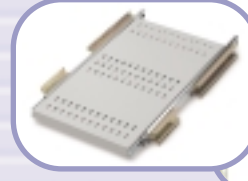

### Ordering codes:

To suit cabinet:	19" 600wide (full width)			800wide (full width)		
	650d	850d	950d	650d	850d	950d
450mm (Actual Depth)	GA1-350-311	GA1-351-311	GA1-352-311	GA1-359-311	GA1-360-311	GA1-361-311
570mm (Actual Depth)	N/A	GA1-353-311	GA1-354-311	N/A	GA1-362-311	GA1-363-311
670mm (Actual Depth)	N/A	GA1-355-311	GA1-356-311	N/A	GA1-364-311	GA1-365-311
720mm (Actual Depth)	N/A	GA1-357-311	GA1-358-311	N/A	GA1-366-311	GA1-367-311

## Hinged Cable Carriers

Provides a secure route and therefore prevents damage to interconnecting cable when telescopic shelves are used.

### Contents:

- 1 x Hinged cable carrier
- 1 x Set fixings

### Ordering codes:

- Hinged cable carrier GA1-089-000

Illustration not available at time of printing

## Cantilever Shelf


Can be fixed in place using standard M6 nut & bolt - weight loading capacity 15kgs.

### Contents:

- 1 x 1.5mm steel shelf
- 1 x Set fixings

### Ordering codes:

- 1U x 200mm deep SM1-345-310
- 1U x 300mm deep SM1-346-310
- 2U x 300mm deep SM1-347-310
- 2U x 350mm deep SM1-348-310
- 2U x 400mm deep SM1-349-310

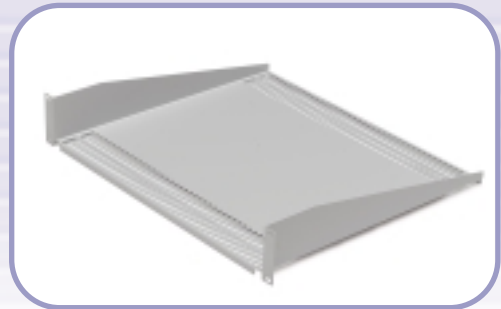




E  
L  
I  
T  
E  
  
3  
0  
3  
  
C  
A  
B  
I  
N  
E  
T

# Elite 303 Cabinet

Accessories

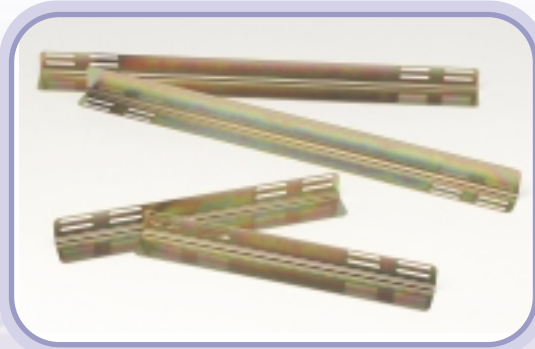

## Chassis Supports


Alternative to using full width shelving, provides additional support to 19" mounting equipment.

### Contents:

- 1 x Chassis supports
- 1 x Set fixings

### Ordering codes:

To suit cabinet	Actual length	
650d	450mm	GA1-132-321
850d	670mm	GA1-133-321
950d	720mm	GA1-134-321

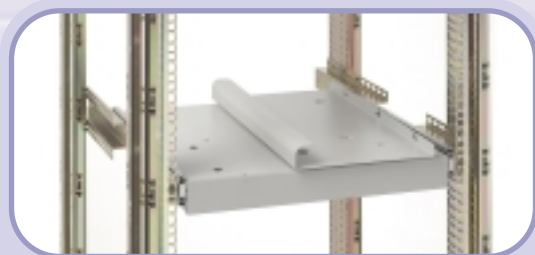

## Rotatable Keyboard Shelf


Full width keyboards do not fit between 19" mounting angles, this clever design overcomes this problem by enabling the keyboard to rotate through 90°.

### Contents:

- 1 x Rotatable keyboard shelf
- 1 x Telescopic runners
- 1 x Set fixings

### Ordering codes:

To suit cabinet	2U Height	
650d	GA1-380-311	
850d	GA1-381-311	
950d	GA1-382-311	

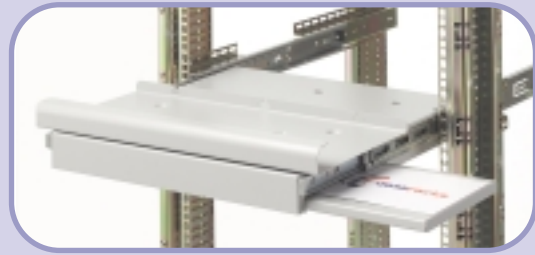

## Telescopic Drawer

Useful addition to the range - storage of documentation, discs, tapes etc. drawer fixed to smooth running telescopic slides secured with quick release fastener.

### Contents:

- 1 x 2 drawer unit
- 1 x Telescopic runners
- 1 x Set fixings

### Ordering codes:

To suit cabinet	2U Height	3U Height
650d	GA1-385-311	GA1-389-311
850d	GA1-386-311	GA1-390-311
950d	GA1-387-311	GA1-391-311



# Elite 303 Cabinet



## Baying Kit


To enable any two Elite 303 cabinets of the same height to be bayed together side by side.

### Contents:

1 x Set fixings

### Ordering code:

Baying kit GA1-023-321

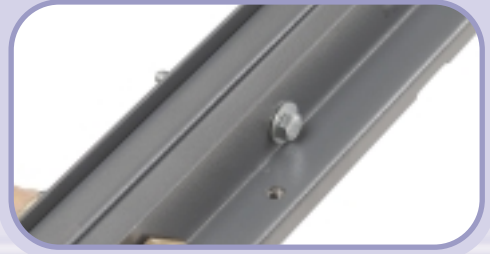

## Earth Bonding Kit

Provides earth continuity between the frame, doors and the top cover of cabinet.

### Contents:

3 x Short bonding cables (front, rear doors & top cover)  
2 x Long bonding cables (side doors). Tri Rated CSA 4mm<sup>2</sup>

### Ordering code:

To suit cabinet

650d	EA1-020-000
850d	EA1-021-000
950d	EA1-023-000



## Document Wallet


Useful storage wallet suitable for up to A4 documents.

### Contents:

1 x Document wallet

### Ordering code:

Document Wallet BI1-037-000

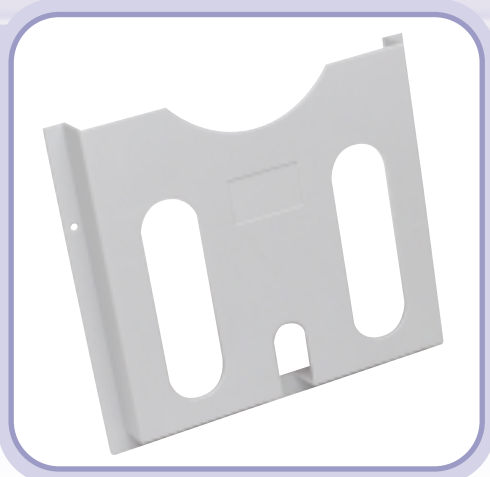

ELITE 303 CABINET



# Elite 303 Cabinet

## Accessories

ELITE 303 CABINET



### Fixed Plinth

Consisting of four identical corner sections and four removable covers, held in place by quick release plastic screws. Adjustable feet locate into corner sections (not included see opposite page).

#### Contents:

- 4 x Corner pieces
- 4 x Removable covers
- 1 x Fixing kit

#### Ordering codes:

Depth	600 wide	800 wide
600	SS1-025-314	SS1-028-314
800	SS1-026-314	SS1-029-314
900	SS1-027-314	SS1-030-314



### Fixed Plinth Brush Strip Panel

To enable cable access without removal of panel. Can be fitted to any side of plinth. Order either individually or specified within plinth build.

#### Contents:

- 1 x Brush strip panel and fixings

#### Ordering codes:

Depth/width	
600mm	SM1-182-314
800mm	SM1-183-314
900mm	SM1-184-314



### Extendable Plinth Complete


Increases cabinet stability when equipment is withdrawn from 19" aperture.

#### Contents:

- 4 x Plinth corners
- 3 x Covers
- 1 x Pullout support - including 1 levelling foot
- 1 x Brackets
- 1 x Set fixings
- 1 x Split front cover

#### Ordering codes:

Depth	600 wide	800 wide
650d	SS1-013-314	SS1-016-314
850d	SS1-014-314	SS1-017-314
950d	SS1-015-314	SS1-018-314

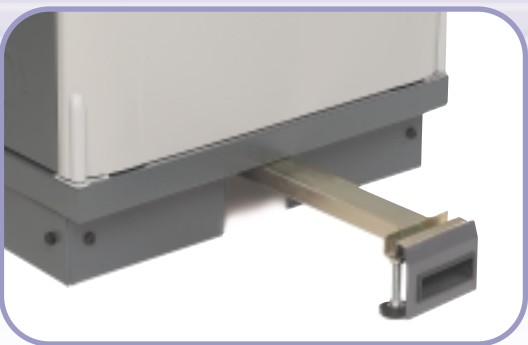

# Elite 303 Cabinet



E  
L  
I  
T  
E  
  
3  
0  
3  
  
C  
A  
B  
I  
N  
E  
T

## Castors

Transport castors fitted as standard, these are not loading bearing castors and must be removed once cabinet is sited.

### Contents:

- 2 x Plain
- 2 x Braked (4 braked on transport castors)
- 1 x Set fixings

### Transport Castor

Diameter wheel	Weight loading	Thread
50mm	Cabinet only	M10

### Ordering codes:

- Transport castor GA1-139-000

**NB:** Suitable for transportation only. Must be removed before installation.

### Light Duty Castor

Diameter wheel	Weight loading	Thread
50mm	60kg	M10

### Ordering codes:

- Light duty castor GA1-140-000

### Medium Duty Castor and Plate

Diameter wheel	Weight loading	Thread
80mm	120kg	M10

### Ordering codes:

- Medium duty castor & plate GA1-141-000

### Heavy Duty Castor and Plate

Diameter wheel	Weight loading	Thread
100mm	180kg	4 x M8 fixing bolts

### Ordering codes:

- Heavy duty castor & plate GA1-142-000

## Levelling Feet

Enables cabinet to be levelled on uneven floor surface.

 
### Contents:

- 4 x Levelling feet

	Height	Weight loading	Thread
Standard	100mm	750kgs	M10
Plinth	70mm	750kgs	M10

### Ordering codes:

- Standard levelling feet GA1-143-000
- Plinth levelling feet GA1-144-000






# Elite 303 Cabinet

Accessories

ELITE  
303  
CABINET

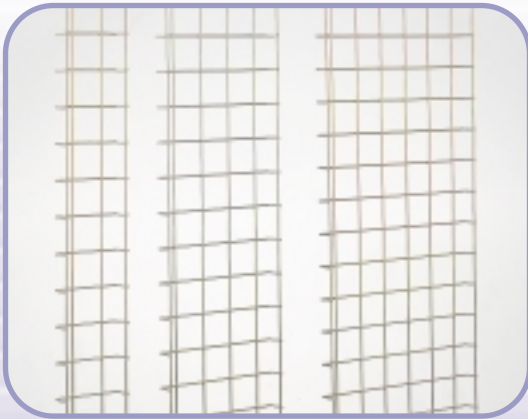

## Basket Tray


The installer's choice for structured vertical cable management. Held in place by spring clips and brackets.

### Contents:

- 1 x Tray wire gauge
- 2 x Fixing bracket
- 2 x Fixing clips

### Ordering codes:

Height	4"w x 1"d (100 x 25mm)	8"w x 1"d (200 x 25mm)	12"w x 1"d (300 x 25mm)	12"w x 2"d (300 x 50mm)
12U	GA1-031-321	GA1-038-321	GA1-045-321	GA1-052-321
18U	GA1-032-321	GA1-039-321	GA1-046-321	GA1-053-321
24U	GA1-033-321	GA1-040-321	GA1-047-321	GA1-054-321
30U	GA1-034-321	GA1-041-321	GA1-048-321	GA1-055-321
36U	GA1-035-321	GA1-042-321	GA1-049-321	GA1-056-321
42U	GA1-036-321	GA1-043-321	GA1-050-321	GA1-057-321
48U	GA1-037-321	GA1-044-321	GA1-051-321	GA1-058-321

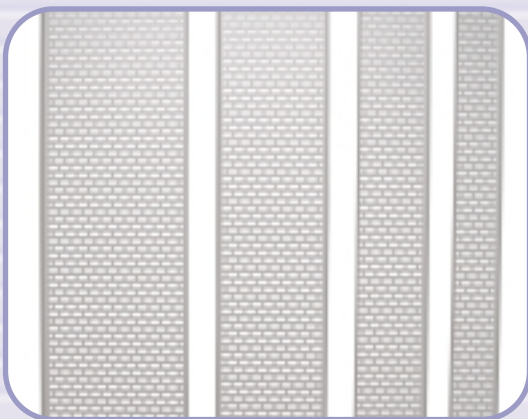

## Cable Tray


Alternative to basket tray, held in place by spring clips and brackets.

### Contents:

- 1 x Tray
- 2 x Fixing bracket screws
- 2 x Fixing clips

### Ordering codes:

Height	75mm	150mm	300mm
12U	GA1-060-311	GA1-067-311	GA1-074-311
18U	GA1-061-311	GA1-068-311	GA1-075-311
24U	GA1-062-311	GA1-069-311	GA1-076-311
30U	GA1-063-311	GA1-070-311	GA1-077-311
36U	GA1-064-311	GA1-071-311	GA1-078-311
42U	GA1-065-311	GA1-072-311	GA1-079-311
48U	GA1-066-311	GA1-073-311	GA1-080-311

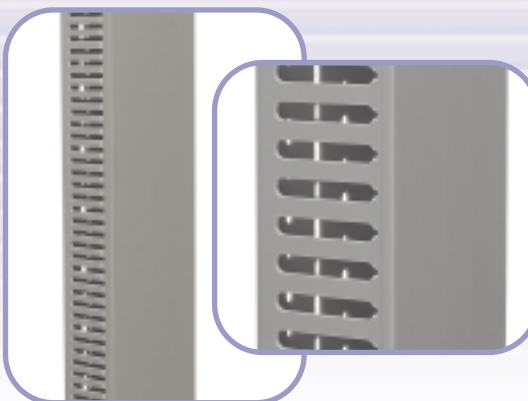

## Cable Trunking (Finger)

Designed to help protect and organise cables.

### Contents:

- 1 x Trunking
- 2 x Fixing bracket screws
- 2 x Fixing clips

### Ordering codes:

100 x 100 x 2m	GA1-082-000
100 x 60 x 2m	GA1-081-000



## Cable Management

All Elite cable management products have been designed to make the management of cables easier and to assist in correct cabling practice.

### Elite Jumper Ring


Purpose designed for the Elite frame, the jumper ring provides the option of vertical and horizontal cable management in area usually obstructed by cabinet corner posts. The jumper ring can be rotated 90° on the Universal Mounting Upright (UMU) knuckle.

#### Contents:

- 10 x Jumper rings
- 10 x UMU Knuckle

#### Ordering code:

- 10 x Elite Jumper rings kit      GA1-145-000

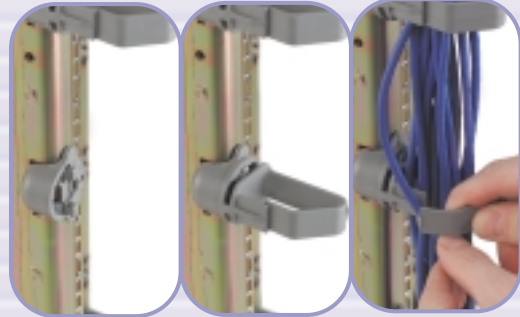

### Elite Cable Management Arm

As with the rest of the Elite cabinet the Cable Management Arm (CMA) incorporates the customer - led design that helped to make the Elite Cabinet so unique.

The primary demands on the product included it to be quick and easy to fit/use, not require additional fixings, provide future proofing to new cabling standards and thereby assist to achieve best cabling practice.

High demands indeed but the CMA achieves this and more. Forward or side facing the CMA is versatile, modular and robust.

### Elite Cable Management Arm Components

#### Ordering codes:

- 10 x 50mm shafts      GA1-176-000
- 10 x End caps      GA1-178-000
- 10 x Retaining arms      GA1-177-000
- 10 x UMU knuckles      GA1-180-000



### Elite 50mm Cable Management Arm

#### Contents:

- 4 x 50mm shafts
- 4 x End caps
- 4 x Retaining arms
- 4 x UMU knuckles

#### Ordering codes:

- 10 x Complete arms      GA1-170-000



### Elite 100mm Cable Management Arm

#### Contents:

- 8 x 50mm shafts
- 4 x End caps
- 4 x Retaining arms
- 4 x UMU knuckles

#### Ordering codes:

- 4 x Complete arms      GA1-173-000



Number of cable management arms required per each height of cabinet - (4 arms = one set)

Height of cabinet	Recommended sets	Maximum sets per pair of uprights
12	1	2
18	2	3
24	3	4
30	4	5
36	5	6
42	6	7
48	7	8



# Elite 303 Cabinet

## Accessories

ELITE 303 CABINET



### 1U Elite Jumper Ring Panel


This panel incorporates the benefits of the Elite jumper ring - enabling 90° rotation and offering horizontal or vertical cable management.

#### Contents:

- 4 x Jumper rings
- 4 x Flat knuckles
- 1 x Black 1U Panel
- 1 x Set fixings

#### Ordering code:

1U 4 Ring panel GA1-083-312

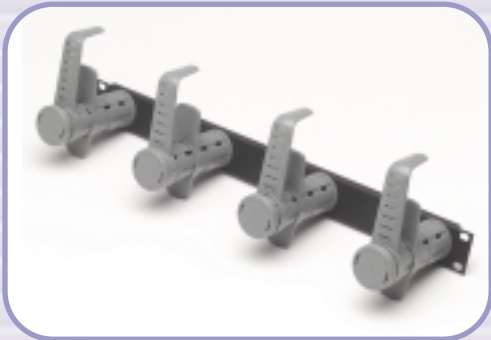

### 1U Elite Cable Management Arm Panel

This clever yet simple idea not only assists in best cabling practice but is also ideal to enable patch cables to flow around the perimeter of the cabinet. It is also extremely useful in providing a channel, which supports a high volume of cables when they need to pass between cabinets without any interference. This makes full use of the Elite frames' unique feature of not having any corner posts like most traditional cabinets.

#### Contents:

- 4 x 2 x 50mm shafts
- 4 x End caps
- 4 x Retaining arms
- 4 x Flat knuckles
- 1 x Black 1U Panel
- 1 x Set fixings

#### Ordering code:

1U Elite cable management arm panel GA1-085-312



### Horizontal Cable Tidy


Standard horizontal cable tidies.

#### Contents:

- 1 x Cable tidy
- 1 x Set fixings
- 4 x Retaining arms

#### Ordering code:

1U Horizontal Cable Tidy Black	GA1-084-312
1U Horizontal Cable Tidy Grey	GA1-084-311
2U Horizontal Cable Tidy Black	GA1-184-312
2U Horizontal Cable Tidy Grey	GA1-184-311

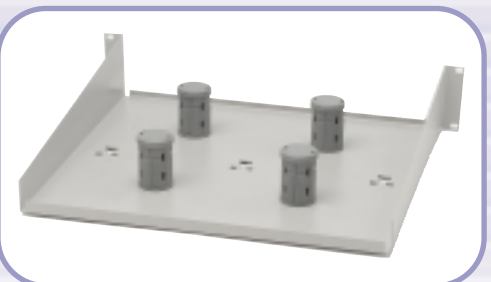

### Cable Tidy Shelf

Ideal for storing excess patch cables.

#### Contents:

- 1 x Shelf
- 4 x Cable management arms
- 1 x Set fixings

#### Ordering code:

2U Cable tidy shelf GA1-086-312

### Flat Bar Jumper Rings and Rod Jumper Rings

Please see page 66

# Elite 303 Cabinet



## 19" Blanking Panels

Please consult sales if other colours are required.

### Contents:

- 1 x Black 1U Panel
- 1 x Set fixings

### Ordering codes:

1U	SA1-043-312
2U	SA1-044-312
3U	SA1-045-312
4U	SA1-046-312
5U	SA1-047-312



## Cage Nut Fixings

### Contents:

- 1 x Set M6 cage nuts

### Ordering code:

- Cage nuts GA1-028-321



## Quick Fit Shelf Fixing

Simple hook into place either on the universal upright or into the 19" mounting angles. Weight loading 50kgs.

### Contents:

- 1 x Quick fit shelf fixing 0.7mm spring steel

### Ordering code:

- Quick fit shelf fixing GA1-029-000



E  
L  
I  
T  
E  
  
3  
0  
3  
  
C  
A  
B  
I  
N  
E  
T