



MASTER LEDtube Performance

MASTER LEDtube PERF 600mm 10.5W840 T8 I ROT

The Philips MASTER LEDtube integrates a LED light source into a traditional fluorescent form factor. Its unique design creates a perfectly uniform visual appearance which cannot be distinguished from traditional fluorescent. This product is the ideal solution for up lighting in general lighting applications.

Product data

• General Characteristics

| | |
|------------------------|------------|
| Main Application | Industrial |
| Cap-Base | G13 |
| Rated Lifetime | 50000 hr |
| Nominal Lifetime hours | 50000 hr |

• Light Technical Characteristics

| | |
|-------------------------------|---------|
| Colour Code | 840 |
| Beam Angle | 140 D |
| Correlated Colour Temperature | 4000 K |
| Colour rendering index | 85 |
| Rated Luminous Flux | 1050 Lm |
| LLMF - end nominal lifetime | 70 % |
| Rated Beam Angle | 140 D |

• Electrical Characteristics

| | |
|--------------------------------|------------------------|
| Wattage | 10.5 W |
| Voltage | 100-240 V |
| Line Frequency | 50/60 Hz |
| Power Factor | 0.9 (min) - |
| Lamp Current mA | 44 (min), 105 (max) mA |
| Dimmable | No |
| Rated Wattage | 10.5 W |
| Starting Time | 0.5 (max) s |
| Warm-up Time to 60% Light Outp | instant full light |
| Energy saving product | Yes |
| Suitable for accent lighting | No |

• Temperature Characteristics

| | |
|-----------------------|-----------------------|
| Operating temperature | -30 (min), 45 (max) C |
| T-Storage | -40 (min), 65 (max) C |

• Environmental characteristics

| | |
|-------------------------------|----|
| Energy Efficiency Label (EEL) | A+ |
|-------------------------------|----|

• Measuring Conditions

| | |
|-----------------|--------|
| Switching cycle | 50000X |
|-----------------|--------|

• Product Dimensions

| | |
|----------------------------|----------|
| Length A1 | 588.5 mm |
| Fixing Hole Distance | 595.5 mm |
| A2 Length | |
| Length A3 | 602.5 mm |
| Mounting hole diameter | 25.68 mm |
| Circular outline dimension | 28 mm |

• Approval & Application Chars

| | |
|-----------------------|-----|
| VDE marking | No |
| CE marking | Yes |
| UL certificate | No |
| RoHS compliance | Yes |
| KEMA Keur certificate | Yes |



PHILIPS


MASTER LEDtube Performance

Product Data

Order code 662297 00
 Full product code 871829166229700
 Full product name MASTER LEDtube PERF 600mm
 10.5W840 T8 I ROT
 Order product name MAS LEDtube PERF 600mm
 10.5W840 T8 I ROT
 Pieces per pack 1
 Packing configuration 10


Packs per outerbox 10
 Bar code on pack - EAN1 8718291708209
 Bar code on outerbox - EAN3 8718291708216
 Logistic code(s) - 12NC 929000283802
 Net weight per piece 0.180 kg

Dimensional drawing

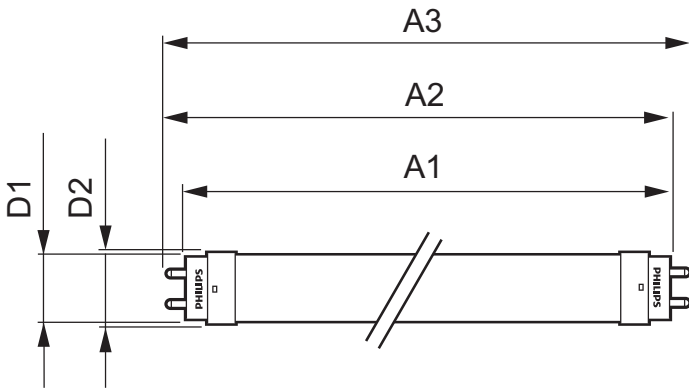


MASTER LEDtube PERF 600mm 10.5W840 T8 I ROT

| Product | A1 (Norm) | A2 (Norm) | A3 (Norm) | D1 (Norm) | D2 (Norm) |
|-----------------------------------|-----------|-----------|-----------|-----------|-----------|
| TLED PERF 600mm 10.5W840 T8 I ROT | 588.5 | 595.5 | 602.5 | 25.68 | 28 |

 

G13

Photometric data

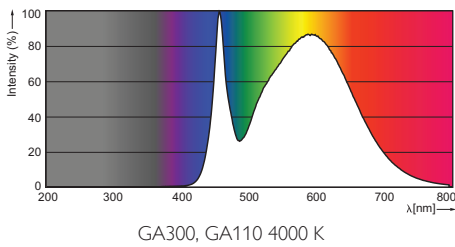

© 2014 Koninklijke Philips N.V. (Royal Philips)
 All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, June 28
 data subject to change