

This is a sample photo.


ORDER SYMBOL: AL 061505

EL.number **EAN:** 6418074004109
 Sweden: 2536309
 Denmark: 8212004634
 Finland: 3423607

INCLUDING:
 Enclosure body, cover with PUR gasket, cover screws, and 2 earth screws.

APPROVALS:
 USA: UL Type 1, 4, 4X, 12, 13 (E75645 Vol.1 Sec.6)
 EURO: IP 67/IP 66
 OTHERS: IEC 529

FIBOX EURONORM II AL

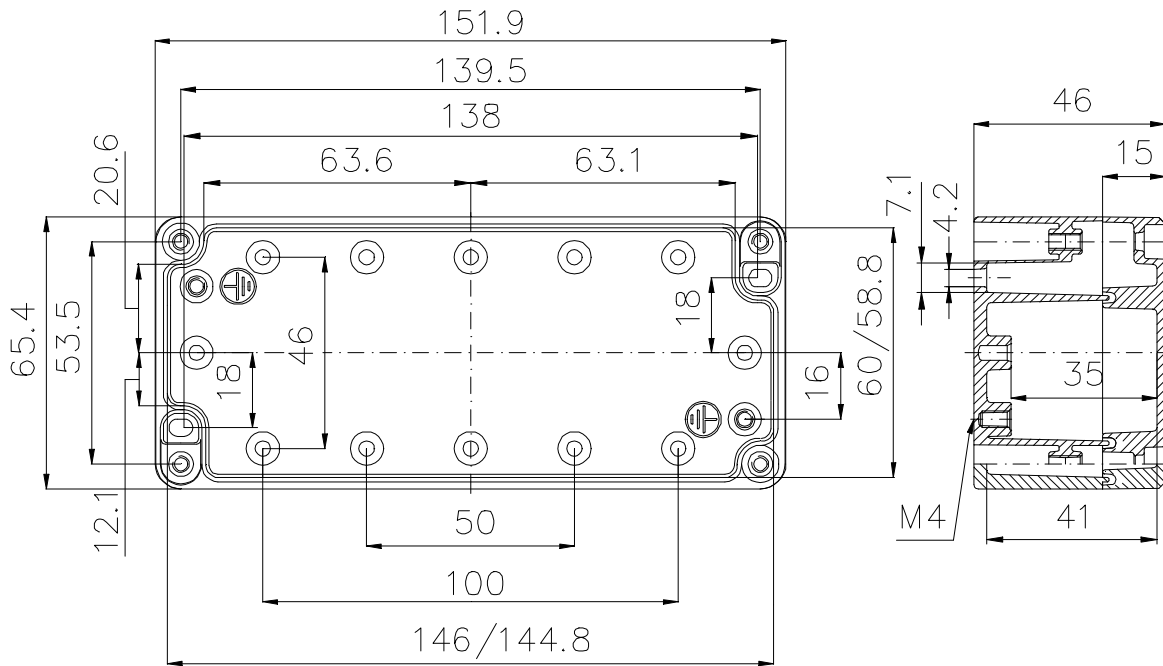

TECHNICAL INFORMATION:

Standard colour: RAL 7001
 Ingress protection: IP 67 (IEC 529)
 Flame resistance:

Temp.range in cont. use: Max. +80 °C
 Temp. range of material: - 50 °C - + 120 °C

ACCESSORIES

DIN-Rail	ARH 12	DIN-Rail	ARH 40
DIN-Rail	ARH 16	DIN-Rail	ARH 60
DIN-Rail	ARH 1636	DIN-Rail	ARM 0610
DIN-Rail	ARH 1656	DIN-Rail	ARM 0615
DIN-Rail	ARH 22	DIN-Rail	ARM 0808
DIN-Rail	ARH 2320	DIN-Rail	ARM 0813
DIN-Rail	ARH 2328	DIN-Rail	ARM 0818
DIN-Rail	ARH 2333	DIN-Rail	ARM 0825
DIN-Rail	ARH 26	Fastening lug	MRS 28540
DIN-Rail	ARH 36	Fastening lug	MRS 28541

(c) FIBOX Oy Data subject to change without notice.