
7506

Lamps with metal bases for cars



Product benefits

- Wide product range
- Reliable quality

Product features

- Original spare parts

Product datasheet

Technical data


Electrical data

| | |
|-----------------------|---------|
| Power input | 25 W |
| Nominal wattage | 21.00 W |
| Nominal voltage | 12 V |
| Power input tolerance | ±6 % |
| Test voltage | 13.5 V |

Photometrical data

| | |
|-------------------------|--------|
| Luminous flux | 460 lm |
| Luminous flux tolerance | ±15 % |

Dimensions & weight

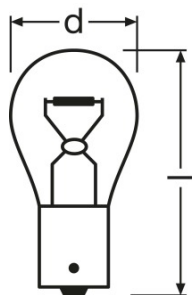

| | |
|----------------|---------|
| Length | 52.5 mm |
| Diameter | 26.5 mm |
| Product weight | 8.10 g |

Lifespan

| | |
|-------------|-------|
| Lifespan B3 | 250 h |
| Lifespan Tc | 500 h |

Additional product data

| | |
|-----------------------------|-------|
| Base (standard designation) | BA15s |
|-----------------------------|-------|

Certificates & standards

| | |
|---------------------------|-------------|
| ECE category | P21W |
| Approval marks - approval | E1 approval |

Product datasheet


Country specific categorizations

| | |
|------------------------|-----------------|
| Order reference | 7506 21W 12V BA |
|------------------------|-----------------|

Country specific information

| Product code | METEL code | SEG number | STK number | UK Org |
|---------------------|-------------------|-------------------|-------------------|---------------|
| 4050300838120 | OSRA7506 | 8328096 | - | - |
| 4050300925448 | OSRA7506BLI2 | 8328348 | 4730328 | - |

Product datasheet

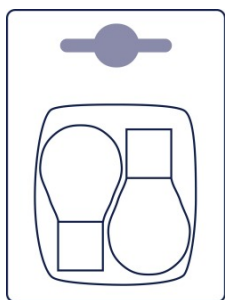

Others graphics

Logistical Data

| Product code | Product description | Packaging unit (Pieces/Unit) | Dimensions (height x width x length) | Volume | Gross weight |
|---------------|---------------------|------------------------------|--------------------------------------|----------------------|--------------|
| 4050300838120 | 7506 | Unpacked 1 | 38 mm x 36 mm x 82 mm | 0.11 dm ³ | 50.33 g |
| 4050300524849 | 7506 | Folding carton box 10 | 108 mm x 54 mm x 88 mm | 0.51 dm ³ | 103.00 g |
| 4008321090966 | 7506 | Shipping carton box 50 | 145 mm x 80 mm x 273 mm | 3.17 dm ³ | 565.00 g |
| 4050300925448 | 7506 | Blister 2 | 55 mm x 24 mm x 66 mm | 0.09 dm ³ | 20.38 g |
| 4008321140494 | 7506 | Shipping carton box 20 | 81 mm x 102 mm x 280 mm | 2.31 dm ³ | 271.50 g |

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.