

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [112000-5027](#)
Status: **Active**
Overview: Brad® PC Network Interface Cards (NIC)
Description: applicom PCIE2000ETH Card, Ethernet + Serial RS485/422, 1 Channel, PCI Express 1x -OPC/DLL/DAS - SCADA/HMI

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

[Product Literature \(PDF\)](#)

General

Product Family	Network Interface
Series	112000
Application	HMI, SCADA
Approvals	CE certified
Comments	Default installed with RS485 module (Alternative interface to purchase)
Communication Speed	Ethernet: 10/100 Mbps, Serial up to 38,400 bps
Messaging	Ethernet, Serial
Mounting Style	PC Slot
Operating System	Windows 7, Windows Server 2003, Windows Server 2008, Windows Vista, Windows XP
Overview	Brad® PC Network Interface Cards (NIC)
Product Literature Order No	987650-5289
Product Name	applicom®
Protocol	Ethernet, Serial
Slot	PCI Express 1x
Software Downloads	APP-ESR-PCIE
Type	Ethernet Card, Serial Card
UPC	883906483746

Physical

Channels	2
Interface	DAServer, DDE Server, DLL, OPC DA Server
Net Weight	300.000/g
Network Connection Type	Ethernet: RJ45, Serial: D-Sub Female (9 pin)
Packaging Type	Carton
Processor	AMD SC520
Temperature Range - Operating	0°C to +65°C

Electrical

Current - Maximum Input	5.5W
EMC	EN 55022 Class B, EN 61000-3-2, EN 61000-3-3, EN 61000-6-2
Supply Voltage	3.3V

Material Info

Old Part Number	APP-ESR-PCIE
-----------------	--------------

Reference - Drawing Numbers

Sales Drawing	SD-112000-5026
---------------	----------------

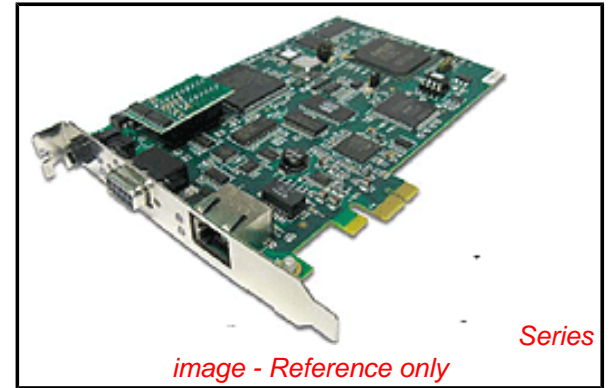


image - Reference only

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[112000Series](#)