


# SR50A 500W SOLDERING IRON

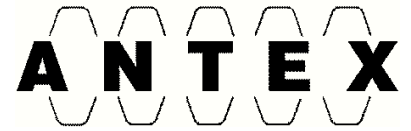

## DATA SHEET


769-3117



Iron featured without bit

### **SPECIFICATIONS SR50A (ANGLED) 500WATT SOLDERING IRON**

NOMINAL POWER (W)	500
STANDARD VOLTAGE	230
NOMINAL TIP TEMP (°C)	500
FITTED BIT (D.F.)	1 1/4" (32mm)
CABLE LENGTH (m)	2.0
CABLE TYPE	Rubber with U.K. plug
HANDLE MATERIAL	Wood
COUNTRY OF ORIGIN	U.K.
WEIGHT gms. (approx.)	1600
DIMENSIONS (approx.)	A: (bit) 55mm. B: 310mm. C: 95mm. D: 400mm.

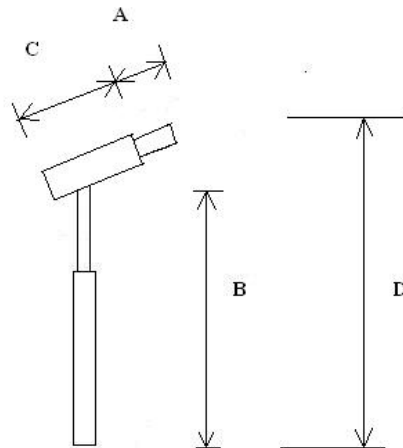

### **TYPICAL APPLICATIONS:**

Heavy duty tasks. Features large bit with rapid heat replacement. Extensively used for heavy maintenance work including electronic motors with high temperature alloys, large metal boxes and for joining busbars.