


**52601-S10-4LF - Quickie® : Double Row,
10 Positions, 2.54 mm (0.1 in.), Vertical
Header 0.38 µm (15 µin.) Gold Mating Plating**

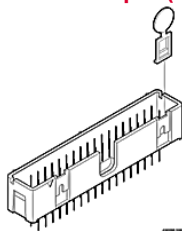

www.fci.com

Specifications

Approvals / Certifications

UL File Number	E66906
CSA File Number	LR46923
Approvals / Certifications	UL and CSA Approved
Dimensional	
Length (Tail)	3.05 mm (0.12 in.) - recommended
Electrical	
Current rating	3 amp Continuous
Resistance (Insulation)	10000 M-ohms min.
Voltage rating	500V AC rms min.
General	
Number of contacts (Total)	10
Number of rows	2
Orientation	Vertical
Attachment type (Board)	Through Mount
Mating half	All Quickie® Receptacles. Select Discrete Wiring Mini-Latch Housings.
Mounting	
Solder process	Wave Vapor-Phase IR Reflow
Other Features	
Packaging (Type)	Trays
Type	Low Profile
Physical	
Color (Housing)	Black
Material (Contact)	Copper Alloy
Material (Housing)	High Temperature Thermoplastic
Plating (Contact area)	0.38 µm (15 µin.) Gold
Plating (Tail)	2.54 µm (100 µin.) Pure Tin
Underplating (Contact)	1.27 µm (50 µin.) Nickel
Flammability rating	UL 94V-0
Temperature (Range)	-65°C to +125°C