

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130054-0013](#)
Status: **Active**
Overview: [industrial ethernet solutions](#)
Description: Ultra-Lock® (M12) Single-Ended Receptacle, 4 Poles, Female (Straight) to Pigtail, 2.0m (6.56') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E200650

General

Product Family	Industrial Cordsets
Series	130054
Connector End A	Ultra-Lock® (M12)
Connector End B	Pigtail
IP Rating	IP67
Overview	industrial ethernet solutions
Performance Category	5e
Product Name	Ultra-Lock® (M12)
Type	Single Ended
UPC	78678804778

Physical

Cable Diameter	N/A
Cable Length	2.0m (6.56')
Color - Cable Jacket	Teal
Coupling Style	Threaded
Gender	Female-Pigtail
Keyway	D-coded
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	PVC
Material - Contact	Copper
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold over Nickel
Net Weight	103.148/g
Orientation	Straight
Poles	4
Temperature Range - Operating	-25°C to +75°C
Wire Size AWG	24
Wire/Cable Type	E152210

Electrical

Current - Maximum per Contact	1.5A
Voltage - Maximum	125V

Material Info

Old Part Number ERWAAJ4002M020

Reference - Drawing Numbers

Sales Drawing SD-130054-001

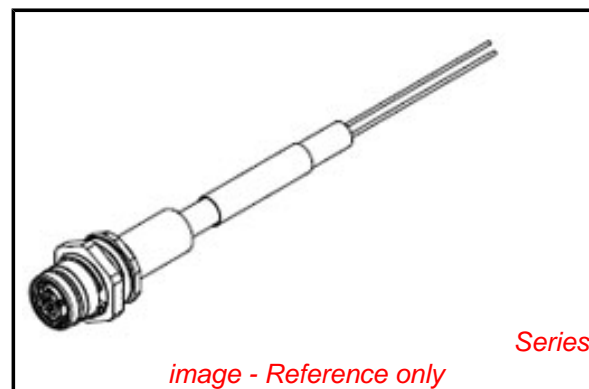


image - Reference only

EU RoHS

RoHS Compliant by Exemption
REACH SVHC
 Not Reviewed
Low-Halogen Status
Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

130054Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION