

Data sheet VARIO® LINEA

Socket strip

EHMANN
Ideen in Strom

Universal 11-fold plus


Item No.: 0201x02112303

- Robust plastic body, grey
- 90° rotated sockets Type E (French Standard)
- Space of sockets: 64 mm
- **3 m** power cord and angle plug
- integrated circuit breaker 16 A
- Increased safety due to integrated child protection
- End caps with mounting facilities

Technische Daten

Connection:	250 V~, 16 A, 50 Hz, 3.600 W
Power cord:	3 m H05VV-F 3G 1,5 mm ²
Plug:	CEE 7/7 angle plug Type EF
Socket:	Middle earth Type E
Switch:	2-pole, illuminated
Circuit breaker:	16 A
Own consumption:	< 0,5 W
Dimension:	846 x 74 x 47 mm (L x B x H)
Fixing dimension X:	838 mm

EAN:	401209600488 2
Packaging unit:	10 pc.

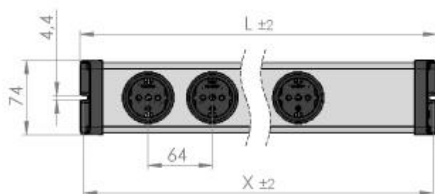

VARIO
LINEA