

ToLEDo Candle

ToLEDo Candle Frosted 250LM B22 SL

0026922



Range features

- Up to 88% energy saving compared to incandescent lamps
- Instant light
- 100% retrofit - Same dimensions as incandescent equivalent
- Suitable for replacement of up to 25W and 40W incandescent lamps
- Uniform light distribution
- Available in Homelight (2700K)
- Good colour rendering (CRI 80+)
- Average rated life 25,000 hrs



PRODUCT OVERVIEW

Light colour	Homelight
Technology	LED
Ordering number	0026922
Average life (Rated) (h)	25000
Energy class	A+
Lamp shape	Candle
Lamp finish	Frosted
Dimmable	No
Cap/Base	B22
Type	ToLEDo Candle
EAN code	5410288269221
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	250
Watt (Nominal) (W)	4
Equivalent watt (W)	25
Voltage (V)	220-240

ToLEDo Candle

ToLEDo Candle Frosted 250LM B22 SL

0026922

DATA TABLE

General data

Dry applications use only	Yes
Ordering number	0026922
Technology	LED
Energy saving lamp	Yes
Average life (Nominal) (h)	25000
Average life (Rated) (h)	25000
Energy class	A+
Lamp finish	Frosted
Lamp shape	Candle
Dimmable	No
Cap/Base	B22
Type	ToLEDo Candle
EAN code	5410288269221
Long description	Up to 88% energy saving compared to incandescent lamps. Instant light. 100% retrofit - Same dimensions as incandescent equivalent. Suitable for replacement of up to 25W and 40W incandescent lamps. Uniform light distribution. Available in Homelight (2700K). Good colour rendering (CRI 80+). Average rated life 25,000 hrs
Product name	ToLEDo Candle Frosted 250LM B22 SL
Lamp mercury content (mg)	0
Starting time (max) (s)	0.05
Warm-up time to 60% of full light (max) (s)	< 1s => 60%
Control gear required	No
Intended purpose	No
No. of switching cycles before premature failure (min)	50000
Special purpose lamp	No
Sales pack quantity	6
Optimal operating condition (°C)	25

Optical data

Light colour	Homelight
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	250
Lumen maintenance at end of nominal life (%)	70
Luminous flux (Nominal) (lm)	250

ToLEDo Candle

ToLEDo Candle Frosted 250LM B22 SL

0026922

Electrical data

kWh per 1000 hours burning time	4
Equivalent watt (W)	25
Watt (Rated) (W)	4
Watt (Nominal) (W)	4
Voltage (V)	220-240
Current (A)	0.024
Lamp power factor	0.7

Physical data


Weight (kg)	0.05
Lamp Length (mm) - C/L	103
Max. Lamp Diameter (mm) - D	38
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	11.90 x 4.80 x 4.80
Inner package dimensions (L x W x H) (cm)	15.50 x 10.50 x 13.40
Inner package net weight (kg)	0.28
Outer package dimensions (L x W x H) (cm)	55.00 x 32.60 x 15.40

ToLEDo Candle

ToLEDo Candle Frosted 250LM B22 SL

0026922

TECHNICAL DRAWINGS

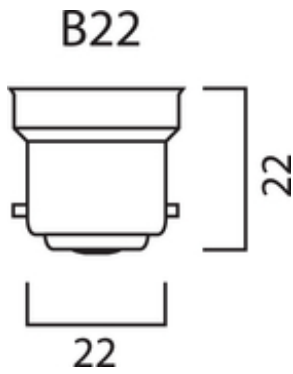

ENERGY LABEL

□