



MASTERCcolour CDM-Tm Mini

MASTERCcolour CDM-Tm Mini 35W/930 PGJ5 1CT

Miniature, single-ended ceramic metal halide lamp PGJ5 twist-lock lamp base

Product data

• General Characteristics

Cap-Base	PGJ5
Bulb	T3.5
Bulb Finish	Clear
Burning Position	any [Any/Universal]
Life to 5% failures	9000 hr
Life to 10% failures	10000 hr
Life to 20% failures	11000 hr
Life to 50% failures	12000 hr

• Light Technical Characteristics

Colour Code	930 [CCT of 3000K]
Colour Rendering Index	88 (min), 91 (nom) Ra8
Colour Designation	Warm white
Colour Temperature	3000 K
Colour Temperature Technical	2950 K
Lamp Luminous Flux EL	3000 Lm
Lamp Luminous Efficacy EL	77 Lm/W
Lumen Maintenance 1000h	85 %
Lumen Maintenance 2000h	80 %
Lumen Maintenance 5000h	70 %
Lumen Maintenance 10000h	60 %
Design Mean Lumens EL	2150 Lm
Chromaticity Coordinate X	0.436 -
Chromaticity Coordinate Y	0.396 -

• Electrical Characteristics

Lamp Wattage	35 W
Lamp Wattage EL 25°C, Rated	39.0 W
Lamp Wattage EL 25°C, Nominal	35.0 W
Lamp Voltage	96 V
Lamp Current EL	0.4 A
Ignition Time	30 (max) s
Run-up time 90%	3 (max) min
Re-ignition Time [min]	15 (max) min
Dimmable	no

• Environmental Characteristics

Energy Efficiency Label (EEL)	A+
Mercury (Hg) Content	2.74 mg
Energy consumption kWh/1000h	42 kWh

• UV-related Characteristics

Damage Factor D/fc PET (NIOSH)	0.4 (max) - 8 (min) h500lx
--------------------------------	----------------------------

• Luminaire Design Requirements

Cap-Base Temperature	250 (max) C
Bulb Temperature	480 (max) C



MASTERColour CDM-Tm Mini

• Product Dimensions

Overall Length C	52 (max) mm
Diameter D	11.2 (max) mm
Light Center Length L	22.3 (min), 22.6 (nom), 22.9 (max) mm
Arc Length O	4 mm
Light Center Length L [inch]	0.89 in
Overall Length C [inch]	2.05 (max) in
Diameter D [inch]	0.44 in

• Product Data


Order code	211491 15
Full product code	871150021149115

Full product name	MASTERColour CDM-Tm Mini 35W/930 PGJ5 1CT
Order product name	MASTERC CDM-Tm Mini 35W/930 PGJ5 1CT/12
Pieces per pack	1
Packing configuration	12
Packs per outerbox	12
Bar code on pack - EAN1	8711500211491
Bar code on outerbox - EAN3	8711500211507
Logistic code(s) - 12NC	928093905130
ILCOS code	MT/UB-35/930-H-PGJ5-11.2/52
Net weight per piece	0.006 kg

Warnings and Safety


- Use only in totally enclosed luminaire, even during testing (IEC61167, IEC 62035, IEC60598)
- The luminaire must be able to contain hot lamp parts if the lamp ruptures
- Use only with electronic control gear
- Control gear must include end-of-life protection (IEC61167, IEC 62035)
- For 20W PGJ5 lamp, use only Philips electronic control gear HID PV mini PGJ5 20W
- For 35W PGJ5 lamp, use only Philips electronic control gear HID PV mini PGJ5 35W

Dimensional drawing

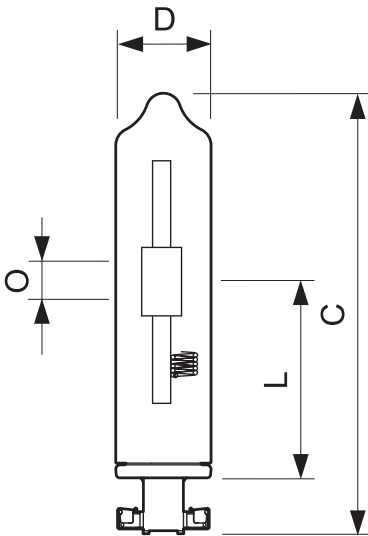


MASTERColour CDM-Tm Mini 35W/930 PGJ5 1CT

Product	C (Max)	D (Max)	L (Min)	L (Norm)	L (Max)	O (Min)	O (Norm)	O (Max)
CDM-Tm 35W/930 PGJ5	52	11.2	22.3	22.6	22.9	-	4	-

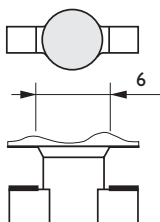

PGJ5

Photometric data

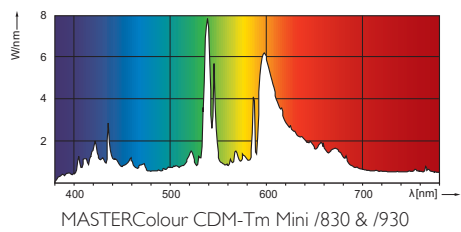

© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, November 30
data subject to change