


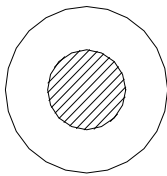

Product Name:	UL1429 22AWG
Product Discription:	UL1429 22AWG
Specification No.:	
Customer's Name:	

Description					Construction							
Rated Voltage:		150V			Conductor		Stranded Tinned Copper					
Rated Temperature:		80℃			Size(AWG)		22					
Reference Standard:		UL758,UL1581			Construction(±0.008mm)		7/0.254					
Cross Section					Stranded Dia.(mm)Ref.		0.76					
					Insulation Material		XLPVC					
					Insulation Color		ANY COLOR					
					Ave Thickness(mm)		0.23					
					Insulation Dia.(±0.06mm)		1.28					
Marking					Remark:							
E148000  AWM STYLE 1429 22AWG 80℃ 150V VW-1 --- C  AWM I A 80℃ 150V FT1 -F- -LF- PC10 LTK					8775355 Red		8775364 Blue		8775377 Grey		8775386 Violet	
					8775358 Black		8775367 White		8775370 Yellow			
					8775351 Brown		8775361 Green		8775373 Orange			
					Characteristics				Customer Approve			
For Internal Wiring of Appliances or Electronic Equipment					Test Item			Standard Value				
					Test Material			XLPVC(ROHS)				
					Insulation DC resistance(MΩ*km)			10				
					Vol. Tesr(AC.V.60S) (V)			2000				
					Flammability Test			VW-1				
					Max.DC Resistance(20℃ Ω/km)			59.4(MAX)			Signature:	
											Date:	
Revisions												
Version	Description		Drawn by	Approved by	Date							
0	New document issue		Lisa	Jason	18/05/2015							