


Verbatim LED Round Capsule G4 1.5W 2700K Warm White 85 LM


- G4 Socket
- 12V AC/DC Voltage
- 40,000 hours Lifetime
- 86% Energy Saving
- Lumen: 85
- Equivalent to 10W incandescent bulb

Product Number	52145
General Data	
Lamp Socket	G4
Design	Round Capsule
Electric Data	
Wattage (W)	1.5
Wattage Equivalent (W)	10
Voltage (V)	12V AC/DC
Dimmable	no
Operating Frequency (Hz)	50-60
Geometric Data	
Length (mm)	36
Diameter (in mm)	29
Weight (g)	6
Photometric Data	
Luminous Flux (lm)	85
CRI	80
CCT (K)	2700
Luminous Intensity (cd)	25
Beam Angle (°)	110
Luminous Efficacy (lm/W)	57
Lifetime (hrs)	40,000
Switching Cycle	50,000

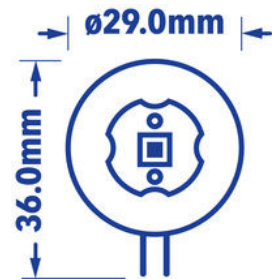


02/07/2014

Photometric Diagrams

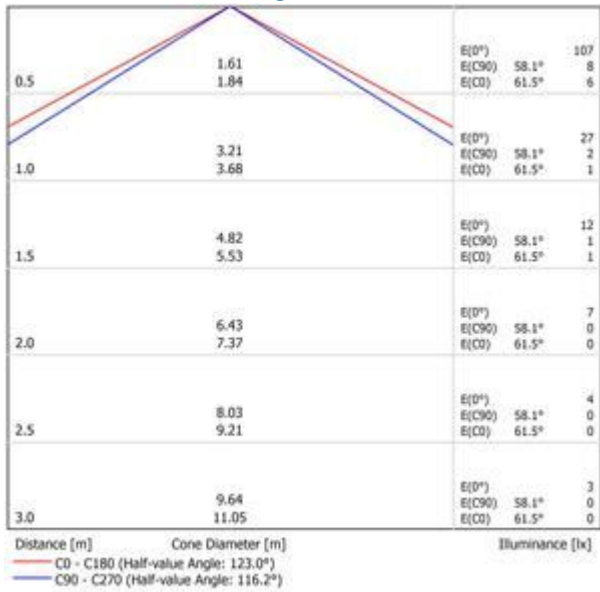

Energy Rating

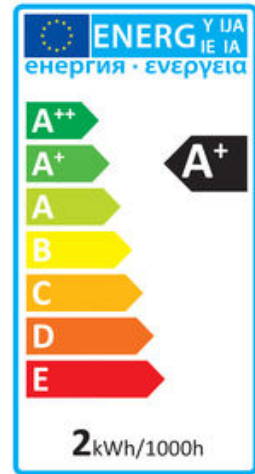

Technical Packaging Details

Barcode

023942521457

EAN 128

(02)00023942521457(37)10(91)09

EAN 14

50023942521452

Pack Dimensions(HxWxL)

135 x 10 x 90

Pack Weight

17

MOQ

10

Carton Dimensions (HxWxL)

150 x 103 x 103

Cartons/Pallet

420

Layers/Pallet

6

Units/Pallet

4200

02/07/2014