



Datasheet

Stock No: 712-5364

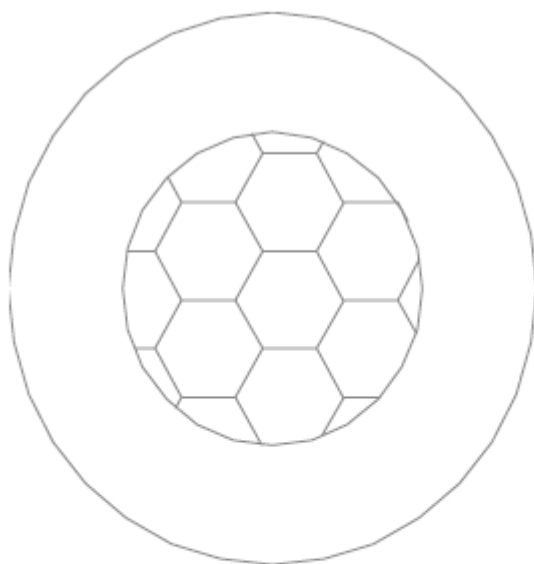
ENGLISH

# RS Pro Yellow Equipment Wire, 0.22mm<sup>2</sup> CSA, 1000 V 1.4 A 24 AWG, 100m



## Cable Construction

<b>Conductor</b>	<b>Tinned Copper</b>
square(mm <sup>2</sup> )	0.22
Construction	T0.2±0.008×7
Standard Dia.(mm)	0.60
<b>Insulation</b>	<b>PVC</b>
Thickness	0.3
Insulation Dia.(±0.1mm)	1.20

**Electrical Characteristics**

Max.Conductor DC Resistance at 20 °C ( $\Omega$ /Km)	<86.2
Min.Insulation DC Resistance at 20 °C (M $\Omega$ *Km)	200
Rated Temperature(°C)	85
Rated Voltage (V)	1000