

This is a sample photo.


**ORDER SYMBOL:** AL 061505

**EL.number** **EAN:** 6418074004109  
 Sweden: 2536309  
 Denmark: 8212004634  
 Finland: 3423607

**INCLUDING:**  
 Enclosure body, cover with PUR gasket, cover screws, and 2 earth screws.

**APPROVALS:**  
 USA: UL Type 1, 4, 4X, 12, 13 (E75645 Vol.1 Sec.6)  
 EURO: IP 67/IP 66  
 OTHERS: IEC 529

FIBOX EURONORM II AL

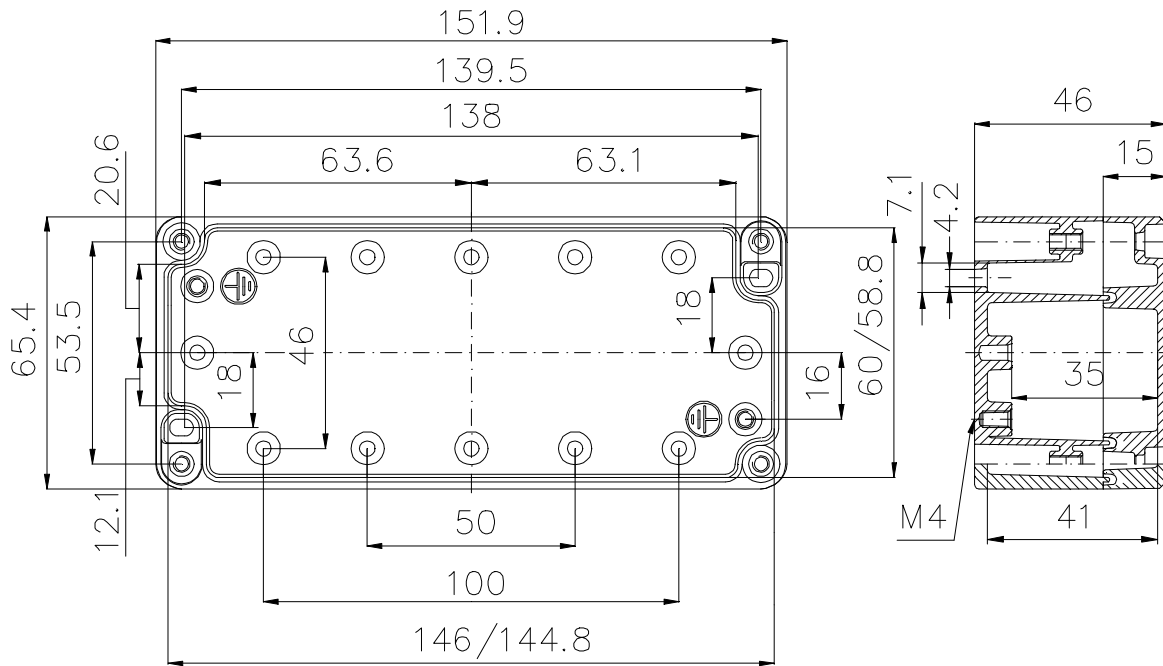

**TECHNICAL INFORMATION:**

Standard colour: RAL 7001  
 Ingress protection: IP 67 (IEC 529)  
 Flame resistance:

Temp.range in cont. use: Max. +80 °C  
 Temp. range of material: - 50 °C - + 120 °C

**ACCESSORIES**

DIN-Rail	ARH 12	DIN-Rail	ARH 26	DIN-Rail	ARM 0818
DIN-Rail	ARH 16	DIN-Rail	ARH 36	DIN-Rail	ARM 0825
DIN-Rail	ARH 1636	DIN-Rail	ARH 40	Fastening lug	MRS 28540
DIN-Rail	ARH 1656	DIN-Rail	ARH 60	Fastening lug	MRS 28541
DIN-Rail	ARH 22	DIN-Rail	ARM 0610		
DIN-Rail	ARH 2320	DIN-Rail	ARM 0615		
DIN-Rail	ARH 2328	DIN-Rail	ARM 0808		
DIN-Rail	ARH 2333	DIN-Rail	ARM 0813		