


Deep groove ball bearings, single row, shield on both sides

Product information



Tolerances , see also text
Radial internal clearance , see also text
Recommended fits
Shaft and housing tolerances

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	* - SKF Explorer bearing
70	125	24	63,7	45	1,9	11000	5600	1,10	6214-2Z *

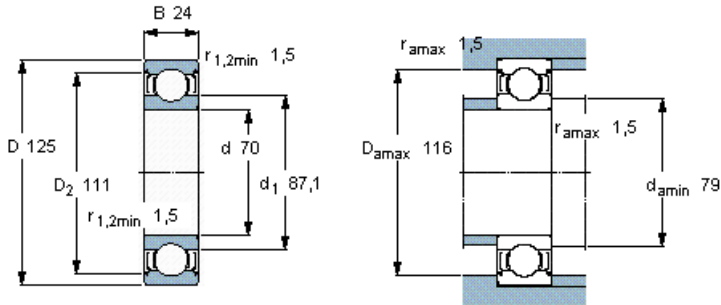

Calculation factors

k_f 0,025
 f_0 15