
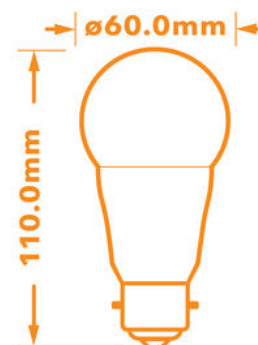


Verbatim LED Classic A B22 12W 3000K Warm White 1100 LM


- B22 Socket
- 220 - 240 V Voltage
- 30,000 hours Lifetime
- 84% Energy Saving
- Lumen: 1100
- Equivalent to 77W incandescent bulb

Product Number	52154
General Data	
Lamp Socket	B22
Electric Data	
Wattage (W)	12
Wattage Equivalent (W)	77
Voltage (V)	220 - 240 V
Dimmable	no
Power Factor	0.90
Operating Frequency (Hz)	50-60
Geometric Data	
Length (mm)	110
Diameter (in mm)	60
Weight (g)	175
Photometric Data	
Luminous Flux (lm)	1100
CRI	≥ 80
CCT (K)	3000
Beam Angle (°)	130
Luminous Efficacy (lm/W)	91.7
Lifetime (hrs)	30,000
Switching Cycle	20,000

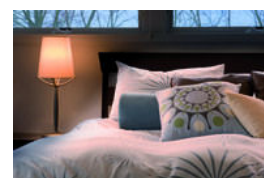


02/07/2014

Photometric Diagrams

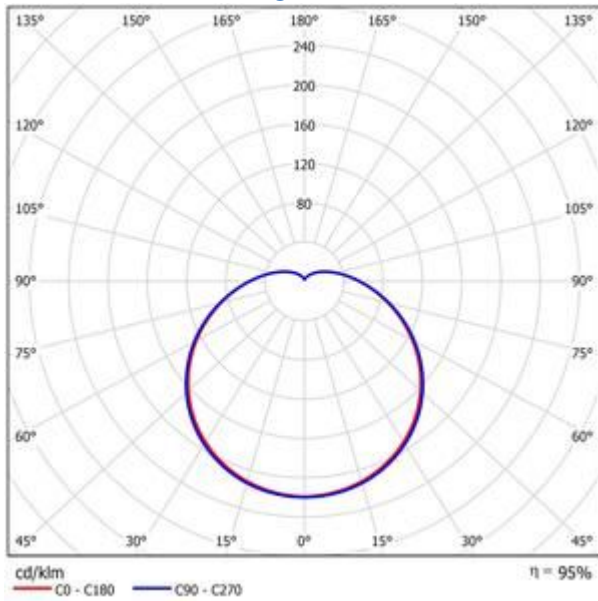

Energy Rating

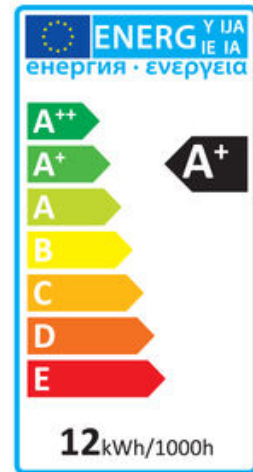

Technical Packaging Details

Barcode

023942521549

EAN 128

(02)00023942521549(37)04(91)204

EAN 14

50023942521544

Pack Dimensions(HxWxL)

178 x 118 x 61

Pack Weight

201

MOQ

4

Carton Dimensions (HxWxL)

195 x 144 x 253

Cartons/Pallet

80

Layers/Pallet

4

Units/Pallet

320

02/07/2014