


ABUS Mini Dome Camera (TVVR31100D)




Bilddaufnehmer / Image sensor / Capteur d'images / Beeldopnemer / Billedoptager	1/4" CMOS DIS
TVL / Lignes TV / TV-lijnen / Tv-linjer	500 TVL
Bildelemente (effektiv) / Picture elements (effective) / Pixels (utiles) / Beeldelementen (effectief) / Billedelementer (effektive)	640 x 480
TV Standard / Norme	PAL / NTSC
Mindestbeleuchtung (Farbe) / Min. illumination (color) / Eclairage minimum (jour) / Minimale verlichting (dag) / Minimumbelysning (dag)	0,28 Lux @ F2.0
Mindestbeleuchtung (Nacht) / Minimum illumination (night) / Eclairage minimum (nuit) / Minimale verlichting (nacht) / Minimumbelysning (nat)	-
Objektiv / Lens / Objectif / Objectief	3,6mm
Horizontaler Blickwinkel / Horizontal viewing angle / Angle de vue horizontal / Horizontale gezichtshoek / Horizontal synsvinkel	54°
Betriebstemperatur / Operating temperature / Température de fonctionnement / Bedrijfstemperatuur / Driftstemperatur	-10°C – 55°C
Spannungsversorgung / Power supply / Alimentation / Spanningsvoorziening / Nominel forsyningsspænding	12 VDC (<100mA)
Gewicht / Weight / Poids / Vægt	300g

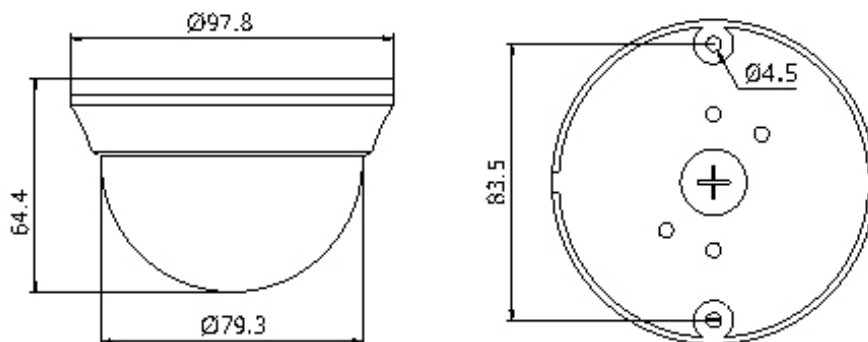


Unit: mm


1)

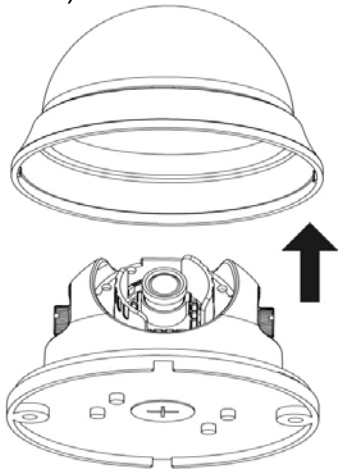

2)

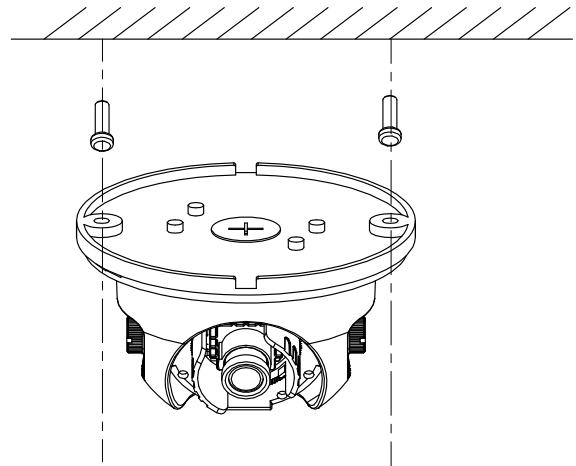

2)

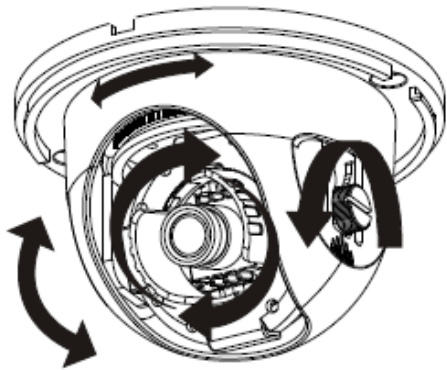

4)

