



MASTER SDW-TG Mini

MASTER SDW-TG Mini 100W/825 GX12-1 1CT

Range of high-efficiency, discharge lamps with warm colour to be used in small, open luminaires designed around MASTERColour CDM-T lamps

Product data

• General Characteristics

System Description	-
Cap-Base	GX12-1
Bulb	T19 [T 19mm]
Bulb Material	-
Bulb Finish	Clear
Burning Position	any [Any/Universal]
Life to 5% failures	5000 hr
Life to 20% failures	8000 hr
Life to 50% failures	10000 hr

• Light Technical Characteristics

Colour Code	825 [CCT of 2500K]
Colour Rendering Index	80 (min), 83 (nom) Ra8
Colour Designation	Golden White
Colour Temperature	2500 K
Colour Temperature Technical	2500 K
Lamp Luminous Flux EL	4900 Lm
Lamp Luminous Efficiency EL	50 Lm/W
Lumen Maintenance 2000h	95 %
Lumen Maintenance 5000h	80 %
Lumen Maintenance 10000h	75 %
Chromaticity Coordinate X	469 -
Chromaticity Coordinate Y	406 -

• Electrical Characteristics

System Power EL	112 W
Lamp Wattage	100 W
Lamp Wattage EL 25°C, Rated	99.0 W
Lamp Wattage EL 25°C, Nominal	100.0 W
Lamp Voltage	91 V
Lamp Current EL	1.1 A
Ignition Time	60 (max) s
Run-up time 90%	2 (max) min
Re-ignition Time [min]	1.5 (max) min
Dimmable	no

• Environmental Characteristics

Energy Efficiency Label (EEL)	B
Mercury (Hg) Content	13 mg
Energy consumption kWh/1000h	110 kWh

• Luminaire Design Requirements

Cap-Base Temperature	280 (max) °C
Pinch Temperature	350 (max) °C
Bulb Temperature	650 (max) °C

• Product Dimensions

Reference Length A	96 (max) mm
Overall Length C	110 (max) mm
Diameter D	20 (max) mm

PHILIPS

MASTER SDW-TG Mini

Light Center Length L	54.5 (min), 56 (nom), 57.5 (max) mm
Arc Length O	18 mm
Light Center Length L [inch]	4.2 in
Overall Length C	12.84375 (max) in
Diameter D [inch]	0.75 in

• **Product Data**


Order code	202338 15
Full product code	871150020233815
Full product name	MASTER SDW-TG Mini 100W/825 GX12-1 1CT

Order product name	MST SDW-TG Mini 100W/825 GX12-1 1CT/12
Pieces per pack	1
Packing configuration	12
Packs per outerbox	12
Bar code on pack - EAN1	8711500202338
Bar code on outerbox - EAN3	8711500202345
Logistic code(s) - 12NC	928158905131
ILCOS code	STH-100/25/1B-GX12-1
Net weight per piece	0.030 kg

Warnings and Safety


- Use only with dedicated Philips control gear

Dimensional drawing

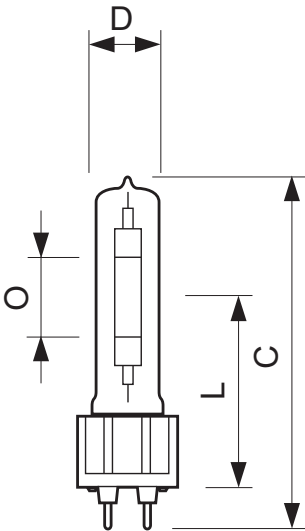


MASTER SDW-TG Mini 100W/825 GX12-1 1CT

Product	C (Max)	D (Max)	L (Min)	L (Norm)	L (Max)	O (Norm)
SDW-TG 100W/825 GX12-1	110	20	54.5	56	57.5	18

 

GX12-1

Photometric data

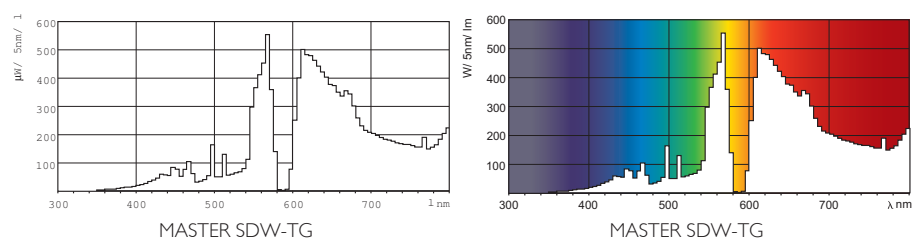

© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, October 31
data subject to change