

This is a sample photo.


ORDER SYMBOL: SC 2819 18 TII

EL.number **EAN:** 6418074036513
 Sweden:
 Denmark:
 Finland: 3422517

INCLUDING:
 Cabinet body, cover, hinges, quick-lock screws, and mounting screws.

APPROVALS:
 USA: NEMA 4, 4X, 12; UL 94-V0
 EURO: IP 65; UL 94-V0
 OTHERS: IEC 529, CE, EEI, SETI 163458-01

FIBOX SOLID SC II

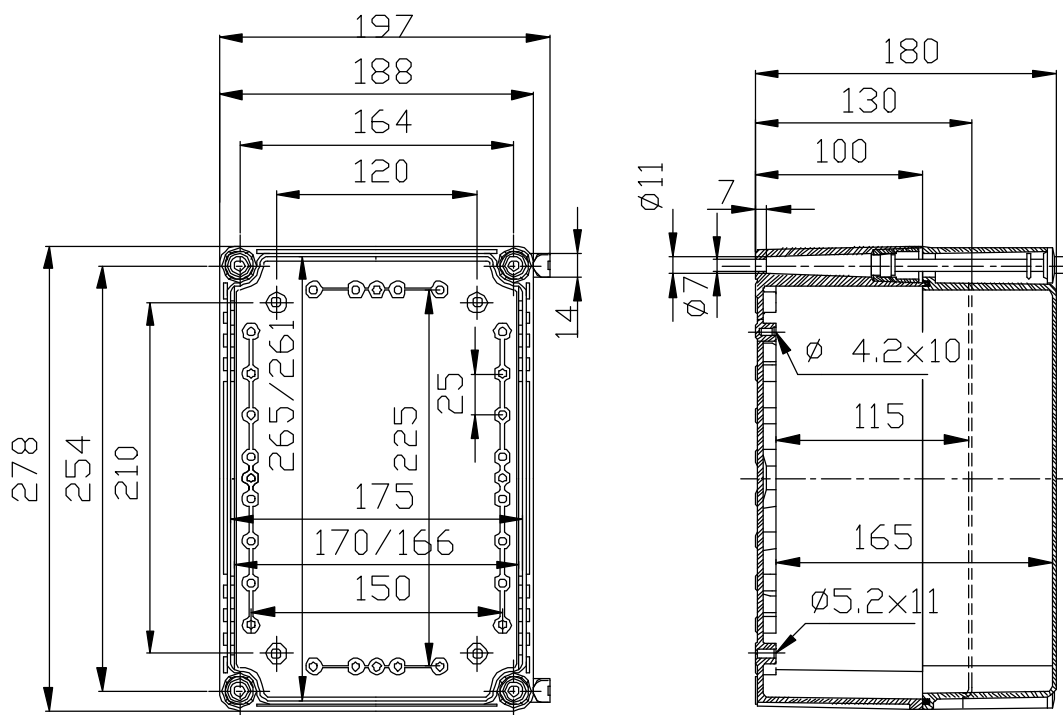

TECHNICAL INFORMATION:

Standard colour: RAL 7035	Temp.range in cont. use: Max. +80 °C
Ingress protection: IP 65 (IEC 529)	Temp. range of material: - 40 °C - + 120 °C
Flame resistance:	

ACCESSORIES

- | | | | |
|-------------------|----------|---------------|----------|
| DIN-Rail | EKV 12 | Earth bar set | MR 26059 |
| DIN-Rail | EKV 14 | | |
| DIN-Rail | EKV 22 | | |
| DIN-Rail | EKV 24 | | |
| DIN-Rail | EKV 32 | | |
| DIN-Rail | EKV 34 | | |
| Corner plug | MB 10523 | | |
| Fastening lug | MB 10674 | | |
| Earth bar support | MB 26069 | | |

(c) FIBOX Oy Data subject to change without notice.