

**Bolt-type screw terminals
WFF 300****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 1429-0

Fax: +49 5231 14292083

www.weidmueller.com

**Klippon® Connect with stud Technology**

Our stud terminals are an established, robust connection alternative for particularly harsh environments. The extensive accessories and quality workmanship ensure high productivity in planning and installation – and sustainable safety in operation..

General ordering data

Type	WFF 300
Order No.	1028700000
Version	Bolt-type screw terminals, Feed-through terminal, Rated cross-section: 300 mm ² , Threaded stud connection
GTIN (EAN)	4008190165017
Qty.	4 pc(s).

Bolt-type screw terminals WFF 300

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Technical data

Dimensions and weights

Width	55 mm	Width (inches)	2.165 inch
Height	163 mm	Height (inches)	6.417 inch
Depth	85.5 mm	Depth (inches)	3.366 inch
Depth including DIN rail	94 mm	Weight	552.15 g
Net weight	534.14 g		

Temperatures

Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	120 °C
----------------------------------	--------	----------------------------------	--------

Material data

Material	Wemid	Colour	Dark Beige
UL 94 flammability rating	V-0		

Rating data IECEx/ATEX

Certificate No. (ATEX)	KEMA98ATEX1684U	ATEX certificate	IECEXKEM07.0053U
ATEX certificate	KEMA98ATEX1684U_e.pdf	Certificate No. (IECEX)	IECEXKEM07.0053U
IEC Ex certificate	IECEXKEM07.0053U_e.pdf	Max. voltage (ATEX)	1100 V
Current (ATEX)	452 A	Wire cross section max. (ATEX)	300 mm ²
Max. voltage (IECEX)	1100 V	Current (IECEX)	452 A
Wire cross section max. (IECEX)	300 mm ²	Voltage, cross-connection	CrossConnectionGuide.pdf
Operating temperature range	For operating temperature range see EC Design Test Certificate / IEC Ex-Certificate of Conformity	Marking EN 60079-7	
Ex 2014/34/EU label	II 2 G D		Ex e II

System specifications

End cover plate required	No	Number of levels	1
No. of clamping points per level	2	Levels cross-connected internally	No
PE connection	No	Mounting rail	TS 35

Additional technical data

Explosion-tested version	Yes	Number of similar terminals	1
Open sides	closed	Type of mounting	Snap-on

CSA rating data

Certificate No. (CSA)	200039-1244019	Current size C (CSA)	510 A
Voltage size C (CSA)	600 V	Wire cross section max. (CSA)	600 kcmil
Wire cross section min. (CSA)	6 AWG		

Bolt-type screw terminals WFF 300

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Technical data

Conductors for clamping (rated connection)

2 x cable lugs DIN 46 234	25...240 mm ²	Cable lug to DIN 46234	25...240 mm ²
Cable lug to DIN 46235	50...300 mm ²	Clamping range, bolted connection , max.	300 mm ²
Clamping range, bolted connection , min.	25 mm ²	Clamping range, rated connection, max.	300 mm ²
Clamping range, rated connection, min.	25 mm ²	Number of connections	2
Stud size for spade connection	M16	Tightening torque, max.	60 Nm
Tightening torque, min.	25 Nm	Type of connection	Threaded stud connection
Wire connection cross section, finely stranded, max.	240 mm ²	Wire connection cross-section, finely stranded, min.	25 mm ²

Rating data

Rated cross-section	300 mm ²	Rated voltage	1,000 V
Rated current	520 A	Current at maximum wires	520 A
Volume resistance according to IEC 60947-7-x	0.06 mΩ	Rated impulse withstand voltage	8 kV
Pollution severity	3		

UL rating data

Certificate No. (UR)	E60693	Conductor size Factory wiring max. (UR)	600 kcmil
Conductor size Factory wiring min. (UR)	6 AWG	Conductor size Field wiring max. (UR)	600 kcmil
Conductor size Field wiring min. (UR)	6 AWG	Current size C (UR)	500 A
Voltage size C (UR)	1000 V		

Classifications

ETIM 3.0	EC002020	ETIM 4.0	EC002020
ETIM 5.0	EC002020	ETIM 6.0	EC000897
UNSPSC	30-21-18-01	eClass 6.2	27-14-11-20
eClass 7.1	27-14-11-20	eClass 8.1	27-14-11-20
eClass 9.0	27-14-11-20	eClass 9.1	27-14-11-20

Product information

Descriptive text ordering data	1000 VDC rated voltage tested.
Descriptive text technical data	1000 V UL and CSA for usage groups B and C: can be used with isolating terminal rails and when using WTW-type partitions.
Descriptive text accessories	WAH 185/300 in blue, Order no. 1064780000

Approvals

Approvals



ROHS

Conform

Bolt-type screw terminals WFF 300

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Technical data

Downloads


Certificate of conformity	CFAT_WFF 300.pdf
Engineering data	EPLAN, WSCAD, Zuken E3.S
Declaration of Conformity	DE_PT1004_20160418_869_ISSUE01.pdf

Bolt-type screw terminals WFF 300

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 1429-0
 Fax: +49 5231 14292083
 www.weidmueller.com

Accessories

Blank

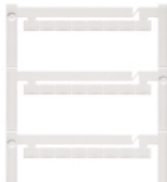

The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.


Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
DEK 5/7.5 MC	1720620000	Dekafix, Terminal marker, 5	4008190362300	320 pc(s).
NE WS		x 7.5 mm, Pitch in mm (P): 7.50 Weidmueller, White		

Blank

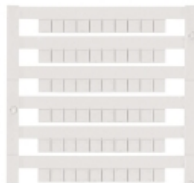

The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
DEK 5/5 MC	1609801044	Dekafix, Terminal marker, 5	4008190397111	1,000 pc(s).
NE WS		5 x 5 mm, Pitch in mm (P): 5.00 Weidmueller, White		

Bolt-type screw terminals WFF 300

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 1429-0
 Fax: +49 5231 14292083
 www.weidmueller.com

Accessories

Group tag holders for S10



The various terminal markers from Weidmüller enable users to solve virtually every labelling task on all types of lines. Whether several lines of labelling, ready-to-use markers with standard printing, or individual labelling, whether white or coloured markers or common designations at the clamping points, the comprehensive range of products represent the easy, quick and clear answer to every marking task.

General ordering data

Delivery status	Available until	Type	Order No.	Version	GTIN (EAN)	Qty.
Discontinued	2014-01-01T00:00:00+01:00	WT 4 F.S10	1341060000	Group marker, Terminal marker, 10.1 x 5 mm, Pitch in mm (P): 5.00 White	4008190163648	100 pc(s).
Discontinued	2014-08-31T00:00:00+02:00	T 4 F. S10 WEISS	0332100000	Group marker, Terminal markers, Terminal marker, 10.3 x 5 mm, Pitch in mm (P): 5.00 White	4008190024437	100 pc(s).
Discontinued	2014-09-30T00:00:00+02:00	T 3 F. S10 WEISS	0383000000	Group marker, Terminal markers, Terminal marker, 7.8 x 5 mm, Pitch in mm (P): 5.00 White	4008190015169	100 pc(s).
Discontinued	2014-01-01T00:00:00+01:00	T 6 F. S 10 WEISS	0332200000	Group marker, Terminal markers, Terminal marker, 15.1 x 5 mm, Pitch in mm (P): 6.00 White	4008190072155	100 pc(s).
Discontinued	2014-01-01T00:00:00+01:00	T 5 F. S10 WEISS	0348500000	Group marker, Terminal markers, Terminal marker, 12.6 x 5 mm, Pitch in mm (P): 5.00 White	4008190093273	100 pc(s).

Bolt-type screw terminals WFF 300

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Accessories

Slotted screwdriver

VDE insulated slot-head screwdriver, SDI DIN 7437, ISO 2380/2, drive output acc. to DIN 5264, ISO 2380/1. SoftFinish grip



General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
SDIS 0.6X3.5X100	9008390000	Screwdriver, Blade width (B): 3.5 mm, Blade length: 100 mm, Blade thickness (A): 0.6 mm	4032248056354	1 pc(s).

End brackets



Klippon® Connect with clamping yoke Technology
The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
WEW 35/1	1059000000	W-Series, End bracket	4008190172282	50 pc(s).

Cover hoods



Klippon® Connect with stud Technology
Our stud terminals are an established, robust connection alternative for particularly harsh environments. The extensive accessories and quality workmanship ensure high productivity in planning and installation – and sustainable safety in operation..

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
WAH 185/300 BL	1064780000	Bolt-type screw terminals, Hood, Blue, 54 mm	4008190103200	10 pc(s).

Bolt-type screw terminals WFF 300

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 1429-0
 Fax: +49 5231 14292083
 www.weidmueller.com

Accessories

WAH [1064760000](#)
 185/300 BE

Bolt-type screw terminals, 4008190108267 10 pc(s).
 Hood, Beige, 54 mm

Cross-connections



Klippon® Connect with stud Technology

Our stud terminals are an established, robust connection alternative for particularly harsh environments. The extensive accessories and quality workmanship ensure high productivity in planning and installation – and sustainable safety in operation..

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
WQL 3 WFF300	1065800000	Bolt-type screw terminals, Cross-connector, No. of poles: 3	4008190031312 5 pc(s).	
WQL 2 WFF300	1065300000	Bolt-type screw terminals, Cross-connector, No. of poles: 2	4008190110000 5 pc(s).	

Blank



WS markers are the perfect match for the W-series connectors. Thanks to their system compatibility, the WS tags can also be used with the I-series and the Z-series. The large marking surfaces do not only permit long character strings but also multi-line text. WS markers are ideal for labels with long, customised character strings. Thanks to the proven MultiCard format, printing with laser printer, PrintJet ADVANCED, plotter or MC-Mobilo is possible.

- Can be fitted in strips or individually
- Markers in proven MultiCard format

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
WS 12/6.5 MC NE WS	1609920000	WS, Terminal marker, 12 x 6.5 mm, Pitch in mm (P): 6.50 Weidmueller, Allen- Bradley, White	4008190203511 540 pc(s).	

Addresses worldwide

Let's connect.

AE United Arab Emirates
Weidmüller Middle East FZE
Warehouse Q3-79
SAIF-Zone
P.O. BOX 8591
Sharjah
Telephone number +971 65572723
Fax number +971 65572724
wme.info@weidmuller.com

AF Afghanistan
Representative Office

AF 11050 Beograd
Telephone number +381 11 2885 274
Fax number +381 11 2885 274
zoran.rabrenovic@weidmuller.com

AO Angola
Please contact
Phambili Interface
South Africa

AR Argentina
CPI SA
Bauness 2660
C1431DOF Buenos Aires
Telephone number +54 11 4523 8008
Fax number +54 11 4522 0546
info@cpi.com.ar
www.cpi.com.ar

AT Austria
Weidmüller GmbH
IZ NOE Süd, Str 2b, Obj M59,
2355 Wiener Neudorf
Telephone number +43 2236 67080
Fax number +43 2236 6708-899
office.at@weidmuller.com
www.weidmuller.com

AU Australia
Weidmüller Pty. Ltd.
PO BOX 6944
Huntingwood 2148
Huntingwood Drive 43
Huntingwood NSW 2148
Telephone number +61 2 9671 9999
Fax number +61 2 9671 9911
info@weidmuller.com.au
www.weidmuller.com.au

AZ Azerbaijan
Representative Office
Weidmüller Interface
Demirchi Tower, 4th floor
37, Khojali ave.
AZ 1025 Baku
Telephone number +994 12 488 80 36
Fax number +994 12 488 80 37
aliyar.hashimli@weidmuller.com

BA Bosnia and Herzegovina
Please contact
our Representative Office
Weidmüller Interface GmbH
& Co. KG
Serbia

or
BH ES Elektrosistem d.o.o.
Palih boraca 104
78000 Banja Luka
Telephone number +387 51 420 340
Fax number
elsist@inecco.net
www.elektrosistem.ba
BIG electric d.o.o
Mladena Stojanovića 117A
78000 Banja Luka
Telephone number +387 51926277
Fax number +387 51926277
bigelectric@blic.net
www.bigelectric.ba

BE Belgium
Weidmüller Benelux B. V.
Mechelsesteenweg 519 bus
6 en 7
1930 Nossegem
Telephone number +32 2 752 40 70
Fax number +32 2 751 36 06
info@weidmuller.be
www.weidmuller.be

BG Bulgaria
Weid-Bul EOOD
Bul. „Kliment Ohridski“ 13
1756 Sofia
Telephone number +359 2 963 2560
Fax number +359 2 963 1098
sofia@weidbul.com
www.weidbul.com

BH Bahrain
Khayber Trading Company
P.O Box 1976
Manama
Telephone number +973 720747
Fax number +973 720331
khayber@batelco.com.bh

BR Brazil
Weidmüller Conexel do Brasil
Conexões Elétricas Ltda.
Av. Presidente Juscelino, 642
- Piraporinha
Diadema, São Paulo
09950-370
Telephone number +55 (11) 4366-9600
Fax number +55 (11) 4362-1677
vendas@weidmuller.com.br
www.weidmuller.com.br

BW Botswana
Please contact
Phambili Interface
South Africa

BY Belarus
TECHNIKON Ltd.
Nezavisimosti pr. 177-9
220125 Minsk
Telephone number +375 17 393-11-77
Fax number +375 17 3930080
wm@technikon.by

CA Canada
W Interconnections Canada Inc.
10 Spy Court
Markham Ontario L3R 5H6
Telephone number +1 (905) 475-1507 Ext. 9836
Fax number +1 (905) 475-2798
support@weidmuller.ca
www.weidmuller.ca

CG Congo
Please contact
Phambili Interface
South Africa

CH Switzerland
Weidmüller Schweiz AG
Rundbuckstraße 2
8212 Neuhausen am
Rheinfall SH
Telephone number +41 52 674 07 07
Fax number +41 52 674 07 08
info@weidmuller.ch
www.weidmuller.ch

CL Chile
CPI CHILE LTDA
Av. Presidente Frei Montalva
6001, 47 complejo el cortijo
Santiago - Conchalí
Telephone number +562 963 8440
Fax number +562 963 8440
cpi@cpichile.cl
www.cpicchile.cl

CN China
Weidmüller Interface
(Shanghai) Co. Ltd.
100 Yutong Road
25 F. BM Intercontinental
Business Center
200070 Shanghai
Telephone number +86 21-22195008
Fax number +86 21-22195009
customer.hotline@weidmuller.com.cn
www.weidmuller.com.cn

CO Colombia
Automatización Avanzada S. A.
Carrera 97 No., 24 c - 23
Bodega 4
110911 Bogotá-D.C.
Telephone number +57 (1) 547-8510
Fax number +57 (1) 422-3044
comercial@automatizacionavanzada.com
www.automatizacionavanzada.com

CR Costa Rica
ELVATRON S. A.
la Uruca 400 Norte Banco
Costa Rica
San Jose Costa Rica
Telephone number +506 2961-060
Fax number +506 5200-609
dirk.haase@elvatron.com
www.elvatron.com

CZ Czech Republic
Weidmüller s.r.o.
Lomnického 5/1705
140 00 Praha 4
Telephone number +420 244 001 400
Fax number +420 244 001 499
office@weidmuller.cz
www.weidmuller.cz

DE Germany
Weidmüller GmbH & Co. KG
Ohmstraße 9
32758 Detmold
Postfach 30 54
32720 Detmold
Telephone number +49 5231 1428-0
Fax number +49 5231 14-292083
weidmuller@weidmuller.de
www.weidmuller.de

DK Denmark
Weidmüller Danmark
Vallensbækvej 18A
2605 Brøndby
Telephone number +45 27747800
kundeservice@weidmuller.dk
www.weidmuller.dk

DZ Algeria
SARL INTER ELECTRIC
1a Angles des Rues Okba Ibn
Nafaa et Hassi Beida
2300 Annaba
Telephone number
Fax number
contact@inter-electric.com

EC Ecuador
Elsystec S. A., Electricidad
Sistemas y Tecnología
Vasco de Contreras N35-251
y Mañosca
Quito - Pichincha
Telephone number +593 22456510
Fax number +593 22456755
Elsystec@uio.satnet.net

EE Estonia
Please contact
our Representative Office
Weidmüller Interface GmbH
& Co. KG
Latvia

or
SLO Eesti AS

11415 Tallinn
Telephone number +372 6 272 200
Fax number
info@slo.ee

SLO Eesti AS

12618 Tallinn
Telephone number +372 622 9119
Fax number
elit@elit.ee

Soots Interface OÜ
Pärnu mnt 142
11317 Tallinn
Telephone number +372 609 6933
Fax number
info@sootsinterface.ee
www.sootsinterface.ee

EG Egypt
Standard Electric (OMEGA)
1, Abdelhamid Badawy Street
Heliopolis
Cairo
Telephone number +202 21805111
Fax number +202 21805600
stdelec@rite.com

ES Spain
Weidmüller, S. A.
Narcis Monturiol 11-13, Pol.
Ind. Sudoeste
8960 Sant Just
Desvern - Barcelona
Telephone number +34 934 803 386
Fax number +34 933 718 055
weidmuller@weidmuller.es
www.weidmuller.es

FI Finland
Weidmüller Suomi,
Weidmüller Aktiebolagetin
sivuliike
Koy Plaza Vivace
Äyritie 8C
FI 1510 Vantaa
Telephone number +358 20 7351300
Fax number +358 800 114 667
asiakaspalvelu@weidmuller.fi
www.weidmuller.fi

FR France
Weidmüller E. U. R. L.
2 Boulevard de l'Oise
CS 31100 CERGY
95095 CERGY PONTOISE
Cedex
Telephone number +33 1 34 24 55 00
Fax number +33 1 34 24 55 01
mail@weidmuller.fr

GB Great Britain
Weidmüller Ltd.
Klippon House
Centurion Court Office Park,
Meridian East, Meridian
Business Park
Leicester
LE19 1TP
Telephone number +44 116 282 3470
Fax number +44 116 289 3582
marketing@weidmuller.co.uk
www.weidmuller.co.uk

GE Georgia
Please contact
our Representative Office
Weidmüller Interface
Azerbaijan.

GH Ghana
Please contact
our Representative Office
Weidmüller Interface GmbH
& Co. KG
South Africa.

GR Greece
G.A. Solutions
Ippokratous 11 Metamorfosi
144 52 Athens
Telephone number +30 210 2823233
Fax number +30 210 2823233
info@weidmuller.gr
www.weidmuller.gr

GT Guatemala
Prestelectro, Prestegard
Electro, S.A.
Avenida Petapa 44-22,
Zona 12
Guatemala City
Telephone number +502 2442-3346
Fax number +502 2476-8945
ventas@prestelectro.com

HK Hong Kong
Weidmüller (Hong Kong)
Limited Co. Ltd.
Unit 1617, Metropolis Tower
No. 10 Metropolis Drive,
Hung Hom, Kowloon
Telephone number +852 3154 8088
Fax number +852 31548099
Info-hk@weidmuller.com.hk

HR Croatia
ElektroPARTNER d.o.o.
Slavonska avenija 24/6
HR-10000 Zagreb
Telephone number +385 (1) 6184 793
Fax number +385 (1) 6184 795
elektropartner@zg.t-com.hr
www.elektropartner.hr

HU Hungary
Weidmüller Kereskedelmi Kft.
Budapest
Gubacsi út 6.
1097
Telephone number +36 1 382 7700
Fax number +36 1 382 7701
info@weidmuller.hu
www.weidmuller.hu

ID Indonesia
PT. Nego Electrindo
Ruko Mega Grosir Cempaka
Mas Blok I No. 20 - 22
Jakarta 10640
Telephone number +62 21 42882255
Fax number +62 21 42882266
sales@negoelectrindo.co.id

IE Ireland
Please contact
Weidmüller Ltd.
Great Britain

IL Israel
A. U. Shay Ltd.
23/25, Embarr Street
49222 Petach-Tikva
P.O. Box 1 00 49
49222 Petach-Tikva
Telephone number +972 3-923-3601
Fax number +972 3-923-4601
shay@uriel-shay.com
www.uriel-shay.com
ATEKA Ltd.
4, Ha Tavor lane Industrial
area Segula
49691 Petach-Tikva
P.O. Box 4710
Petach-Tikva
Telephone number +972 73-200-1311
Fax number +972 3-924 4245
marketing@ateka.co.il
www.ateka.co.il



You can find all Weidmüller addresses and your local contact on the internet at: www.weidmuller.com/countries

Let's connect.

Sales company 

Representation abroad 

without representation abroad 

IN India Representative Office Weidmüller Electronics India Pvt. Ltd. No. 9, Union Street, Off. Infantry Road BANGALORE 560 001 Telephone number +91-80-22860028 wmi@weidmuller.in www.weidmuller.com	KW Kuwait Kana Controls General Trading & Contracting Co. W. L. L. Al Rai Industrial Area, Plot 28-30, St. 31 13016 Safat B.P. 25593 Telephone number +965 4741373 Fax number +965 4741537 info@kanacontrols.com Petroleum Services Co. W.L.L. Kuwait Trade Free Zone Area P.O. Box 4098 Safat 13041 Telephone number +96524610801/2/3 ext. 208 II Fax number +96524613754 psc-systems@petserv.net	MD Moldova Inoxpa Solutions SRL 20, Igor Vieru street MD-2075 Chisinau Moldova Telephone number +373 (22) 866665 Fax number +373 (22) 866663 atiuleanu@gmp-moldova.com www.gmp-moldova.com	NA Namibia Please contact Phambili Interface South Africa	PK Pakistan Automation Controls (Pak) Apartment No. 33 C III, Chensab Block, Allama Iqbal Town Lahore Telephone number +92 42 37809948 Fax number +92 42 37809950 nadeem@acpak.com.pk www.acpak.com.pk
IR Iran Representative Office Tamin Ehtajat Fanni Tehran (TAF Co.) No. 36, West 4th St., Ettehad Ave. Damavand Rd. Tehran - 1658674583, Iran Telephone number +9821 77120809 info@taf-co.com http://www.taf-co.com	KZ Kazakhstan Please contact Weidmüller Group Russia	ME Montenegro Please contact our Representative Office Weidmüller Interface GmbH & Co. KG Serbia.	NG Nigeria Please contact Weidmüller Interface GmbH & Co. KG South Africa	PL Poland Weidmüller Sp. z o. o. ul. Ogrodowa 58 00-876 Warszawa Telephone number +48 22 510 09 40 Fax number +48 22 510 09 41 biuro@weidmuller.com.pl www.weidmuller.pl
IS Iceland Samey Automation Center Lyngas 13 210 Garoabaer Telephone number +354 510 5200 Fax number +354 5 10 5201 Samey@samey.is www.samey.is	LB Lebanon Progress Engineering & Trading Enterprises Al Nahr Street Beirut 11-1111 Telephone number +961 1 444 664 Fax number +961 1 561 880 progress@inco.com.lb	MG Madagascar Please contact Phambili Interface South Africa	NL Netherlands Weidmüller Benelux B. V. Franciscusweg 221 1216 SE Hilversum P.O. Box 1505 1200 BM Hilversum Telephone number +31 35 626 12 61 Fax number +31 35 623 20 44 info@weidmuller.nl www.weidmuller.nl	PR Puerto Rico Please contact W Interconnections Inc. United States
IT Italy Weidmüller S. r.l. Via Albert Einstein 4 20092 Cinisello Balsamo Milano Telephone number +39 02 680681 Fax number +39 02 6124945 weidmuller@weidmuller.it www.weidmuller.it	LT Lithuania Please contact our Representative Office Weidmüller Interface GmbH & Co. KG Latvia or ELEKTROS IRANGA Tinklų g. 29 a LT-5319 Panevezys Telephone number +370 (45) 582 828 Fax number +370 (45) 582 727 info@eliranga.lt UAB „SLO Lithuania“ Vilkipėdės g. 4 LT-LT-03151 Vilnius Telephone number +370 5 215 00 70 Fax number +370 5 215 00 71 biuras@slo.lt	MK Macedonia Please contact our Representative Office Weidmüller Interface GmbH & Co. KG Serbia or ELEKTRO - SMK dooel UL. III Makedonska brigada b.b. 1000 Skopje Telephone number +389 22460295 Fax number Elektro-smk@telekabel.net.mk	NO Norway Sivilingeniør J.F. Knudtzen AS Billingstadsletta 97 1396 Billingstad PO Box 160 1378 Nesbru Telephone number +47 66 98 33 50 Fax number +47 66 98 09 55 firmapost@jfkudtzen.no www.jfkudtzen.no	PT Portugal Weidmüller Sistemas de Interface S. A. Estrada Outeiro Polima, R. Augusto Dias da Silva, Lote B - Esc. 2 São Domingos de Rana 2785-515 Abóboda Telephone number +351 214 459 191 Fax number +351 214 455 871 weidmuller@weidmuller.pt www.weidmuller.pt
JM Jamaica Please contact W Interconnections Inc. United States	LU Luxembourg Please contact Weidmüller Benelux B. V. Netherlands	MT Malta E. S. S., Electrical Supplies & Services Ltd. San Gwakkim Road Mrieħel Telephone number +356 21255777 Fax number +356 21255999 robert.agius@ess.com.mt	NZ New Zealand Cuthbert S. Steward Ltd. 27 Te Puni Street Petone PO Box 38496 Wellington Mail Centre 5054 Telephone number (04) 568 6156 Fax number (09) 489 1752 csl@cuthbertstewart.co.nz Cuthbert S. Steward Ltd 4 Fred Thomas Drive Aon Building, Ground Floor, South Entry Takapuna PO Box 100 338 North Shore City 745 Telephone number (09) 489 1751 Fax number (04) 568 6056 cslak@cuthbertstewart.co.nz	PY Paraguay Please contact CPI SA Argentina
JO Jordan Billeh Electricals Mat. Co. PO Box 4343 Amman Telephone number +962 6 4656 987 Fax number +962 6 4649 216	LV Latvia SIA Abi4 Daugavgrivas 49 k3 Riga, LV-1007 Telephone number +371 674 70999 Fax number abi_4@tvnet.lv	MU Mauritius Mubelo Electrical Ltd. Office 26, Gateway building, St Jean Road Quatre Bornes Mauritius Telephone number +230 4670989 Fax number +230 4654051 richard.mubelo@orange.mu	OM Oman DAN INTERNATIONAL LLC. Ghala St. 111 BP 2901 Seeb Telephone number +968 5036 77 Fax number +968 5037 55 yedu@danintl.com	QA Qatar Doha Motors PO Box 145 Telephone number +974 4651441 Fax number +974 4654579 dmtctech@qatar.net.qa http://www.dohamotorsgroup.com/td.html
JP Japan Nihon Weidmüller Co. Ltd. Sphere Tower Tennoz 2-2-8 Higashi-Shinagawa, Shinagawa-ku Tokyo 140-0002 Telephone number +81 3 6711 5300 Fax number +81 3 6711 5333 info@weidmuller.co.jp www.weidmuller.co.jp	RO Romania Representative Office Weidmüller Interface GmbH & Co. KG Ionescu Crum Street, No. 1, 1st Tower, 1st Floor, Office 4 500446 Brasov - Brasov Business Park Telephone number +40 (268) 446 222 Fax number +40 (268) 446 224 claudiu.totea@weidmuller.com www.weidmuller.ro	MX Mexico W Interconnections S. A. DE C. V. Bld. Hermanos Serdán 698, Col. San Rafael Oriente 72029 Puebla Telephone number +52 (222) 268 6227 Fax number +52 (222) 286 6242 clientes@weidmuller.com.mx	PE Peru IMPEXINCA S.A.C. Calle Ortiz de Zevallos No. 105, Urb. San Antonio 18 Lima, Miraflores Telephone number +51 1 447 5608 info@impexinca.pe www.impexinca.pe J & W CIA. S. A. Calle 6 Mz. D Lte. 23, Urb. Ind. Grimanesa 01 Callao Telephone number +51 1 572 2539 Fax number +51 1 572 0152 contacto@jwcia.com www.jwcia.com	RS Serbia Representative Office Weidmüller Interface GmbH & Co. KG Ustanicka 189, III sprat lokal 7a 11050 Beograd Telephone number +381 112885274 Fax number +381 112885274 zoran.rabrenovic@weidmuller.com TeLa Elektrik d.o.o. Ul. Dr. Drage Ljocić 6 Beograd Telephone number +381 11 2772 415 Fax number +381 11 2772 850 office@tela.rs www.tela.rs
KE Kenya Please contact our Representative Office Weidmüller Interface GmbH & Co. KG South Africa.	MA Morocco Sofimed 137, Bd Moulay Ismail Roches Noires 20290 Casablanca Telephone number Fax number contact@sofimedmaroc.com	MY Malaysia Connect Plus Technology Sdn Bhd No. 43, Jalan PJS 11/22, Bandar Sunway 46150 Petaling Jaya Selangor Darul Ehsan Telephone number +60 3 5633 7363 Fax number +60 3 5633 6562 paul@cptech.com.my www.cptech.com.my	PH Philippines Enclosure Systems Specialists Inc. 2276 Don Chino Roces Avenue Extension Room 103/105 Narra Building 1231 Makati City Telephone number +63 2 813 8580 Fax number +63 2 813 8596 sales_encsys@pltdsl.net www.enclosuresystemsph.com	
KG Kyrgyzstan Please contact our Representative Office Weidmüller Interface Azerbaijan.		MZ Mozambique Please contact Phambili Interface South Africa		
KR Korea Weidmüller Korea Co. Ltd. 9th floor 429, Teheran-ro, Gangnam-Gu Seoul 135-721 Telephone number +82 2-516-0003 Fax number +82 2-516-0090 info@weidmuller.co.kr www.weidmuller.co.kr				

Addresses worldwide

Let's connect.

- RU Russia**
Weidmüller Group
7/10 Khlebozavodskiy
Passage,
Moskau
115230
Telephone number +7 495
280 72 71
Fax number +7 495 280
72 71
Info@weidmueller.ru
www.weidmueller.ru
- SA Saudi Arabia**
Al Abdulkarim Holding Co.
P.O. Box 4
Dammam 31411
Telephone number +966 3
8337 110
Fax number +966 3
8829547
E-mail salehsk@akh.com.sa
www.weidmueller.ae

Saudi Electric Supply
Company (SESCO)
P.O. Box 32 98
Al Khobar 31952
Telephone number +966 3
8829546 Ext. 3030
Fax number
E-mail Safdar.Malik@sescogex.com
www.sesco-gex.com
- SE Sweden**
Weidmüller AB
Axel Danielssons väg 271
BOX 31025
SE-200 49 Malmö
Telephone number +46 77-
143 00 44
Fax number +46 40-37 48 60
info@weidmuller.se
www.weidmuller.se
- SG Singapore**
Weidmüller Pte. Ltd.
70 Bendemeer Road
04-03 Luzerne Building
Singapore 339940
Telephone number +65 6841
5311
Fax number +65 6841 5377
info@weidmuller.com.sg
www.weidmuller.com.sg
- SI Slovenia**
Elektrospoji d. o. o.
Stegne 27
Sl- 1000 Ljubljana
Osrednjeslovenska
Telephone number +386 1
511 3810
Fax number +386 1 511
1604
info@elektrospoji.si
www.elektrospoji.si
- SK Slovakia**
ELEKTRIS s.r.o.
Elektrárenská 1
831 04 Bratislava
Telephone number +421
2/4920 0113
Fax number +421 2/4920
0119
bratislava@elektris.sk
- SV El Salvador**
Prestegard Electro
11 Avenida Norte No. 240
Edificio Salazar No. 2
San Salvador
Telephone number +503
2271 1690
Fax number +503 2221
3851
prestegard@navegante.com.sv
- SY Syria**
Please contact
Weidmuller Middle East FZE
United Arab Emirates
- SZ Swaziland**
Please contact
Phambili Interface
South Africa
- TH Thailand**
Pisanu Engineering Co. Ltd.
Kwang Dingaeng, Khet
Dingaeng
800/2 Soi Trakulsuk, Asoke-
dindaeng Road
Dindaeng, Bangkok
10400
Telephone number +66 2
248 2896
Fax number +662 105 6301
ecsales@pisanu.co.th
www.pisanu.co.th

Representative Office
Weidmüller Pte. Ltd.
37/F, Sathorn Square Building
98 North Sathorn Road
Bangkok, Silom Bangrak
10500
Telephone number +66 2
105 6300
Fax number +66 2 642 9220
info@weidmuller.com.sg
- TJ Tajikistan**
Please contact
our Representative Office
Weidmüller Interface
Azerbaijan.
- TM Turkmenistan**
Please contact
our Representative Office
Weidmüller Interface
Azerbaijan.
- TN Tunisia**
Please contact
Weidmüller E. U. R. L.
France
- TR Turkey**
Weidmüller Elektronik Ticaret
Ltd. Sirketi
Kavacik Mah. Orhan Veli Kanik
Caddesi 9/1
34810 Beykoz / Istanbul
Telephone number +90 (216)
537 10 70
Fax number +90 (216) 537
10 77
info@weidmuller.com.tr
www.weidmuller.com.tr
- TW Taiwan**
Please contact
Weidmuller (Hong Kong)
Limited Co. Ltd.
Hong Kong
- TZ Tanzania**
Please contact
our Representative Office
Weidmüller Interface GmbH
& Co. KG
South Africa.
- UA Ukraine**
LLC WM UKRAINE
Levanevskogo str. 6
Kiev
3058
Telephone number +38 044
490 32 48
Fax number
info@wm-ua.com.ua
wm-ua.com.ua/

Representative Office
Weidmüller Interface GmbH
& Co. KG
Z, office 303
7-D, Zdolbunivska str.
Kiev, 2081
Telephone number
(mobile) +38 050 440 25 24
info.ua@weidmueller.com
- US United States**
W Interconnections Inc.
821 Southlake Boulevard
Richmond Virginia 23236
Telephone number +1 (804)
794-2877
Fax number +1 (804) 379-
2593
info@weidmuller.com
www.weidmuller.com
- UY Uruguay**
REWO Uruguay S. A.
AV. Bolivia 2001Esq
Roca fuerte
11300 Carrasco Montevideo
Telephone number +598
2604 8439
Fax number +598 2604
8439
rewo@rewouruguay.com.uy
- UZ Republic of Uzbekistan**
Please contact
our Representative Office
Weidmüller Interface
Azerbaijan.
- VE Venezuela**
Somerinca C. A.
Corazon de Jesus - 3ra
Transversal con calle el
Carmen- Los Dos Caminos
Caracas 1070-A
Telephone number +58
2122352748
Fax number +58
2122399341
klocmoeller@cantv.net
www.somerinca.com
- VN Vietnam**
AUMI Industrial Equipment &
Automation Company Limited
E1, La Thanh Hotel
218 Doi Can Street
Lieu Giai Ward, Ba Dinh
District
Hanoi City
Telephone number +84 4
37628601
Fax number +84 4
62661391
aumi@aumi.com.vn
www.aumi.com.vn

Representative Office
Weidmüller Pte. Ltd.
Level 16 Saigon Tower
Building
29 Le Duan Street
District 1
Ho Chi Minh
Telephone number +848
3520 7717
Fax number +848 3520
7604
info@weidmuller.com.sg
- ZA South Africa**
Phambili Interface
PO Box 193
1609 Johannesburg, Edenvale
5 Bundo Road, Sebenza
1610 Johannesburg
Telephone number +27 (11)
4521930
Fax number
info@weidmuller.co.za
www.weidmuller.co.za

Representative Office
Weidmüller Interface GmbH
& Co. KG
210 Amarand
Avenue, Pegasus Building
181 Pretoria, waterkloof Glen
ext 2 -
Telephone number +27 12
003 2906
Fax number +27 (11)
4526455
Jacques.Vosloo@weidmueller.
com
www.weidmueller.com
- ZM Zambia**
Please contact
Phambili Interface
South Africa
- ZW Zimbabwe**
Please contact
Phambili Interface
South Africa