

CIE-GROUP's
PROPOSAL Aug 2012
 for RS



conec².





Comprehensive range of modular AV & Data faceplate modules plates and risers.



• **CLB50-VGA:**

VGA to Screw Terminal



• **CLB50-VGA-16:**

VGA to Screw Terminal, 16 position

• **CLB46-VGA-16:**

45 ~ 25 version



• **CLB50-2RCA:**

2 x Phono to Screw Terminal



• **CLB50-3RCA-AV:**

3 x Phono to Screw Terminal

• **CLB46-3RCA-AV:**

3 x Phono to Screw Terminal



• **CLB50-44K-C3:**

2 x RJ12 to Krone IDC Block



• **CLB50-480-13MP:**

50 x 12.5 Blanking plate



Comprehensive range of modular AV & Data faceplate modules plates and risers.



• **CLB50-480-12MP:**

50 x 50 Blanking Plate



• **CLB50-480-3MP:**

50 x 25 Blanking Plate



• **CLB-360AK-8-C6:**

Cat 6 Angled module



• **CLB-360K-8-C6:**

Cat 6 Straight module



• **CLB50-84K-C5E:**

1 x Data, 1 x voice to Krone IDC



• **CLB50-88K-C6:**

2 x Cat, 6 to Krone IDC Block



conec₂

Comprehensive range of modular AV & Data faceplate modules plates and risers.



- **CLB50-8K-C5E:**
- **CLB46-8K-C5E:**

1 x Cat, 6e to Krone IDC Block
45 x 25 version



- **CLB50-BB:**

BaNaNa to Screw Terminal



- **CLB50-BNC/BNC:**

BNC-BNC 50 x 25 mm plate



- **CLB50-BNC/BNC2:**

BNC-BNC x 2, 50 x 25 mm plate



- **CLB50-HO-1:**

3.5mm cut out 50 x 25 mm blank



- **CLB50-HO-2:**

Phono cut out 50 x 25 mm blank



Comprehensive range of modular AV & Data faceplate modules plates and risers.



• **CLB50-HO-3:**

BNC cut out 50 x 25 mm blank



• **CLB50-HO-3RCA:**

3 x Phono cut out 50 x 25 mm blank



• **CLB50-PHJ:**
• **CLB46-PHJ:**

3.5mm to Screw Terminal
45 x 25 version



• **CLB50:**

F Connector to Screw Terminal



• **CLB50-SP:**

2 x Speaker Coupler L-R



• **CLB50-2ST-ST-SM-CE:**

Fiber 2 x ST Simplex Coupler





Comprehensive range of modular AV & Data faceplate modules plates and risers.



• **CLB50-2SC-SC-SM-CE:** Fiber 2 x SC Simplex Coupler



• **CLB50-LC-DUSCA-CE:** Fiber 2 x LC Duplex Coupler



• **CLB50-2SC-SC-DU-CE:** Fiber 2 x SC SC Duplex coupler



• **CLB50-LC-4-SCT:** Fiber 4 x LC coupler



• **CLB50-SV+PHJ:** S-Vid 3.5mm to Screw terminal



• **CLB50-TV:** TV aerial to Screw terminal



Comprehensive range of modular AV & Data faceplate modules plates and risers.



- **CLB50-USB:**
- **CLB46-USB:**

USB A 2.0 to Screw terminal
USB A 2.0 to Screw terminal



- **CLB-50-HDMI-90-F/F:**
- **CLB-46-HDMI-90-F/F:**

HDMI to HDMI coupler
45 x 25 version



- **CLB-50-HDMI-T:**

HDMI to Punch down



- **CLB50-USB-3.0:**

USB A 3.0 to Screw terminal



- **CLB2410-USB-CHG-H:**

- Switch ON/OFF for used USB charger
- Input: 100 ~ 250v AC, 50/60HZ 0.25
- Output: 5v DC 1000mA




- **CLB2410-USB-CHG-H:**

- Switch ON/OFF for used USB charger
- Input: 100 ~ 250v AC, 50/60HZ 0.25
- Output: 5v DC 1000mA



Comprehensive range of modular AV & Data faceplate modules plates and risers.

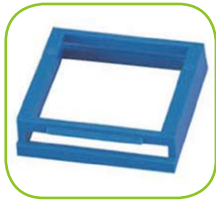

• **FA-1013-5045:**

50 ~ 45 mm Reducer, Blue



• **CLB460A:**

Single-gang wall plate 50 x 50 cut out



• **CLB460A1:**

Single-gang wall plate 25 x 50 cut out



• **CLB860A:**

Double-gang wall plate 100 x 50 cut out



• **CLB46DP-180A**

Desk Riser System housing, 4 x (45 x 45 mm) modules



• **CLB46DP-270A**

Desk Riser System housing, 6 x (45 x 45 mm) modules



Comprehensive range of modular AV & Data faceplate modules plates and risers.



- **CLB50-UK:**
- **CLB46-UK:**

UK power socket module, 50 x 50 mm
45mm version



- **CLB-2550-UD-HDMI-2:** Media outlet 1 x HDMI



- **CLB-2550-UD-USB:** Media outlet 1 x USB A



Comprehensive range of modular AV & Data faceplate modules plates and risers.



- **CLB-2550-UD-TV:** Media outlet, 1 x TV



- **CLB-2550-UD-VGA+AUDIO:** Media outlet, 1 x VGA + 3.5mm



- **CLB-2550-UD-84K-C5E:** Media outlet, 1 x data, 1 x voice 86 x 86 mm



- **CLB-2550-UD-88K-C5E:** Media outlet, 2 x data, 86 x 86 mm

Splitter Cables



- **CLB-15M-D29FX2-1FT:** VGA Male to 2 x Gold Plated DVI-I Female



- **CLB-15M-F3RCA-1FT:** VGA Male to VGA Female and 3 x Gold Plated Phono



- **CLB-15M-FX2-1FT:** VGA Male to 2 x Gold Plated VGA Female



- **CLB-D29M-15FX2-1FT:** DVI Male to 2 x Gold Plated VGA Female



- **CLB-D25M-FX2-1FT:** DVI Male to 2 x Gold Plated DVI-D Female



- **CLB-D25M-FH19F-1FT:** DVI-D Male to 2 x DVI-D Female and Gold Plated HDMI Female



Splitter Cables



- **CLB-MDVI-HFD25F-1FT:** Mini DVI Nickel Plated to HDMI Female and DVI-D Female



- **CLB-RCA3M-3FX2-1FT:** Phono Male to 6 x Gold Plated Phono



ROTOR Cables



- **CLB-HD15MM-RO-6FT:** VGA Male to Male 360° Rotor Cable
- **CLB-HD15MF-RO-6FT:** VGA Male to Female 360° Rotor Cable



- **CLB-HD1MI-MMG-RO-6FT:** HDMI to HDMI 360° Rotor Cable



HDMI and Display Port Cable with LED



- **CLB-DPC-MMG-100-30#-LED:** Display Port 20 Male to Male Gold Plated 1m Black, High Speed 30# Molded Type with LED
- **CLB-DPC-MMG-200-30#-LED:** Display Port 20 Male to Male Gold Plated 2m Black, High Speed 30# Molded Type with LED
- **CLB-DPC-MMG-300-30#-LED:** Display Port 20 Male to Male Gold Plated 3m Black, High Speed 30# Molded Type with LED



- **CLB-H19M-FX2-1FT-LEDB:** HDMI Male to 2 x Gold Plated HDMI Female with blue LED
- **CLB-H19M-FX2-1FT-LEDY:** HDMI Male to 2 x Gold Plated HDMI Female with yellow LED
- **CLB-H19M-FX2-1FT-LEDG:** HDMI Male to 2 x Gold Plated HDMI Female with green LED



HDMI Couplers



- **CLB-ADP-HDMI-MM-LED:**
 - HDMI Couplers with Green/Blue LED's
 - HDMI 19 pin Male to HDMI 19 pin Male with LED Adapter
- **CLB-ADP-HDMI-MF-LED:**
 - HDMI Couplers with Green/Blue LED's
 - HDMI 19 pin Male to HDMI 19 pin Female with LED Adapter
- **CLB-ADP-HDMI-FF-LED:**
 - HDMI Couplers with Green/Blue LED's
 - HDMI 19 pin Female to HDMI 19 pin Female with LED Adapter






- **EHTSLB:** Switchcraft EH Series Panel Mount Toggle Switch

Switchcraft



- **EHPBSMRB:** Switchcraft EH Series Panel Mount Push Button switch

Switchcraft

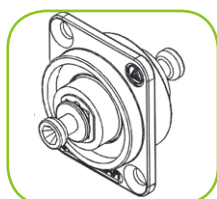


- **EHTLZ:** Switchcraft EH Series Panel Mount Toslink Feed Through Connector

Switchcraft




- **EHST2 Single mode:** Switchcraft EH Series Panel Mount ST Fiber Feed Through
- **EHST2m Double mode:**

Switchcraft

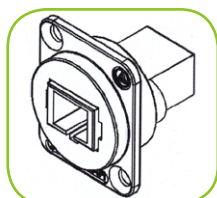

- **EHSC2 Single mode:** Switchcraft EH Series Panel Mount ST Fiber Feed Through
- **EHSC2m Multi mode:**

Switchcraft

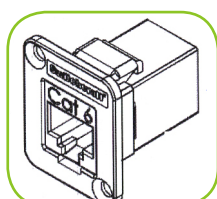

- **EHRJ45P5E:** Switchcraft EH Series Panel Mount RJ45 Feed Through
- **EHRJ45P5ES:**
- **EHRJ45P6:**
- **EHRJ45P6S:**

Switchcraft




- **EHRRSLB:** Switchcraft EH Series Pannel Mount Switch

Switchcraft




- **EHHDMI2PKG:** Switchcraft EH Series Pannel Moun HDMI Through Connector

Switchcraft

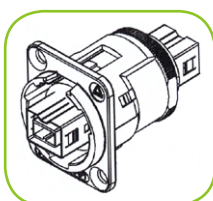

- **EHFW800X2:** Switchcraft EH Series Pannel Mount 8 W X Wired Firewire


Switchcraft

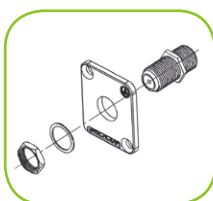

- **EHFF2:** Switchcraft EH Series Pannel Mount F to F Feed Through

Switchcraft

www.cie-group.com 

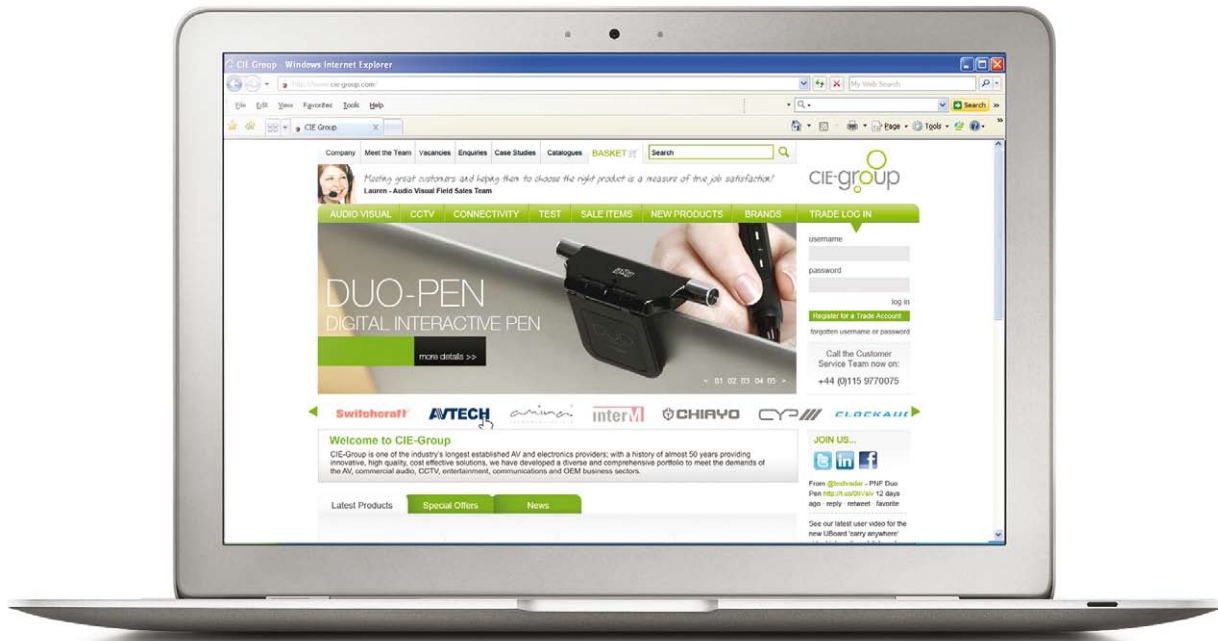

- Loudspeakers • Amplifiers • Audio Signal Processing • Audio Signal Generation • Audio System Tools
- Microphones (Wired) • Microphones (Wireless) • Portable PA Systems • Soundfield • Induction Loops • Racks & Cabinets
- Brackets • Interactive & Projectors • Digital Signage & 3D • AV Signal Distribution • Faceplates • Cables • Connectors
- CCTV Cameras • DVRs • CCTV Accessories & Software • Monitors & Displays • Testers



T: +44 (0)115 9770075 F: +44 (0)115 9770081 E: info@cie-group.com W: www.cie-group.com
CIE-Group Widdowson Close Blenheim Industrial Estate Bulwell Nottingham NG6 8WB UK

This Brochure is Fully Recyclable 