


FRONT MOUNTING

PADLOCKABLE PRESENTATION

Cat. No.

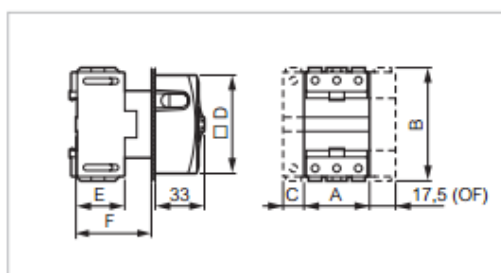

Safety switch to disconnect and isolate poles.
 IP 20 "finger safe"
 Double break type load switching
 Red padlockable handle on
 yellow plate
 Actual position (ON or OFF) clearly visible
 Conform to standards:
 IEC EN 60947-3
 Approved by UL - cUL - Suitable as motor disconnect



172001

Dimensions

A: 44
 B: 75.4
 C: 14.5
 D: □ 66
 E: 36
 F: 50

25 A

3P
 3P+NC/NO (1)
 4P neutral on left

172001
 172011
 172021

32 A

3P
 4P neutral on left

172101
 172121



172201

Dimensions

A: 53.6
 B: 85
 C: 17.9
 D: □ 66
 E: 50.3
 F: 60

50 A

3P
 4P neutral on left

172201
 172221

63 A

3P
 4P neutral on left

172301
 172321



172401

Dimensions

A: 71.8
 B: 93
 C: 26.8
 D: □ 86
 E: 63.8
 F: 70

80 A

3P
 4P neutral on left

172401
 172421

100 A

3P

172501

(1) Padlock: $\varnothing$ 6 to 8 mm