

Housing - HC-EVO-B16-HHFS-PLBK - 1407642

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON EVO sleeve housing, plastic, with bayonet flange for EVO screw connection, B16, for single locking latch, height: 76 mm, without EVO screw connection

Why buy this product

- Flexible cable outlet direction, lateral or straight
- Lower costs than metal version
- Labeling option using 9 x 20 mm marking label
- Low weight
- Lower risk of condensation
- Both contact insert PE sheets are connected by means of a metal frame integrated in the sleeve housing
- Metal inlays ensure leading PE contact with angled plugs
- Completely corrosion-resistant
- Halogen-free plastic
- Impact test according to IK 08



Key commercial data

| | |
|--------------------------------------|---|
| Packing unit | 1 pc |
| GTIN |  4 046356 777063 |
| Weight per Piece (excluding packing) | 101.0 g |
| Custom tariff number | 85389099 |
| Country of origin | Poland |

Technical data

Dimensions

| | |
|--------|---------|
| Height | 78 mm |
| Width | 44 mm |
| Length | 93.5 mm |

Ambient conditions

| | |
|--------------------------------------|------|
| Degree of protection of housing (IP) | IP66 |
|--------------------------------------|------|

Housing - HC-EVO-B16-HHFS-PLBK - 1407642

Technical data

Ambient conditions

| | |
|--|-----------------------|
| Degree of protection of housing (NEMA) | 4 (UL50e / NEMA 250) |
| | 4X (UL50e / NEMA 250) |
| | 12 (UL50e / NEMA 250) |
| Ambient temperature (operation) | -40 °C ... 125 °C |

General

| | |
|---|--|
| Note | For contact inserts HC-B16, BB32, D40, DD72, HS6, HV6, M, K, HV06-I-PR, HV 6-E...C |
| Type | B16 |
| Housing type | Sleeve housing |
| Color | black |
| Locking type | for single locking latch |
| No. of cable outlets | 1 |
| Cable exit | Straight |
| | Lateral |
| Screw connection | none |
| Housing material | Polyamide |
| Inflammability class according to UL 94 | V0 |
| Connection | The sleeve base housing must be supplemented with the EVO screw connection. The EVO screw connection is available in four sizes. It facilitates the creation of a straight or a side cable outlet. The EVO screw connection is mounted with the aid of, for example, a pipe wrench |

Classifications

eCl@ss

| | |
|------------|----------|
| eCl@ss 4.0 | 27140816 |
| eCl@ss 4.1 | 27140816 |
| eCl@ss 5.0 | 27143424 |
| eCl@ss 5.1 | 27143424 |
| eCl@ss 6.0 | 27143424 |
| eCl@ss 7.0 | 27440209 |
| eCl@ss 8.0 | 27440202 |

ETIM

| | |
|----------|----------|
| ETIM 3.0 | EC000437 |
| ETIM 4.0 | EC000437 |
| ETIM 5.0 | EC000437 |

UNSPSC

| | |
|---------------|----------|
| UNSPSC 6.01 | 31261502 |
| UNSPSC 7.0901 | 31261502 |
| UNSPSC 11 | 31261502 |

Housing - HC-EVO-B16-HHFS-PLBK - 1407642

Classifications

UNSPSC

| | |
|--------------|----------|
| UNSPSC 12.01 | 31261502 |
| UNSPSC 13.2 | 31261502 |

Approvals

Approvals

Approvals

GL / EAC

Ex Approvals

Approvals submitted

Approval details

GL

EAC

Accessories

Accessories

Cable gland with bayonet locking

Cable gland - HC-B-G-M20-PLRBK - 1407669



EVO plastic cable gland with bayonet locking; size M20, cable diameter: 7 - 13 mm

Cable gland - HC-B-G-M25-PLRBK - 1407670



EVO plastic cable gland with bayonet locking, for housing series B, size M25, cable diameter: 9 - 17 mm

Housing - HC-EVO-B16-HHFS-PLBK - 1407642

Accessories

Cable gland - HC-B-G-M32-PLRBK - 1407671



EVO plastic cable gland with bayonet locking; size M32, cable diameter: 11 - 21 mm

Cable gland - HC-B-G-M40-PLRBK - 1407672



EVO plastic cable gland with bayonet locking; size M40, cable diameter: 19 - 28 mm

Corrugated pipe screw connection

Corrugated tube screw connection - HC-B-GCA-M20-PLRBK - 1412021



EVO corrugated pipe screw connection, size: M20, protection class: IP66, plastic

Corrugated tube screw connection - HC-B-GCA-M25-PLRBK - 1411973



EVO corrugated pipe screw connection, size: M25, protection class: IP66, plastic

Corrugated tube screw connection - HC-B-GCA-M32-PLRBK - 1412022



EVO corrugated pipe screw connection, size: M32, protection class: IP66, plastic

Housing - HC-EVO-B16-HHFS-PLBK - 1407642

Accessories

Corrugated tube screw connection - HC-B-GCA-M40-PLRBK - 1412023



EVO corrugated pipe screw connection, size: M40, protection class: IP66, plastic

Device marking


Snap-in markers - US-EMP (20X9) - 0829439



Snap-in markers, Card, white, unlabeled, can be labeled with: THERMOMARK CARD, Mounting type: snapped into marker carrier, Lettering field: 20 x 9 mm

Drawings

Dimensioned drawing

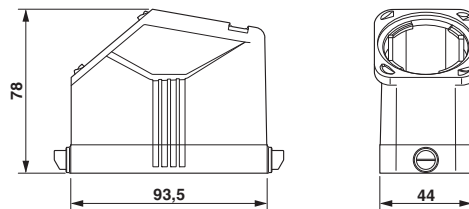

Dimensional drawing