

Micro-Lynx F

0025218



Range features

- Integrated twist and lock safety key
- Instant flicker free start (<0.3 seconds)
- Mercury content <2.5mg
- Good colour rendering (CRI=80)
- Average rated life 8,000 hrs
- Available in Homelight (2700K) Warm White (3000K) and Cool White (4000K)
- To be used in dry applications or fully enclosed fixtures



PRODUCT OVERVIEW

Ordering number	0025218
Average life (Rated) (h)	8000
Cap/Base	GX53
EAN code	5410288252186
Colour temperature (K)	3000
Watt (Nominal) (W)	6
Voltage (V)	230
Lamps	1x6W TC-FSE GX53 3000K

Micro-Lynx F

0025218

DATA TABLE

General data

Ordering number	0025218
Average life (Rated) (h)	8000
Cap/Base	GX53
EAN code	5410288252186
E-number SE	8357900
E-number FI	4942343
Long description	Integrated twist and lock safety key. Instant flicker free start (<0.3 seconds). Mercury content <2.5mg. Good colour rendering (CRI=80). Average rated life 8,000 hrs. Available in Homelight (2700K) Warm White (3000K) and Cool White (4000K). To be used in dry applications or fully enclosed fixtures
Product name	Micro-Lynx F
Control gear availability	Included
Control gear mounting	Integral
Control gear type	Electronic
Environment	Interior
General application	Commercial
Specific application	Commercial, Leisure
Sales pack quantity	20

Optical data

Colour temperature (K)	3000
Distribution type	Direct - Symmetric
Optical controller finish	Clear

Electrical data

Watt (Nominal) (W)	6
Voltage (V)	230
T Class min (°C)	-1
T Class max (°C)	-1
Lamps	1x6W TC-FSE GX53 3000K
Number of heads	1


Physical data

Weight (kg)	0.05
Emergency	Without
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	8.10 x 8.10 x 2.70
Outer package dimensions (L x W x H) (cm)	28.00 x 19.50 x 9.20

Micro-Lynx F

0025218

PHOTOMETRY

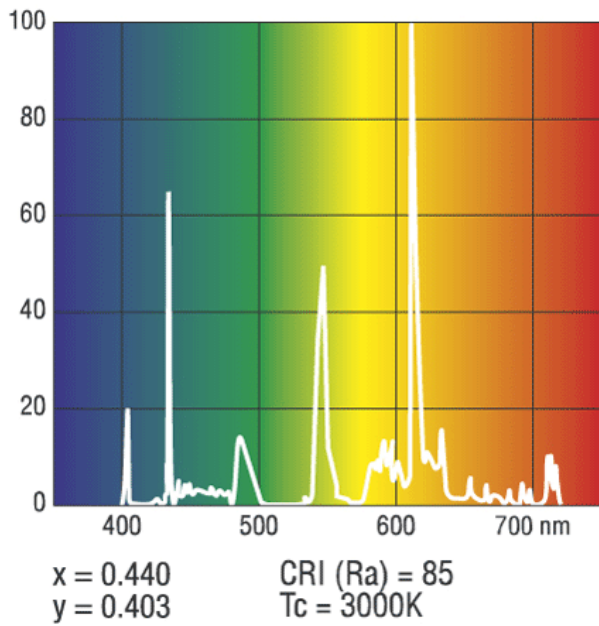

TECHNICAL DRAWINGS

