





## W2E200H Series Tubeaxial

225x225x80mm

- AC fans with external rotor shaded-pole motor.
- Die-cast aluminum housing. Impeller of sheet-steel, directly welded onto rotor.
- Air exhaust over struts. Rotational direction CCW looking at rotor.
- Mounting from either face using four 4.5 mm holes.
- Electrical connection via 2 flat pin terminals 2.8 x 0.5 mm.
- Mounting from either face using 2 4.3 mm (.169") holes.
- UL, CSA, VDE approvals on some models, please contact application engineering.

| Part Number    | Curve | CFM @ 0 | VAC | Hertz | Power (W) | dBA | Max Amb. Temp C | Bearing Type | Features       | Wgt. (lbs) |
|----------------|-------|---------|-----|-------|-----------|-----|-----------------|--------------|----------------|------------|
| W2E200-HH82-01 | 1     | 500     | 115 | 50/60 | 60        | 56  | 75              | Ball         | Terminal Block | 4.38       |
| W2E200-HH86-01 | 2     | 607     | 115 | 50/60 | 80        | 61  | 75              | Ball         | Terminal Block | 4.38       |
| W2E200-HH64-05 | 1     | 500     | 230 | 50/60 | 60        | 56  | 75              | Ball         | Terminal Block | 4.38       |
| W2E200-HH38-01 | 2     | 607     | 230 | 50/60 | 80        | 61  | 75              | Ball         | Terminal Block | 4.38       |

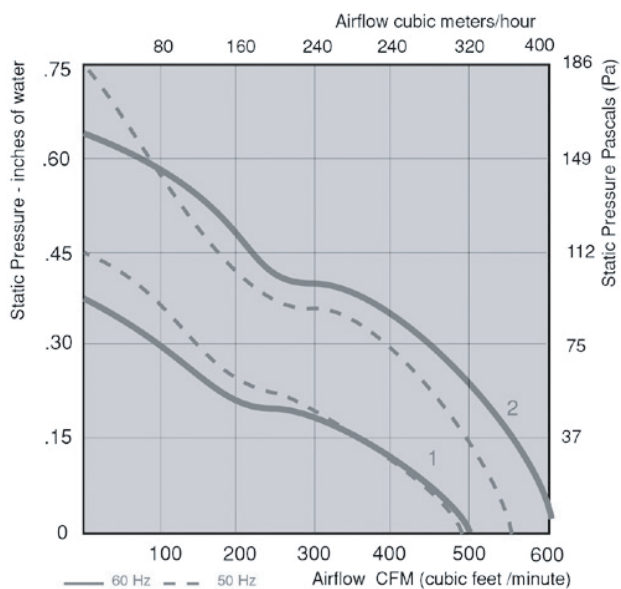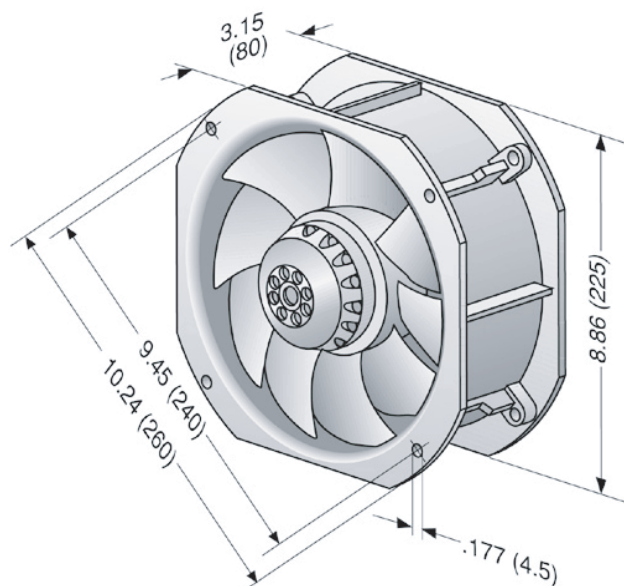

**ebmpapst**

e-mail: [sales@us.ebmpapst.com](mailto:sales@us.ebmpapst.com) • TEL: 860-674-1515 • FAX: 860-674-8536

ebm-papst Inc., 100 Hyde Road, Farmington, CT 06034 USA

ebm-papst Inc., 2004 © ebm-papst Inc. reserves the right to change any specifications or data without notice