


CPP INDUSTRY'S CHOICE

Advanced Engineered Industrial Couplings

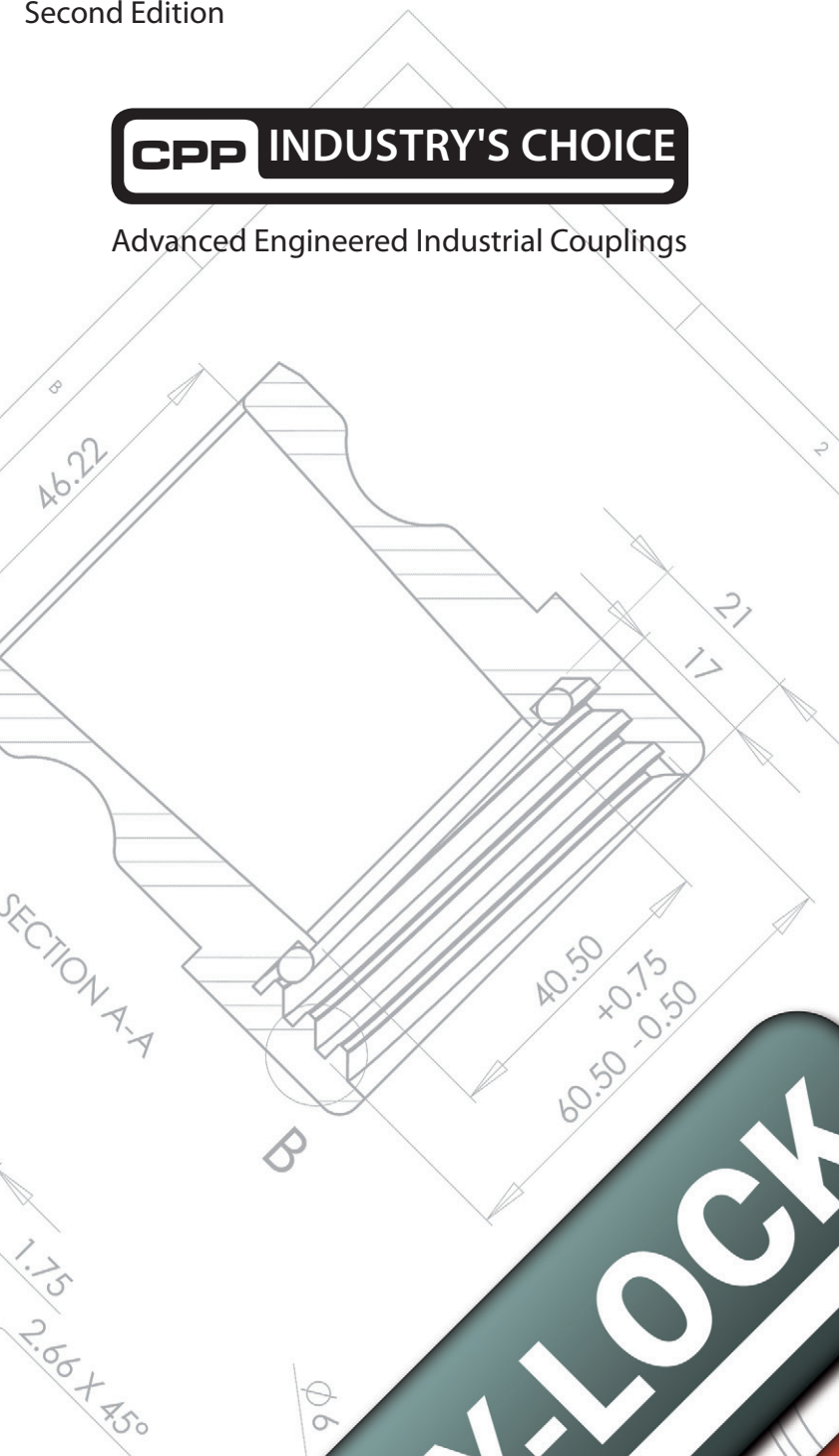

CPP KEY-LOCK

OSY-SEAL

CPP IBC VALVE

IBC ADAPTORS

CPP DRY

CP

CS

IBC CONNECTIVITY — KEY REFERENCE

Components within this brochure are identified with a key regarding which IBC the component fitting(s).

IBC Fitting	Thread	Description	Key
		<p>Name: 560X6 (2") male buttress D1: 60mm (2.36") P1: 6mm (0.24") Standard: DIN 6131 (schütz do not us this specification) Note: Most common thread found on European IBC's</p>	▲
		<p>Name: 2" NPS male D1: 59.6mm (2.35") P1: 2.21mm (0.09" - 11.5 TPI) Standard: ANSI B1.20.1-1983 Note: American National Standard Straight Pipe Thread</p>	▼
		<p>Name: 2" Camlock male with 2" BSP D1: 63mm (2.48") (59.4mm (2.34") thread) P1: 2.3mm (0.09" 11 TPI) Standard: Camlock- A-A-59326 : 1992 Thread – BS 2779 : 1986 Note: Camlock male adaptor with added external thread for cheap and compact dust cap</p>	◆
		<p>Name: 2" Camlock male with 2 1/8" BSP D1: 63mm (2.48") (62.7mm (2.47") thread) P1: 2.3mm (0.09" 11 TPI) Standard: Camlock- A-A-59326 : 1992 Thread – N/A Note: Camlock male adaptor with added external over sized thread for cheap and compact dust cap and added seal area for connecting a female Camlock.</p>	●
		<p>Name: 2" Camlock male adaptor D1: 63mm (2.48") P1: N/A Standard: Camlock- A-A-59326 : 1992 Note: 2" Camlock male adaptor fitted to an IBC</p>	■
		<p>Name: M80X3 male thread D1: 80mm (3.15") P1: 3mm (0.12") Standard: ISO 68 (ANSI B1.13M) Note: A 80mm (3.15") metric thread found mainly on the Chinese Kingtainer IBC</p>	⬠
		<p>Name: S100X8 (3") male buttress D1: 97-100mm (3.82" - 3.94") P1: 8mm (0.32") Standard: N/A Note: Found on a lot of 3" outlet IBC's, short length and a large thread depth</p>	★
		<p>Name: 3" Camlock with 3" BSP D1: 91.5mm (3.6") (87.7mm (3.45") thread) P1: 2.3mm (0.09" 11 TPI) Standard: Camlock- A-A-59326 : 1992 Thread – BS 2779 : 1986 Note: Camlock male adaptor with added external thread for cheap and compact dust cap</p>	☾

Please reference page 16 for IBC Valve Fittings and relevant keys: 

CPP HOSE FITTINGS


Polymer Hose Fittings

Hex: Glass coupled polypropylene hose tails with parallel male thread

Lugged couplings: Polypropylene hose couplings, caps and plugs in BSP and URT threads

Standard Hex threaded polypropylene fittings

Part 'HE' — Male threaded x hose tail

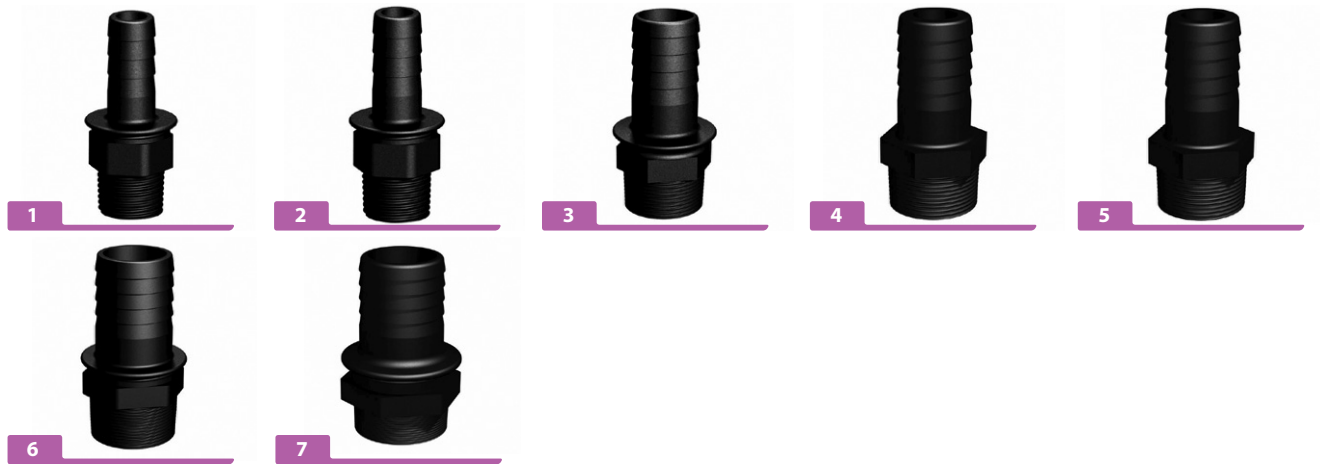

ID	Product Number	Product Description
1	HMB/05T/027	½" BSP hex. Male X ½"(13mm) hose tail G/P/P
2	HMB/75T/027	¾" BSP hex. Male X ¾"(19mm) hose tail G/P/P
3	HMB/10T/027	1" BSP hex. Male X 1"(25mm) hose tail G/P/P
4	HMB/12T/027	1 ¼" BSP hex. Male X 1 ¼"(32mm) hose tail G/P/P
5	HMB/15T/027	1 ½" BSP hex. Male X 1 ½"(38mm) hose tail G/P/P
6	HMB/20T/027	2" BSP hex. Male X 2"(50mm) hose tail G/P/P
7	HMB/30T/027	3" BSP hex. Male X 3"(75mm) hose tail G/P/P

Standard Lugged threaded polypropylene fittings

Part 'LC' — Female thread lugged nut X hose tail



ID	Product Number	Product Description
1	LFBG/15S/025	1 ½" BSP lugged female - flat gasket x 1 ½" (38mm) hose tail P/P
2	LFBG/20S/025	2" BSP lugged female - flat gasket x 2" (50mm) hose tail P/P
3	LFBG/25S/025	2 ½" BSP lugged female - flat gasket x 2 ½" (63mm) hose tail P/P
4	LFBG/30S/025	3" BSP lugged female - flat gasket x 3" (75mm) hose tail P/P
5	LFBG/40S/025	4" BSP lugged female x 4" - flat gasket (101.5mm) hose tail P/P

Part 'LE' — Male thread lugged X hose tail



ID	Product Number	Product Description
1	LMB/15S/025	1 ½" BSP lugged male x 1 ½" (38mm) hose tail P/P
2	LMB/20S/025	2" BSP lugged male x 2" (50mm) hose tail P/P
3	LMB/25S/025	2 ½" BSP lugged male x 2 ½" (63mm) hose tail P/P
4	LMB/30S/025	3" BSP lugged male x 3" (75mm) hose tail P/P
5	LMB/40S/025	4" BSP lugged male x 4" (101.5mm) hose tail P/P

Part 'LDC' — Female threaded lugged nut X dust cap




ID	Product Number	Product Description
1	LCBG/15P/025	1 ½" BSP lugged female - flat gasket x dust cap P/P
2	LCBG/20P/025	2" BSP lugged female - flat gasket x dust cap P/P
3	LCBG/25P/025	2 ½" BSP lugged female - flat gasket x dust cap P/P
4	LCBG/30P/025	3" BSP lugged female - flat gasket x dust cap P/P
5	LCBG/40P/025	4" BSP lugged female - flat gasket x dust cap P/P

Part 'LDP' — Male thread lugged X dust cap




ID	Product Number	Product Description
1	LPB/15P/025	1 ½" BSP lugged male x dust plug P/P
2	LPB/20P/025	2" BSP lugged male x dust plug P/P
3	LPB/25P/025	2 ½" BSP lugged male x dust plug P/P
4	LPB/30P/025	3" BSP lugged male x dust plug P/P
5	LPB/40P/025	4" BSP lugged male x dust plug P/P

Part 'LUC' — *URT female threaded lugged nut X hose tail*

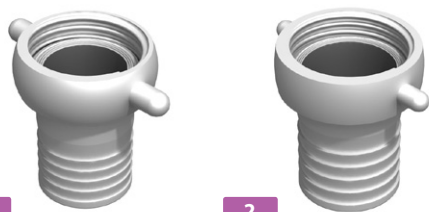

ID	Product Number	Product Description
1	LFUG/30S/025	3" URT lugged female - flat gasket x 3" (75mm) hose tail P/P
2	LFUG/40S/025	4" URT lugged female - flat gasket x 4" (101.5mm) hose tail P/P

Part 'LUE' — *URT male thread lugged X hose tail*

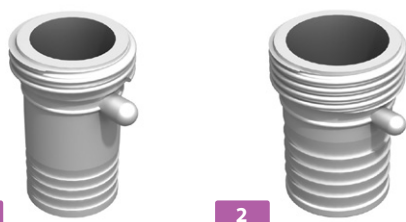


ID	Product Number	Product Description
1	LMU/30S/025	3" URT lugged male x 3" (75mm) hose tail P/P
2	LMU/40S/025	4" URT lugged male x 4" (101.5mm) hose tail P/P

Part 'LUDC' — *URT female threaded lugged nut X dust cap*



ID	Product Number	Product Description
1	LCUG/30P/025	3" URT lugged female - flat gasket x dust cap P/P
2	LCUG/40P/025	4" URT lugged female - flat gasket x dust cap

Part 'LUDP' — *URT male thread lugged X dust plug*

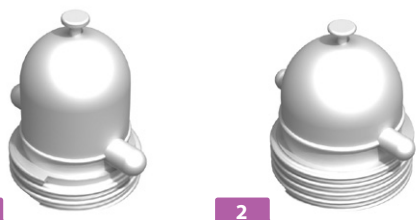

ID	Product Number	Product Description
1	LPU/30P/025	3" URT lugged male x dust plug P/P
2	LPU/40P/025	4" URT male lugged x dust plug P/P

Part 'LUB' — URT female threaded nut X male thread



2

ID	Product Number	Product Description
1	AFGM/004/025	4" URT lugged female - flat gasket x 3" URT male adaptor P/P

Spares — Lugged coupling gaskets



1

2

3

4

5

ID	Product Number	Product Description
1	LG15/PP/WT	1 ½" Lugged Gasket Ribbed White PP
2	LG20/PP/WT	2" Lugged Gasket Ribbed White PP
3	LG25/PP/WT	2 ½" Lugged Gasket Ribbed White PP
4	LG30/PP/WT	3" Lugged Gasket Ribbed White PP
5	LG40/PP/WT	4" Lugged Gasket Ribbed White PP