

DELTA REFLEX SMOKE DETECTOR 9V STAND-ALONE DIMENSIONS 115MM X 43MM TITANIUM WHITE



Model		
Type of certification / NCP		No
Cable entry type		Not applicable
Design of fire alarm / Smoke detector		Yes
Design of the product / explosion-proof design		No
Design of transmission medium / wireless transmission		No
General technical data		
Response value temperature	°C	50
Outer diameter / of the enclosure	mm	111
Loudness level	dB	85
Voltage		
voltage supply		9 V alkaline battery (included in the scope of supply)
Supply voltage		
Type of voltage / of the supply voltage		DC
Protection class		
Protection class IP		IP30
Appearance		
Color		white
Product details		
Product component / Integrated / orientation lighting		No
Product expansion / optional / can be networked with wireless connection		No

## Product function

### Product function

- of backup battery / rechargeable

No

## Number

### Number of fire detectors / networkable

1

## Mechanical Design

### Height

mm

40

### Length

mm

180

### Mounting type

assembly

### Mounting type / mounting in cable duct

No

## Certificates

### Certificate of suitability

- VdS approval

Yes

### General Product Approval



[other](#)

## Further information

### Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

### Industry Mall (Online ordering system)

<https://eb.automation.siemens.com/mall/en/WW/Catalog/Product/5TC1295>

### Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.automation.siemens.com/WW/view/en/5TC1295/all>

### Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mfb=5TC1295](http://www.automation.siemens.com/bilddb/cax_en.aspx?mfb=5TC1295)

### CAX-Online-Generator

<http://www.siemens.com/cax>

### Tender specifications

<http://ausschreibungstexte.siemens.com/tiplv>

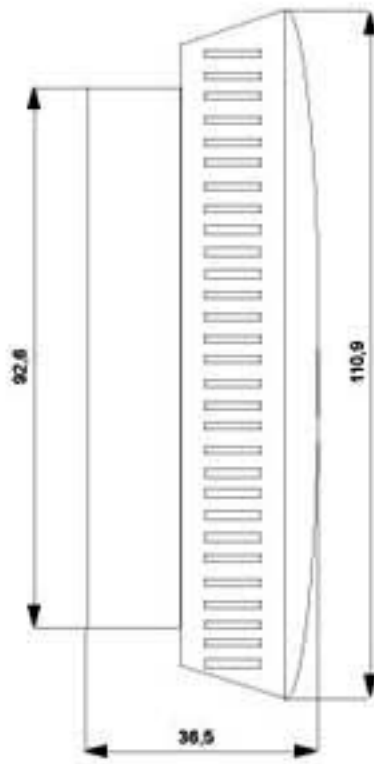

last modified:

05.05.2015