


Datasheet

Filament Indicator Lamp

RS Stock number [106-391](#)

Dimensions: (mm)

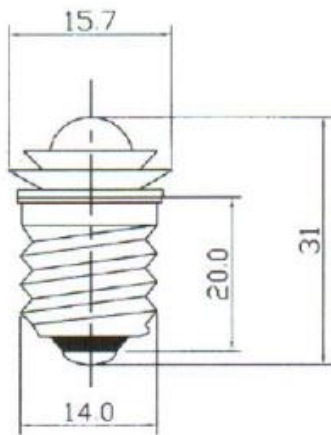

Specifications

Structure		Design Characteristics	
Bulb Type	E16X30	Voltage	220/250V
Bulb Diameter	Ø15.7 Max	Amperage	2.5mA±10%
Length	31.0 Max	Gas Type	Neon gas-filled
Base Type	E14	Life Hours	25000hrs