

5

4

3

2

1

Lieferumfang :

1 Gehäuse mit Deckel-Zinkdruckguss

2 Rändelschrauben :

4-40 UNC x 16,9 (bei X=0)

M3 x 16,9 (bei X=3)

2 Zylinderschrauben mit Innensechskant :

4-40 UNC x 17,5 (bei X=2)

M3 x 17,5 (bei X=1)

2 Federringe 2,6 DIN 127 B (bei X=1 oder 2)

1 Erdungsschraube M2,5 x 4

4 Deckelschrauben M2,5 x 6,5

2 Blind plugs

Bei Verwendung eines Schraubendrehers mit Kugelkopf wird die Bedienbarkeit der Schrauben wesentlich vereinfacht

Bestellnummer : 61 03 600 0021

Hood assembly consists of :

1 Metal hood with cover-diecast zinc

2 Thumb screws (knurled) :

4-40 UNC x 16,9 (with X=0)

M3 x 16,9 (with X=3)

2 Cylinder socket head cap screws :

4-40 UNC x 17,5 (with X=2)



M3 x 17,5 (with X=1)

2 Spring washers 2,6 DIN 127 B (with X=1 or 2)

1 Screw M2,5 x 4 for grounding post

4 Cover screws M2,5 x 6,5

2 Blind plugs

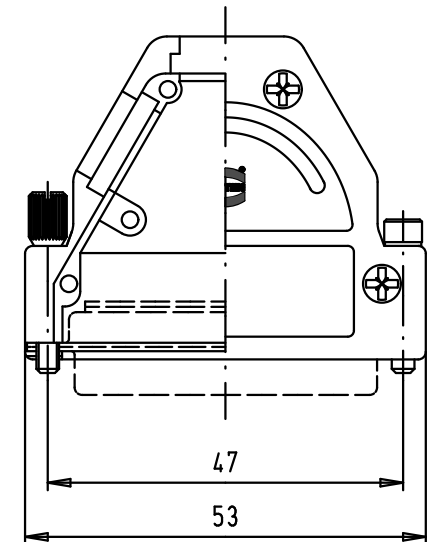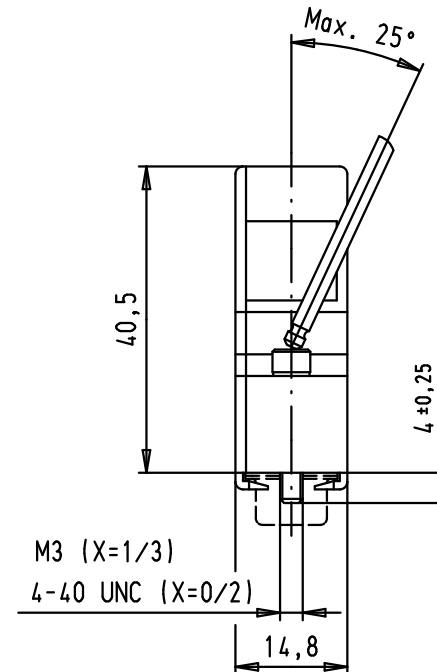

X = 0 ... 3

				Det.	Name		INDUCOM	Maßstab/ Scale
			Detail.	14/08/03	STRAUCH		Full metal hood for D-Sub	1:1
			Insp.			All Dim. in mm	25 poles connectors with	
			Stand.			Orig. Size DIN A 4	angled/straight cable entry	
32473	10/01/05	STRAUCH	HARTING Electronics GmbH & Co. KG				TB 61 03 001 X017	Blatt/ Page
Mod.	Det.	Name	D-32339 ESPELKAMP				Sub.	1 / 1