

WR 2002

2-Channel Rework Station Set, 200 W (300 W)
Product no.: T0053380699N



Benefits

- › Power unit WR 2, 2 channels with soldering iron WP 80, desoldering iron DSX 80
- › Small repair set for all rework applications
- › Simultaneous operation of hot air and desoldering iron is not possible


For this purpose, we recommend:



Solder fume extractors



Soldering irons

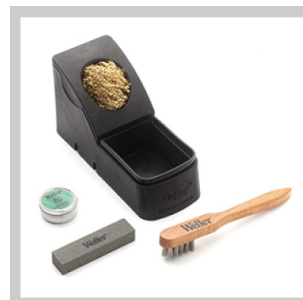

Cleaning




Pre-heating plates



Technical Data

Dimensions L x W x H (mm)	273 x 235 x 102
Dimensions L x W x H (inches)	10,75 x 9,2 x 4,02
Weight (approx.) in kg	6,7
Voltage	230 V
Power	250 W (300 W)
Channels	2
Temperature range (depends on tool) °C	50 - 550
Temperature range (depends on tool) °F	150 - 950
Temperature accuracy °C	±9
Temperature accuracy °F	±17
Temperature stability °C	±2
Temperature stability °F	±4
Equipotential bonding socket	Via a 3.5 mm jack bush (initial state-hard-grounded)
Display	LCD
Air consumption l/min	---
Operating pressure in bar/psi	---
Capacity l/min	18
Vacuum	---

Owning the bench

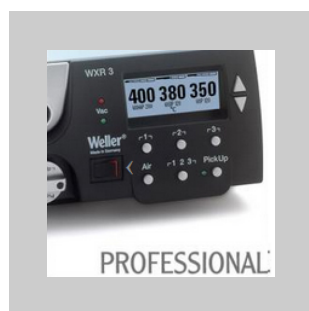

PROFESSIONAL



FILTRATION



EREM



XCELITE